



- **High stability**
- Component for conveyor structure
- For round tube
- Materials:
 - Body: Reinforced polyamide
 - Inserts: Nickel brass
 - Screws: stainless steel

Accessories

- Compatible **PR** Feet

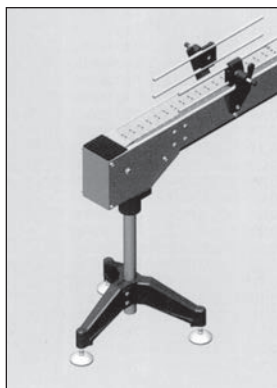

Typical application

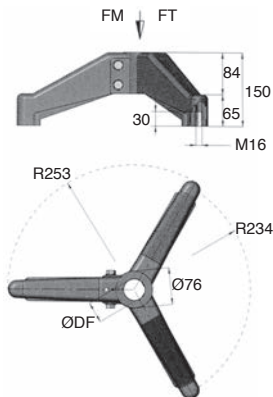

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request


Part number	ØDF	Max. load resistance FM (N)	Max. working load FT (N)	Weight (kg)	Stock*	Price each 1 to 4
ESST-42	42,4	16000	8000	1,90	✓	44,01 €
ESST-48	48,3	16000	8500	1,90	-	42,78 €
ESST-50	50,9	16000	9000	1,90	✓	44,77 €
ESST-60	60,3	16000	10000	1,90	✓	39,88 €

*Depending on availability - Dimensions in mm

Our other products



 PTKss
Foot for the food industry, Stainless steel - 3-A standard



LAT2
2A motorised linear actuator, 2 amperes



NCT
Square tube connector, Fixed angle



INO
Internal gear, Steel 20NCD2




GLT2-17
Telescopic drawer runners for groove mounting, Partial extension



CHM50-MOT
Asynchronous AC motorgearboxes 0.18 to 0.75kW, 0.18 to 0.75kW



CHT80
Asynchronous AC Motor 0.55 to 1.1kW, 0.55 to 1.1kW

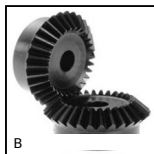

B
Steel bevel gear, 1:1



GCA
Linch pin, Linch



BLHM50
Right angled gearbox, double output shafts, up to 30 Nm



T5M T10M
T type timing belt per metre, T5 Steel cored polyurethane



SDG
Adjustable guide support bracket, Plastic

Complementary products



PR40
Articulated foot Ø40, Ø 40



ESSB
Bipod support base, Bipod support base