



- **High stability**
- Component for conveyor structure
- For round tube
- Materials:
 - Body: Reinforced polyamide
 - Inserts: Nickel brass
 - Screws: stainless steel

Accessories

- Compatible **PR Feet**

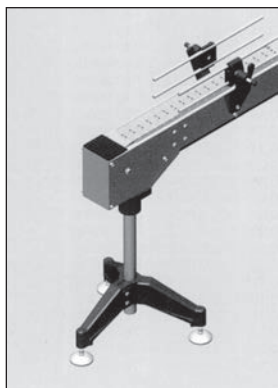

Typical application

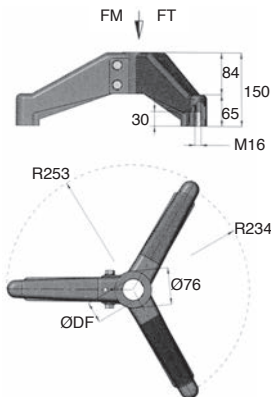

DISCOUNTS

Qty	1+	5+	10+
Disc. List	-5%	On request	

Part number	ØDF	Max. load resistance FM (N)	Max. working load FT (N)	Weight (kg)	Stock*	Price each 1 to 4
ESST-42	42,4	16000	8000	1,90	✓	44,01 €
ESST-48	48,3	16000	8500	1,90	-	42,78 €
ESST-50	50,9	16000	9000	1,90	✓	44,77 €
ESST-60	60,3	16000	10000	1,90	✓	39,88 €


*Depending on availability - Dimensions in mm

Our other products



PTAF80-PAMF80

 Articulated fixable foot with pressed base Ø80, Ø 80



H1

Crossed helical gear crossed axis at 90°, Machined plastic (delrin)



GAL_20

Conveyor roller for Ø20mm spindle, Self-lubricating polyamide



SHA_PT

Handwheel with handle, Polyamide



EIM

Stainless steel U bolt, Stainless steel



T10_21N1F

T type timing pulley, Economy range - T10 moulded plastic (nylon)



PRS80

Stainless steel articulated foot Ø80, Ø 80



GLP

Small 6 lobe threaded handle - male, Technopolymer - Stainless steel



SC2

2 part rigid shaft clamp, Clamping jaw



AC

Strike for toggle latch, 12,13,18 and 20mm



SHO

Parallel axis helical gear, Machined plastic (delrin)



BLHM20

Right angled gearbox, double output shafts, up to 1.77 Nm

Complementary products



PR40

Articulated foot Ø40, Ø 40



ESSB

Bipod support base, Bipod support base