

# Modular handle for aluminium profiles


## ETP

### Ends and tubes for creating custom handles



- **Interchangeable ends**
- Ends and caps sold in pairs
- **Material:**  
 Ends : Black glass fibre reinforced nylon  
 Tubes : Carbon fibre, aluminium or stainless steel

### Advantages


- Modular system allows assembly of tailor made handles

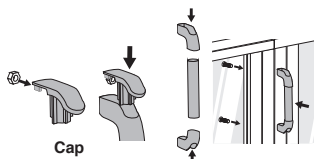

Assembly using square tube TUBE

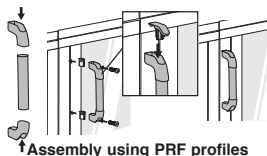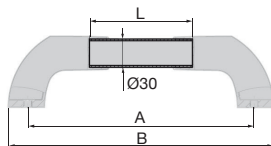

Assembly using PRF profiles

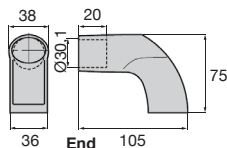

### DISCOUNTS

Qty	1+	50+	100+
Disc.	List -5%	On request	

Références	For screw	A	L	B	Weight (g)	Prix Uni. 1 à 49
<b>End</b>						
ETP-B	M8	-	-	-	69,8	7,71 €
<b>End cap</b>						
ETP-B-CAP	-	-	-	-	52	3,45 €
<b>Anodised aluminium tube</b>						
ETP-200/AA	-	200	70	240,8	17	6,51 €
ETP-300/AA	-	300	170	340,8	42	9,79 €
ETP-400/AA	-	400	270	440,8	67	13,06 €
ETP-500/AA	-	500	370	540,8	91	16,35 €
<b>Stainless steel tube</b>						
ETP-200/SS	-	200	70	240,8	51	16,35 €
ETP-300/SS	-	300	170	340,8	124	24,52 €
ETP-400/SS	-	400	270	440,8	197	31,06 €
ETP-500/SS	-	500	370	540,8	270	39,25 €

Dimensions in mm

## Our other products



J51  
Spur gear coaxial gearbox, from 0.13 to 0.49 Nm - In-line



ACLBDB  
Closing mechanism for aluminium profile, Dual ball catch



WSRM  
Cylindrical polymer nut, Polymer (Iglidur®) - 1 thread



CHMX\_CHMDX  
Shaft for worm and wheel reducer CHMR and CHM, CHMR and CHM gearbox...



PLA  
Flat magnet, Flat magnet



PCS25ECO  
Chain sprocket - steel, 6.35mm



SBF  
Sealed flange bearing unit for Food Industry, cover



PSP  
Support profile, Panel support



GSI\_A  
Gas control screw for gas spring, Gas



VAB  
Flanged nut for ball screw, For VAB



HTD8M-BAR  
HTD type tooth bar stock, HTD8



CMAss  
Eye bolt stainless steel, Stainless steel

## Complementary products



PRF4545  
Standard aluminium profile, 45 x 45 mm



PRF\_ECL  
Nut for aluminium profile, Steel square nut with tab