


- Cable terminal to be screwed
- Material :
Stainless steel 316

Accessories

- CAB cable
(tome 1 p.418)

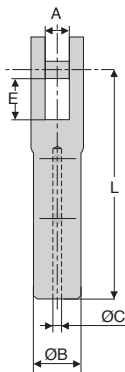

DISCOUNTS

Qty	1+	4+	10+	15+
Disc. List	-10%	-20%	On request	


Part number	For cable					Weight (g)	Price each 1 to 3
	ØC	A	ØB	C	L		
EVC2-37/SS	2	4,5	8	7	37	16,5	
EVC3-50/SS	3	5,5	10	8	50	30,0	
EVC4-52/SS	4	6,5	12	8	52	46,0	

Dimensions in mm

- Cable terminal to be screwed
- Thread ISO pitch right hand
- Delivered with a nut
- Material :
Stainless steel 316

Accessories

- CAB cable
(tome 1 p.418)

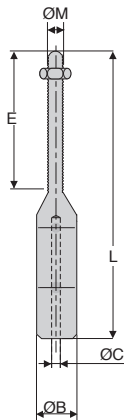

DISCOUNTS

Qty	1+	4+	10+	15+
Disc.	List	-10%	-20%	On request


Part number	For cable			E	L	Weight (g)	Price each 1 to 3
	ØC	ØM	ØB				
EVF2-50-M4/SS	2	M4	8	20	50	11,0	
EVF3-56-M4/SS	3	M4	10	20	56	19,0	
EVF4-80-M5/SS	4	M5	12	40	80	51,5	

Dimensions in mm

- Cable terminal to be screwed
- Material :
Stainless steel 316

Accessories

- CAB cable
(tome 1 p.418)

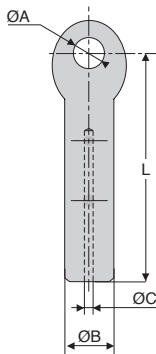

DISCOUNTS

Qty	1+	4+	10+	15+
Disc. List	-10%	-20%	On request	


Part number	For cable			L	Weight (g)	Price each 1 to 3
	ØC	ØA	ØB			
EVY2-37/SS	2	4,5	8	37	13	
EVY3-50/SS	3	5,5	10	50	27	
EVY4-52/SS	4	6,5	12	52	41	

Dimensions in mm

- Cable terminal to be screwed
- Thread ISO pitch right hand
- Delivered with a nut
- Material :
Stainless steel 316

Accessories

- CAB cable
(tome 1 p.418)

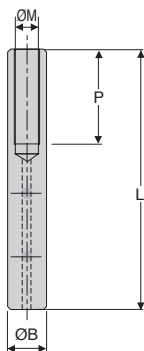

DISCOUNTS

Qty	1+	4+	10+	15+
Disc.	List	-10%	-20%	On request

Part number	For cable			P	L	Weight (g)	Price each 1 to 3
	ØC	ØM	ØB				
EVT2-55-M5/SS	2	M5	8	20	55	16,0	
EVT3-65-M5/SS	3	M5	10	25	65	33,0	
EVT4-70-M6/SS	4	M6	12	25	70	51,5	

Dimensions in mm

Our other products



SRG

Adjustable latch clamp with strike plate, Stroke from 117,4mm to 128mm



BLH30

Right angled gearbox, from 1.32 to 4.40 Nm



G-ECO25

Eco range Spur gear, Steel C45



BPF

Sheet steel flanged bearing for light loads, Sheet steel



PRES3HR

Manual workbench press, Force up to 400kg



GAC

Lock for latch clamp, Strike plate



BOX-TOR-B

Box set of Nitrile O-rings in nitrile, 20.38 x 1.78mm to 50.16 x 5.34



 
CHTRP

Single and dual output gearboxes, Up to 9,1 Nm



CHT

Asynchronous AC Motor, 0.18 to 0.55kW



PF20

Worm and wheel gear reducer, up to 5 Nm



PDM_PDv

Detectable plastic palm grip, blue



LVT

Miniature motorised actuator 1A, 1 amper

Complementary products



ERC

Quick fitting cable terminal, Fork



 
ERC

Quick fitting cable terminal, Eye version



ERF

Quick fitting threaded cable terminal, Cable terminal with threaded ...



CAB

Galvanised steel cable, Galvanised steel