

Optional shaft for E-type gear reducers


Stainless steel

**Ex
EDX**


- Optional accessory for adding outputs shafts to E series gear reducers

Composition


- Single shaft kit E-x: shaft in stainless steel 303, 2 steelkeys and 2 steel circlips
- Double shaft kit E-dx: stainless steel 303 shaft, 3 steel keys and 2 steel circlips

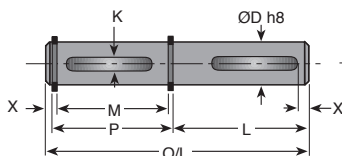

Single shaft E-X

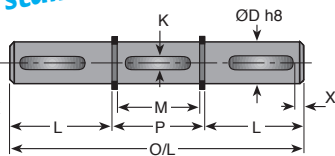

Double shaft E-DX

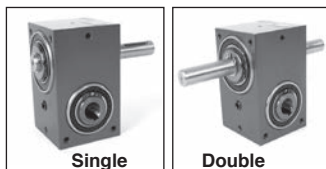

Single

Double

Assembly examples



DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-15%	-20%	On request

Part number	For gearbox	ØD	O/L	M	P	X	L	K	Price each 1 to 5
Single									
E20-X	E20	6	68,80	40	41,60	3,00	25	K2 x 22	47,01 €
E30-X	E30	10	98,60	54	56,20	3,50	40	K3 x 20	55,68 €
E40-X	E40	15	127,10	72	74,20	4,00	50	K5 x 30	67,62 €
E50-X	E50	20	153,80	88	90,60	4,50	60	K6 x 32	75,49 €
E60-X	E60	25	182,30	106	108,60	5,00	70	K8 x 40	81,38 €
Double									
E20-DX	E20	6	91,60	40	41,60	3,00	25	K2 x 22	60,58 €
E30-DX	E30	10	136,20	54	56,20	3,50	40	K3 x 20	69,80 €
E40-DX	E40	15	174,20	72	74,20	4,00	50	K5 x 30	81,21 €
E50-DX	E50	20	210,60	88	90,60	4,50	60	K6 x 32	94,27 €
E60-DX	E60	25	248,60	106	108,60	5,00	70	K8 x 40	110,01 €

Dimensions in mm

Our other products



SH0

Parallel axis helical gear, Steel 20NCD2



DFG

Flat suction cup, nitrile



HK

Manual locking clamp, Manual locking clamp LWH



SSB

Stainless steel bevel gear, 1:1



PPS

Lifting ring, Universal threaded



HRV

V-rail guidance Simple Select® system, Rail with carriage



BPPE

Ball transfer unit push fit, Light




MSP3815

Masterplate® glueable insert rectangular, rectangular with



HDSS

 Needle roller double universal joint - Stainless steel, Heavy



LVT

Miniature motorised actuator 2A, 2 ampers



BAPT

Hardened Stainless steel ball pin, Hardened stainless



M0

Worm and wheel set, Machined plastic (delrin)

Complementary products



E20

Right angle helical reducers, from 0.60 to 3.84 Nm



E30

Right angle helical reducers, from 1.50 to 9 Nm