


- Large degree of deformation accepted thus absorbing large amounts of energy
- Energy absorbed gradually
- Material:
 - Core: Steel plates
 - Cylinder: Rubber
- Hardness NK 55-60 shore A
- Working temp: -40°C to +70°C

Uses

- Shock absorbing stop

Info.

- Not sold individually, please contact us for details
- Values for loads and rigidity are given as a guide only

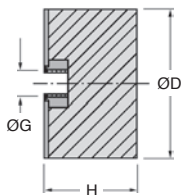

DISCOUNTS

Qty	1+	6+	20+	40+	100+	200+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	ØG	ØD	H	Compression		Stock*	Price each 1 to 5
				stiffness (N/mm)	Max. load (N)		
E-ZY4-10-10	M4	10	10	38	43	✓	1,16 €
E-ZY4-10-15	M4	10	15	-	-	✓	1,42 €
E-ZY4-15-15	M4	15	15	74	95	✓	1,49 €
E-ZY6-20-15	M6	20	15	138	170	✓	1,97 €
E-ZY6-20-20	M6	20	20	-	-	✓	2,04 €
E-ZY6-25-10	M6	25	10	-	-	✓	2,20 €
E-ZY6-25-20	M6	25	20	128	280	✓	2,82 €
E-ZY6-25-30	M6	25	30	80	280	✓	2,82 €
E-ZY8-30-15	M8	30	15	-	-	✓	2,73 €
E-ZY8-30-17	M8	30	17	-	-	✓	2,82 €
E-ZY8-30-20	M8	30	20	200	400	✓	3,17 €
E-ZY8-30-30	M8	30	30	120	400	✓	3,87 €
E-ZY8-40-30	M8	40	30	23	234	✓	4,76 €
E-ZY10-50-20	M10	50	20	680	1000	✓	6,03 €
E-ZY10-50-30	M10	50	30	425	1000	✓	6,58 €
E-ZY10-50-40	M10	50	40	-	-	✓	7,23 €
E-ZY10-50-50	M10	50	50	-	-	✓	8,45 €
E-ZY12-75-25	M12	75	25	2000	2300	✓	12,82 €
E-ZY12-75-55	M12	75	55	-	-	✓	19,07 €

*Depending on availability - Dimensions in mm

Our other products



H0

Crossed helical gear
crossed axis at 90°,
Steel 20NCD2



SDG_SS

Universal adjustable
guide support
bracket, Stainless
steel




PW_PWG2

Wheel - precision
range, Bronze



CABPVC

PVC covered
galvanised steel
cable, Galvanised
steel with

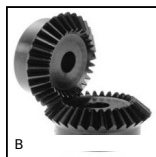

B

Steel bevel gear, 1:1



DTR

Chain idler sprocket,
Chain idler sprocket -
Plastic



TCXR

Automatic chain
tensioner, With
stainless steel
sprocket



DOMI50

Connecting kits, XZ
linking kit



CMAss

Eye bolt stainless
steel, Stainless steel



HLC28

Right angle spiro
bevel gearbox, Up to
182Nm



CHM30

Worm and wheel gear
reducer, up to 28 Nm



VTA

Vari-Tork® slip
friction clutch, 0.53 to
1.32 Nm

Complementary products



DZY

Cylindrical stop, Steel



EZYSS

Stainless steel
cylindrical stop,
stainless steel



AZY

Cylindrical elasto
mount, Steel



BZY_SS

Stainless steel
cylindrical elasto
mount, Stainless steel