


- Large degree of deformation accepted thus absorbing large amounts of energy
- Energy absorbed gradually
- Material:
 - Core: Steel plates
 - Cylinder: Rubber
- Hardness NK 55-60 shore A
- Working temp: -40°C to +70°C

Uses

- Shock absorbing stop

Info.

- Not sold individually, please contact us for details
- Values for loads and rigidity are given as a guide only

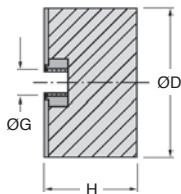

DISCOUNTS

Qty	1+	6+	20+	40+	100+	200+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	ØG	ØD	H	Compression		Stock*	Price each 1 to 5
				stiffness (N/mm)	Max. load (N)		
E-ZY4-10-10	M4	10	10	38	43	✓	1,16 €
E-ZY4-10-15	M4	10	15	-	-	✓	1,42 €
E-ZY4-15-15	M4	15	15	74	95	✓	1,49 €
E-ZY6-20-15	M6	20	15	138	170	✓	1,97 €
E-ZY6-20-20	M6	20	20	-	-	✓	2,04 €
E-ZY6-25-10	M6	25	10	-	-	✓	2,20 €
E-ZY6-25-20	M6	25	20	128	280	✓	2,82 €
E-ZY6-25-30	M6	25	30	80	280	✓	2,82 €
E-ZY8-30-15	M8	30	15	-	-	✓	2,73 €
E-ZY8-30-17	M8	30	17	-	-	✓	2,82 €
E-ZY8-30-20	M8	30	20	200	400	✓	3,17 €
E-ZY8-30-30	M8	30	30	120	400	✓	3,87 €
E-ZY8-40-30	M8	40	30	23	234	✓	4,76 €
E-ZY10-50-20	M10	50	20	680	1000	✓	6,03 €
E-ZY10-50-30	M10	50	30	425	1000	✓	6,58 €
E-ZY10-50-40	M10	50	40	-	-	✓	7,23 €
E-ZY10-50-50	M10	50	50	-	-	✓	8,45 €
E-ZY12-75-25	M12	75	25	2000	2300	✓	12,82 €
E-ZY12-75-55	M12	75	55	-	-	✓	19,07 €

*Depending on availability - Dimensions in mm

Our other products



PFM

Fixed levelling foot,
Flanged plate




BLHB30

Right angled gearbox,
bored shafts, up to
4.4 Nm



MPB

Hexagonal spacer,
Brass

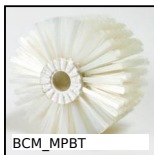

BCM_MPBT

Modular cylindrical
brush, PBT polyester
bristles



CLASS

Stainless steel
indexing handle -
female, Stainless steel



BFDdII

Locking pin for
bushes, Nickel-plated
steel




PM3

Worm and wheel set,
Non hardened steel



PRF_T

 Corner reinforcement,
Corner reinforcement




TBV

Manual lifting tables,
For vertical strokes -
Ø 16 mm column



SDCss

 Positioning sleeve for
indexing pin, For pin
Ø4 to Ø12



MLY

Bow shackle with eye
bolt, Steel



RTK

 
BoWex® curved tooth
gear coupling, Nylon
and steel

Complementary products



DZY

Cylindrical stop, Steel



EZYSS

Stainless steel
cylindrical stop,
stainless steel



AZY

Cylindrical elasto
mount, Steel



BZY_SS

Stainless steel
cylindrical elasto
mount, Stainless steel