

- Very high deformation allowing high levels of energy to be absorbed
- Progressive deformation
- Materials:
  - Core: Stainless steel plates (A2)
  - Head: Rubber
- **Hardness: NK 55-60 Shore A**
- Working temp: -40°C to +70°C

### Uses


- Shock absorbing stop

### Info.

- **Not sold individually, please contact us for details**
- Load and stiffness figures are given as a guide only



stainless steel

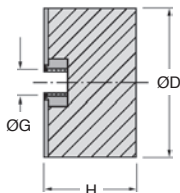

### DISCOUNTS

Qty	1+	6+	20+	40+	100+
Disc. List	-	-10%	-15%	-20%	On request

Part number	ØG	ØD	H	Compression Stiffness (N/mm)	Max load (N)	Stock*	Price each 1 to 5
E-ZY4-10-10/SS	M4	10	10	38	43	✓	2,54 €
E-ZY4-10-15/SS	M4	10	15	-	-	✓	1,98 €
E-ZY4-15-15/SS	M4	15	15	74	95	✓	2,16 €
E-ZY6-20-15/SS	M6	20	15	138	170	✓	2,87 €
E-ZY6-20-20/SS	M6	20	20	-	-	✓	3,00 €
E-ZY6-25-10/SS	M6	25	10	-	-	✓	3,15 €
E-ZY6-25-20/SS	M6	25	20	128	280	✓	3,38 €
E-ZY6-25-30/SS	M6	25	30	80	280	✓	4,00 €
E-ZY8-30-15/SS	M8	30	15	-	-	✓	4,00 €
E-ZY8-30-17/SS	M8	30	17	-	-	✓	4,00 €
E-ZY8-30-20/SS	M8	30	20	200	400	✓	4,46 €
E-ZY8-30-30/SS	M8	30	30	120	400	✓	5,42 €
E-ZY8-40-30/SS	M8	40	30	23	234	✓	6,66 €
E-ZY10-50-20/SS	M10	50	20	680	1000	✓	8,48 €
E-ZY10-50-30/SS	M10	50	30	425	1000	✓	9,22 €
E-ZY10-50-40/SS	M10	50	40	-	-	✓	10,06 €
E-ZY10-50-50/SS	M10	50	50	-	-	✓	11,89 €
E-ZY12-75-25/SS	M12	75	25	2000	2300	-	18,20 €
E-ZY12-75-55/SS	M12	75	55	-	-	-	26,69 €

\*Depending on availability - Dimensions in mm

## Our other products



BPPE  
Ball transfer unit push fit, Light



T39\_T49  
Extension spring in metre length steel, by the metre



UGPL  
Actuator guide kit, Long bearing



DFG  
Flat suction cup, nitrile



BOX-SHNA  
Hexagonal nut - DIN934, Box set of steel nuts



CHAuss  
Screwed hinge, 270°



CHT  
Asynchronous AC motor, 0.09kW



CHM110  
Worm and wheel gear reducer, up to 980 Nm



CLSCLP\_SS  
Clevis components, short version, Stainless steel - short



EMR  
Fast-locking knurled nut, Knurled



CTZYSS  
Stainless steel diabolo shaped elasto mount, Stainless steel



RPCtc  
Swivel castor with central hole, Steel - Polyamide

## Complementary products



EZY  
Cylindrical stop, Steel



DZYSS  
Stainless steel cylindrical stop, stainless steel