

- Very high deformation allowing high levels of energy to be absorbed
- Progressive deformation
- Materials:
 - Core: Stainless steel plates (A2)
 - Head: Rubber
- **Hardness: NK 55-60 Shore A**
- Working temp: -40°C to +70°C


Uses

- Shock absorbing stop

Info.

- **Not sold individually, please contact us for details**
- Load and stiffness figures are given as a guide only

stainless steel

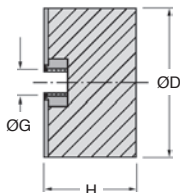

DISCOUNTS

Qty	1+	6+	20+	40+	100+
Disc. List	-	-10%	-15%	-20%	On request

Part number	ØG	ØD	H	Compression Stiffness (N/mm)	Max load (N)	Stock*	Price each 1 to 5
E-ZY4-10-10/SS	M4	10	10	38	43	✓	2,54 €
E-ZY4-10-15/SS	M4	10	15	-	-	✓	1,98 €
E-ZY4-15-15/SS	M4	15	15	74	95	✓	2,16 €
E-ZY6-20-15/SS	M6	20	15	138	170	✓	2,87 €
E-ZY6-20-20/SS	M6	20	20	-	-	✓	3,00 €
E-ZY6-25-10/SS	M6	25	10	-	-	✓	3,15 €
E-ZY6-25-20/SS	M6	25	20	128	280	✓	3,38 €
E-ZY6-25-30/SS	M6	25	30	80	280	✓	4,00 €
E-ZY8-30-15/SS	M8	30	15	-	-	✓	4,00 €
E-ZY8-30-17/SS	M8	30	17	-	-	✓	4,00 €
E-ZY8-30-20/SS	M8	30	20	200	400	✓	4,46 €
E-ZY8-30-30/SS	M8	30	30	120	400	✓	5,42 €
E-ZY8-40-30/SS	M8	40	30	23	234	✓	6,66 €
E-ZY10-50-20/SS	M10	50	20	680	1000	✓	8,48 €
E-ZY10-50-30/SS	M10	50	30	425	1000	✓	9,22 €
E-ZY10-50-40/SS	M10	50	40	-	-	✓	10,06 €
E-ZY10-50-50/SS	M10	50	50	-	-	✓	11,89 €
E-ZY12-75-25/SS	M12	75	25	2000	2300	-	18,20 €
E-ZY12-75-55/SS	M12	75	55	-	-	-	26,69 €

*Depending on availability - Dimensions in mm

Our other products



NPCR
Adjustable cell support, Adjustable



ASM
Cylindrical polymer bush, Food grade polymer



RURp
Fixed castor with plate, Polyurethane - Aluminium rim (Free running)



FBL6000_K13
Brush strip per meter PP fibres Ø0.2, Black striated polypropylene ...



CHAR7520
Spring hinge, screwed



SLB
Indexing plunger, stainless steel



BOXdhx
Boxed set of threaded dowel pins DIN7979D, Boxed set - extractable D...



SVR5
Screwjack with travelling nut, with moving nut




LFM2
Steel leadscrew, Medium carbon steel - 2 threads



SSDB
Stainless steel bevel gear, 2:1




H2
Crossed helical gear crossed axis at 90°, Machined plastic

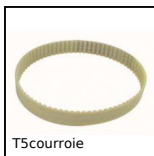

T5courroie
T type timing belt, T5 Steel cored polyurethane

 Complementary products



EZY
Cylindrical stop, Steel



DZYSS
Stainless steel cylindrical stop, stainless steel