

Multifunction display

New

F7-I

With internal sensor

- **Indicator with integrated sensor**
- Resolution: 0.1mm
- Max speed: 2.5m/s
- Display range: -99999 to 99999
- Display: LCD, character height 7.5mm
- Max distance between sensor and band: 1mm
- 3 button tactile keypad
- Sensor IP rating: IP57
- Indicator IP protection: IP54
- Working temperature: 0 to 50°C
- Relative humidity: 35-85%
- EMC protection: 2004/108/EC
- Power supply: ½AA 3.6V battery ((Lithium-thionyl chloride)
- Battery life: Approx 4 years
- Material:
 - Sensor: Black anodised aluminium
 - Display housing: Plastic

NEW!




View A



View B

Parameters

- Reset/preset, absolute/incremental, mm/inch/degrees, 3 origin points

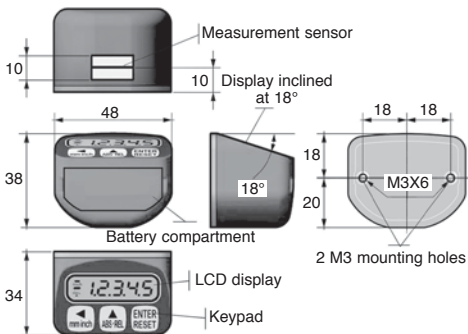

DISCOUNTS

Qty	1+	3+
Disc	List	On request

Part number	View	Price each 1 to 2
F7-I-A	A	325,12 €
F7-I-B	B	325,12 €

Dimensions in mm

Our other products



HLA28
Right angle spiro
bevel gearbox, Up to
182Nm



SHA
Handwheel without
handle, Polyamide



CABma
Swaging sleeve for
fitting cable, To crimp
a wire rope



SHW
Plain washer, A2
Stainless steel



BCM_MPBT
Modular cylindrical
brush, PBT polyester
bristles



PRF-P
Aluminium profile feet
support, For feet or
casters



DOG111
Motor-gearbox 12V
and 24V DC, from 1.5
to 6 Nm



J65
Spur gear coaxial
gearbox, from 0.80 to
2.95 Nm - In-line



ETGamme
Extension springs
DIN2097, DIN 2097



ADL_M
Male eye bolt
conforms to DIN580,
Stainless steel



WING
Manually tightened
wing nut, Stainless
steel DIN 314/315



PCF2
Conical flexible
mount, Oval base
plate

Complementary products



F7-SF-SM
Multifunction display,
Mounting bracket for
front mounting



F7-SN
Multifunction display,
Articulated support