

Multifunction display

New

F7-I

With internal sensor

- **Indicator with integrated sensor**
- Resolution: 0.1mm
- Max speed: 2.5m/s
- Display range: -99999 to 99999
- Display: LCD, character height 7.5mm
- Max distance between sensor and band: 1mm
- 3 button tactile keypad
- Sensor IP rating: IP57
- Indicator IP protection: IP54
- Working temperature: 0 to 50°C
- Relative humidity: 35-85%
- EMC protection: 2004/108/EC
- Power supply: ½AA 3.6V battery ((Lithium-thionyl chloride)
- Battery life: Approx 4 years
- Material:
 - Sensor: Black anodised aluminium
 - Display housing: Plastic

NEW!




View A



View B

Parameters

- Reset/preset, absolute/incremental, mm/inch/degrees, 3 origin points

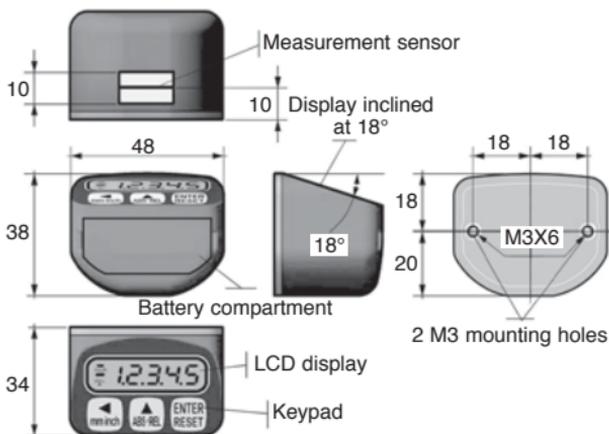

DISCOUNTS

Qty	1+	3+
Disc	List	On request

Part number	View	Price each 1 to 2
F7-I-A	A	325,12 €
F7-I-B	B	325,12 €

Dimensions in mm

Our other products



PTRSS
Idler chain sprocket,
For hostile
environments



RBNpl
Swivel castor with
double brake, Steel -
rubber



PR85
Articulated foot Ø83,
Ø 83



PW_PWG1
Wheel - precision
range, Bronze



MHX
Hexagonal threaded
sleeve, Hexagonal -
stainless steel



DOMI120
Domino 120
adjustable slide, Slide
DOMILINE 120 with
counter and han...



VAP
Magnetic stud with
central hole, With
central hole




CHAR7520
Spring hinge, screwed



VTLB
Three-lobed knob,
Thermoplastic / Brass
or stainless steel



SA_SAKH
Housing for linear
bearing, Closed - light
load

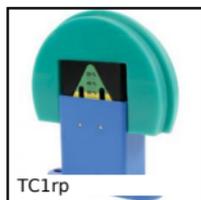

TC1rp
Automatic chain
tensioner, With 180°
guide



DBL820
Idler for slat top
chain, Ranges 820
and 815

Complementary products



F7-SF-SM
Multifunction display,
Mounting bracket for
front mounting



F7-SN
Multifunction display,
Articulated support