

# Multifunction display

New

## F7-I

### With internal sensor

- **Indicator with integrated sensor**
- Resolution: 0.1mm
- Max speed: 2.5m/s
- Display range: -99999 to 99999
- Display: LCD, character height 7.5mm
- Max distance between sensor and band: 1mm
- 3 button tactile keypad
- Sensor IP rating: IP57
- Indicator IP protection: IP54
- Working temperature: 0 to 50°C
- Relative humidity: 35-85%
- EMC protection: 2004/108/EC
- Power supply: ½AA 3.6V battery ((Lithium-thionyl chloride)
- Battery life: Approx 4 years
- Material:
  - Sensor: Black anodised aluminium
  - Display housing: Plastic

**NEW!**




View A



View B

## Parameters

- Reset/preset, absolute/incremental, mm/inch/degrees, 3 origin points

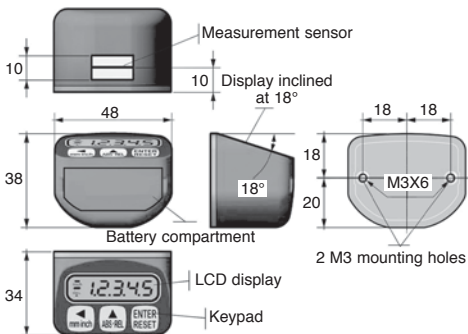

## DISCOUNTS

Qty	1+	3+
Disc	List	On request

Part number	View	Price each 1 to 2
F7-I-A	A	325,12 €
F7-I-B	B	325,12 €


Dimensions in mm

## Our other products



PSG2

Spur gear - precision range, Pre-hardened Steel 35NCD6

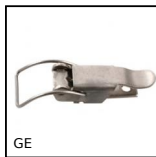

GE

Toggle latches, Standard



MAX26

Motor-gearbox 12V and 24V DC, from 0,075 to 0,6Nm



NPTR\_M

Adjustable cross clamp, Adjustable



SH0

Parallel axis helical gear, Steel 20NCD2



EBH

Cap nut Hygienic Design®, With collar



BABA

Ball pin lifting ring, Steel



HG5

Steel spur gear, Steel 20NCD2



 
RIMtce

Locking castor, with central hole



HDSS

Needle roller double universal joint - Stainless steel, Heavy



IN2

Internal gear, Machined plastic (delrin)



PTRSS

Idler chain sprocket, For hostile environments

## Complementary products



F7-SF-SM

Multifunction display, Mounting bracket for front mounting



F7-SN

Multifunction display, Articulated support