

# Multifunction display

New

## F7-I

## With internal sensor

- **Indicator with integrated sensor**
- Resolution: 0.1mm
- Max speed: 2.5m/s
- Display range: -99999 to 99999
- Display: LCD, character height 7.5mm
- Max distance between sensor and band: 1mm
- 3 button tactile keypad
- Sensor IP rating: IP57
- Indicator IP protection: IP54
- Working temperature: 0 to 50°C
- Relative humidity: 35-85%
- EMC protection: 2004/108/EC
- Power supply: ½AA 3.6V battery ((Lithium-thionyl chloride)
- Battery life: Approx 4 years
- Material:
  - Sensor: Black anodised aluminium
  - Display housing: Plastic

**NEW!**




View A



View B

### Parameters

- Reset/preset, absolute/incremental, mm/inch/degrees, 3 origin points

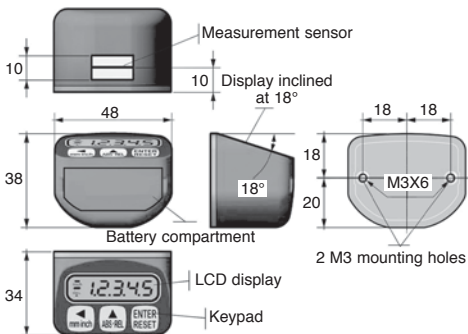

### DISCOUNTS

Qty	1+	3+
Disc	List	On request

Part number	View	Price each 1 to 2
F7-I-A	A	325,12 €
F7-I-B	B	325,12 €

Dimensions in mm

## Our other products



FBL4004\_K7

Brush strip per meter  
PA6 fibres Ø0.3 to  
Ø0.5, Black polyamide  
6 -...



T39\_T49

Extension spring in  
metre length stainless  
steel, by the metre



BLHM50

Right angled gearbox,  
double output shafts,  
up to 30 Nm



PLM-C

Cylindrical holding  
magnets, Cylindrical  
holding magnet



SLB

Indexing plunger,  
stainless steel



AC156-157

Strike for toggle latch,  
25.5mm



APB\_BOU

Protective cap, Safety  
cap



DOMI30

Accessories, Fixing kit



BPHfclip

Clip for ball transfer  
unit, Insert clip -  
Installing from above



CHAsb63

Hinge without pin,  
Polymer pin hinge



HSE-HSB

Hexagonal spacer,  
Steel



PRF\_BR

Clamp for aluminium  
profile, Clamp for  
profile

## Complementary products



F7-SF-SM

Multifunction display,  
Mounting bracket for  
front mounting



F7-SN

Multifunction display,  
Articulated support