

Multifunction display

New

F7-I

With internal sensor

- **Indicator with integrated sensor**
- Resolution: 0.1mm
- Max speed: 2.5m/s
- Display range: -99999 to 99999
- Display: LCD, character height 7.5mm
- Max distance between sensor and band: 1mm
- 3 button tactile keypad
- Sensor IP rating: IP57
- Indicator IP protection: IP54
- Working temperature: 0 to 50°C
- Relative humidity: 35-85%
- EMC protection: 2004/108/EC
- Power supply: ½AA 3.6V battery ((Lithium-thionyl chloride)
- Battery life: Approx 4 years
- Material:
 - Sensor: Black anodised aluminium
 - Display housing: Plastic

NEW!




View A



View B

Parameters

- Reset/preset, absolute/incremental, mm/inch/degrees, 3 origin points

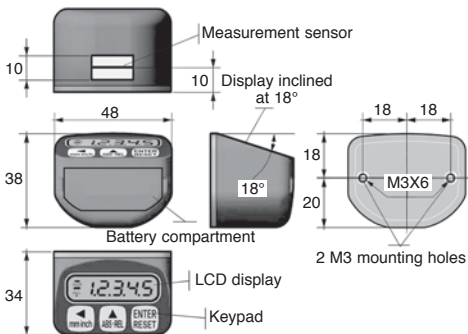

DISCOUNTS

Qty	1+	3+
Disc	List	On request

Part number	View	Price each 1 to 2
F7-I-A	A	325,12 €
F7-I-B	B	325,12 €

Dimensions in mm

Our other products



OP3_14_06
Reducing sleeve for
OP indicators,
Reduction socket



EPRC
High helix leadscrew,
Cylindrical nut - up to
40mm per rotation



VDSQC8
Sliding lock
adjustment system,
Blocking wedge



PPOss
Pad eye on mounting
plate oval, Stainless
steel



CHT
Asynchronous AC
Motor, 0.55 to 1.1kW



E20
Right angle helical
reducers, from 0.60 to
3.84 Nm



BLHM70
Right angled gearbox,
up to 128 Nm



SLHVlok
Horizontal toggle
clamp, Horizontal
toggle clamp / vertical
foot



RPP
Connecting plate for
RPP type timing belts,



SCR
Suction cup threaded
insert, Insert for



CLLCLLP
Clevis components,
long version, Steel -



GD01
Double universal joint,
Standard duty

Complementary products



F7-SF-SM
Multifunction display,
Mounting bracket for
front mounting



F7-SN
Multifunction display,
Articulated support