

Multifunction display

New

F7-I

With internal sensor

- **Indicator with integrated sensor**
- Resolution: 0.1mm
- Max speed: 2.5m/s
- Display range: -99999 to 99999
- Display: LCD, character height 7.5mm
- Max distance between sensor and band: 1mm
- 3 button tactile keypad
- Sensor IP rating: IP57
- Indicator IP protection: IP54
- Working temperature: 0 to 50°C
- Relative humidity: 35-85%
- EMC protection: 2004/108/EC
- Power supply: ½AA 3.6V battery ((Lithium-thionyl chloride)
- Battery life: Approx 4 years
- Material:
 - Sensor: Black anodised aluminium
 - Display housing: Plastic

NEW!




View A



View B

Parameters

- Reset/preset, absolute/incremental, mm/inch/degrees, 3 origin points

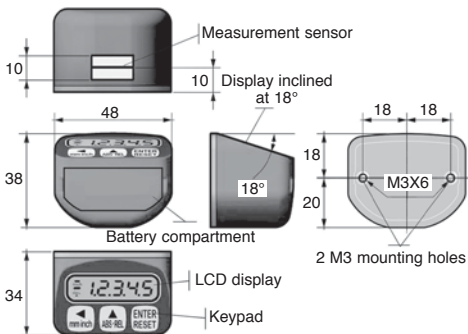

DISCOUNTS

Qty	1+	3+
Disc	List	On request

Part number	View	Price each 1 to 2
F7-I-A	A	325,12 €
F7-I-B	B	325,12 €

Dimensions in mm

Our other products



M1

Worm and wheel set,
Hardened steel



UGH32

H Type Guide units,
For Ø32 actuators



M0

Worm and wheel set,
Unhardened steel



DOMI30

Domino 30 adjustable
slide, Slide DOMILINE
30



GPBSS

Threaded spherical
knob, Aluminium



PRF_BM

Base support plate for
aluminium profile,
Central base fixation



DCG

Suction cup, 2.5
bellows, silicon



CHA1056-UPA

Molded polyamide
face-mounted hinge,
Black polyamide



CHAGC-AL

Screw-in garnet
hinge, Screw-on




PSG08S

Spur gear - precision
range, Stainless steel
316



LC

 Friction clutch, 190 to
1800 Nm



M1

Worm and wheel set,
Machined plastic
(delrin)

Complementary products



F7-SF-SM

Multifunction display,
Mounting bracket for
front mounting



F7-SN

Multifunction display,
Articulated support