

- **Indicator with an external sensor**
- Resolution: 0.1mm
- Max speed: 2.5m/s
- Display range: -99999 to 99999
- Display: LCD, character height 7.5mm
- Max distance between sensor and band: 1mm
- 3 button tactile keypad
- Sensor IP rating: IP57
- Indicator IP protection: IP54
- Working temperature: 0 to 50°C
- Relative humidity: 35-85%
- EMC protection: 2004/108/EC
- Power supply: ½AA 3.6B battery (Lithium-thionyl chloride)
- Battery life: Approx 4 years
- Material:

Sensor: Black anodised aluminium


Display housing: Plastic

NEW!



Parameters

- Reset/preset, absolute/incremental, mm/inch/degrees, 3 origin points

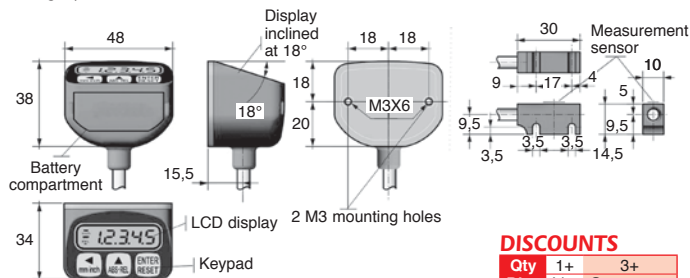

DISCOUNTS

Qty	1+	3+
Disc	List	On request

Part number	View	Length of sensor (mm)	Price each 1 to 2
F7-E-A-500	A	500	378,94 €
F7-E-A-1000	A	1000	378,94 €
F7-E-A-3000	A	3000	401,27 €
F7-E-A-5000	A	5000	423,60 €
F7-E-B-500	B	500	378,94 €
F7-E-B-1000	B	1000	378,94 €
F7-E-B-3000	B	3000	401,27 €
F7-E-B-5000	B	5000	423,60 €

Dimensions in mm

Our other products



RAGFLOWsupport

Floway2® Roller track accessory, Roller track support



MEB

Moulded plastic bevel gear (nylon), 1:1



VPR

Wing screw Hygienic Usit®, Stainless steel



RAGFLOW

Floway2® roller track, Roller track



 
BFD

Locking pin for bush, +180°C




BSPM

Miniature ballscrew, Nut+rolled ballscrew



B

 Steel bevel gear, 1:1




TBV

Manual lifting tables, 20kg



HLUMss

 Revolving handle for handwheel, Stainless steel 316



RPP14

RPP heavy duty timing belt, RPP14



UCP

Cast iron pillow block bearing, Cast iron



PTA100ssEB

Articulated foot with sheet metal base Ø100, Articulated foot

Complementary products



F7-P-AM

Multifunction display, Magnetic band



F7-P-AM

Multifunction display, Magnetic ring