

Multifunction display

New

F7-I

With internal sensor

- **Indicator with integrated sensor**
- Resolution: 0.1mm
- Max speed: 2.5m/s
- Display range: -99999 to 99999
- Display: LCD, character height 7.5mm
- Max distance between sensor and band: 1mm
- 3 button tactile keypad
- Sensor IP rating: IP57
- Indicator IP protection: IP54
- Working temperature: 0 to 50°C
- Relative humidity: 35-85%
- EMC protection: 2004/108/EC
- Power supply: ½AA 3.6V battery ((Lithium-thionyl chloride)
- Battery life: Approx 4 years
- Material:
 - Sensor: Black anodised aluminium
 - Display housing: Plastic

NEW!




View A



View B

Parameters

- Reset/preset, absolute/incremental, mm/inch/degrees, 3 origin points

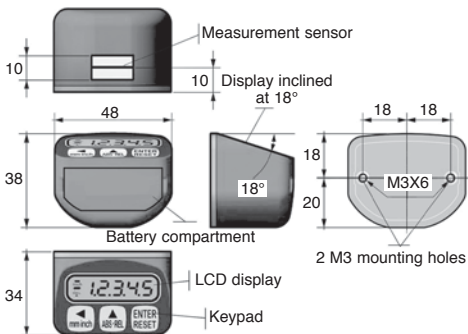


DISCOUNTS

Qty	1+	3+
Disc	List	On request

Part number	View	Price each 1 to 2
F7-I-A	A	325,12 €
F7-I-B	B	325,12 €

Dimensions in mm

 Our other products



KS

Keysteel, Stainless steel - Keystock



BLH70

Right angled gearbox, from 26 to 128 Nm



CTZY

Diabolo shaped elasto mount, Steel



SVR15

Screwjack with travelling nut, with moving nut



HDSS

Needle roller double universal joint - Stainless steel, Heavy duty



PW_PWG3

Worm - precision range, Stainless steel



GG2

Ground spur gear, Heat treated steel



SH0

Parallel axis helical gear, Machined plastic (delrin)



GAL22

Conveyor wheel, Zinc plated steel



M1

Worm and wheel set, Bronze



RHTtcss

High Temperature Castor, up to 200kg



SDB

Locking bolt support bracket, Mounting holes at 90° to locating bolt

Complementary products



F7-SF-SM

Multifunction display, Mounting bracket for front mounting



F7-SN

Multifunction display, Articulated support