

Swivel feet without anti-slip plate

Swiveling range +/-10°



- Material:

Base plastic PA glass fibre reinforced

Spindle steel zinc plated

Assembly

- By forceful interlocking (mallet or press)

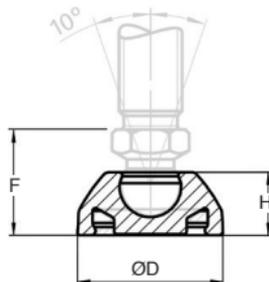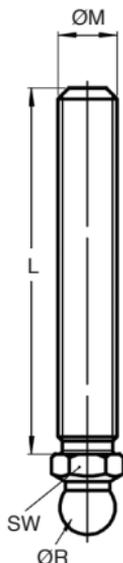

DISCOUNTS

Qty	1+	10+	20+	40+
Disc. Net	-	-10%	-15%	On request

Part number	ØD	ØM	L	ØR	SW	F	H	Max load (N)	Stock*	Price each 1 to 9
FAD25-6-20	24	M6	20	10	10	17,5	10,4	1000	✓	2,84 €
FAD25-6-40	24	M6	40	10	10	17,5	10,4	1000	✓	2,93 €
FAD25-8-20	24	M8	20	10	13	17,5	10,4	2000	-	3,09 €
FAD25-10-20	24	M10	20	10	13	17,5	10,4	2000	✓	3,03 €
FAD25-10-40	24	M10	40	10	13	17,5	10,4	2000	✓	3,25 €
FAD25-10-60	24	M10	60	10	13	17,5	10,4	2000	✓	3,48 €
FAD40-6-20	39	M6	20	10	10	17,5	10,4	1000	✓	2,93 €
FAD40-8-20	39	M8	20	10	13	17,5	10,4	2500	✓	3,19 €
FAD40-10-40	39	M10	40	10	13	17,5	10,4	4000	✓	3,35 €
FAD40-10-60	39	M10	60	10	13	17,5	10,4	4000	✓	3,58 €
FAD50-6-15	49	M6	15	15	14	29,5	18,0	1000	✓	4,97 €
FAD50-6-30	49	M6	30	15	14	29,5	18,0	1000	-	6,71 €
FAD50-8-25	49	M8	25	15	14	29,5	18,0	3500	-	4,84 €
FAD50-10-45	49	M10	45	15	14	29,5	18,0	4700	✓	5,22 €
FAD50-12-45	49	M12	45	15	14	29,5	18,0	7700	✓	5,61 €

* Depending on availability - All dimensions in mm