

New

Threaded swivel feet

Max load: up to 7700N**FAD****Swivel feet without anti-slip plate**

Swiveling range +/-10°

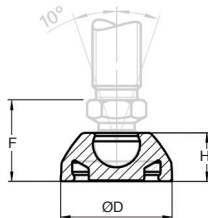
- Material:

Base plastic PA glass fibre reinforced

Spindle steel zinc plated

Assembly

- By forceful interlocking (mallet or press)

**DISCOUNTS**

Qty	1+	10+	20+	40+
Disc.	Net	-10%	-15%	On request

Part number	ØD	ØM	L	ØR	SW	F	H	Max load (N)	Stock*	Price each 1 to 9
									✓	
FAD25-6-20	24	M6	20	10	10	17,5	10,4	1000	✓	2,70 €
FAD25-6-40	24	M6	40	10	10	17,5	10,4	1000	✓	2,79 €
FAD25-8-20	24	M8	20	10	13	17,5	10,4	2000	-	2,94 €
FAD25-10-20	24	M10	20	10	13	17,5	10,4	2000	-	2,88 €
FAD25-10-40	24	M10	40	10	13	17,5	10,4	2000	✓	3,10 €
FAD25-10-60	24	M10	60	10	13	17,5	10,4	2000	✓	3,31 €
FAD40-6-20	39	M6	20	10	10	17,5	10,4	1000	✓	2,79 €
FAD40-8-20	39	M8	20	10	13	17,5	10,4	2500	✓	3,04 €
FAD40-10-40	39	M10	40	10	13	17,5	10,4	4000	✓	3,19 €
FAD40-10-60	39	M10	60	10	13	17,5	10,4	4000	✓	3,40 €
FAD50-6-15	49	M6	15	15	14	29,5	18,0	1000	-	4,72 €
FAD50-6-30	49	M6	30	15	14	29,5	18,0	1000	-	6,38 €
FAD50-8-25	49	M8	25	15	14	29,5	18,0	3500	-	4,60 €
FAD50-10-45	49	M10	45	15	14	29,5	18,0	4700	✓	4,97 €
FAD50-12-45	49	M12	45	15	14	29,5	18,0	7700	✓	5,33 €

* Depending on availability - All dimensions in mm

Our other products



RUR
Wheel, Polyurethane -
Aluminium rim (Free
running)



NPTR
Adjustable cross
clamp, Adjustable



HG8-ECO
Eco range Spur gear,
Steel C45



DIV_SS
Stainless steel locking
bolt, With grip -
Stainless steel



BSM_LOK
Long-Lok spring
plunger with internal
hexagonal socket,
LONG-LOK - s...



RAGFLOW
Floway2® roller track,
Roller track



CHT
Asynchronous AC
Motor 1.1 to 1.85kW,
1.1 to 1.85kW



ACL-PR
Joining plate for
aluminium profile,
Right angled
connection



RPP5
RPP heavy duty
timing belt, RPP5



BIMSS
Indexing plunger mini,
miniature - Stainless



G01
Single universal joint,
Normal duty



EPE
Wing nuts Hygienic
Design®, Narrow

Complementary products



PR40
Articulated foot Ø40,
Ø 40