

New

Threaded swivel feet

Max load: up to 7700N**FAD****Swivel feet without anti-slip plate**Swiveling range $\pm 10^\circ$


- Material:

Base plastic PA glass fibre reinforced

Spindle steel zinc plated

Assembly

- By forceful interlocking (mallet or press)

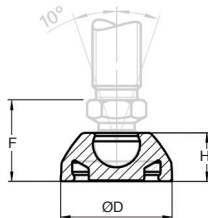
**DISCOUNTS**

Qty	1+	10+	20+	40+
Disc.	Net	-10%	-15%	On request

Part number	ØD	ØM	L	ØR	SW	F	H	Max load (N)	Stock*	Price each 1 to 9
									✓	
FAD25-6-20	24	M6	20	10	10	17,5	10,4	1000	✓	2,70 €
FAD25-6-40	24	M6	40	10	10	17,5	10,4	1000	✓	2,79 €
FAD25-8-20	24	M8	20	10	13	17,5	10,4	2000	-	2,94 €
FAD25-10-20	24	M10	20	10	13	17,5	10,4	2000	-	2,88 €
FAD25-10-40	24	M10	40	10	13	17,5	10,4	2000	✓	3,10 €
FAD25-10-60	24	M10	60	10	13	17,5	10,4	2000	✓	3,31 €
FAD40-6-20	39	M6	20	10	10	17,5	10,4	1000	✓	2,79 €
FAD40-8-20	39	M8	20	10	13	17,5	10,4	2500	✓	3,04 €
FAD40-10-40	39	M10	40	10	13	17,5	10,4	4000	✓	3,19 €
FAD40-10-60	39	M10	60	10	13	17,5	10,4	4000	✓	3,40 €
FAD50-6-15	49	M6	15	15	14	29,5	18,0	1000	-	4,72 €
FAD50-6-30	49	M6	30	15	14	29,5	18,0	1000	-	6,38 €
FAD50-8-25	49	M8	25	15	14	29,5	18,0	3500	-	4,60 €
FAD50-10-45	49	M10	45	15	14	29,5	18,0	4700	✓	4,97 €
FAD50-12-45	49	M12	45	15	14	29,5	18,0	7700	✓	5,33 €

* Depending on availability - All dimensions in mm

Our other products

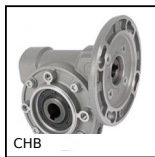

CHB

Worm and wheel gear reducer, up to 22 Nm



BOX-TOR-INCH

Box set of Nitrile O-rings in inch NBR90Sh A, For fasteners and fittings



RBGtc

Swivel castor with central hole, Steel - grey rubber - with double ball



BLHM40

Right angled gearbox, double output shafts, up to 10.3 Nm



ZG0

Plastic spur gear, Machined plastic (delrin)



Q6

Deep groove ball bearing, Steel



 
PTKss

Foot for the food industry, Stainless steel - 3-A standard



ADL_F

Female eye bolt conforms to DIN582, Stainless steel



M1

Worm and wheel set, Machined plastic



UCP

Cast iron pillow block bearing, Cast iron



PRF_GAL

Roller for aluminium profile, Fixing kit for



PSP

Support profile, Panel support

Complementary products



PR40

Articulated foot Ø40, Ø 40