

Sealing brush strips

FBL

Advantages and applications


Advantages



- No wastage, only the length required is removed from the roll.
- Reduced storage/transport space, each box contains 25 metres.



- Special scissors allow the strip to be cut to the required length.

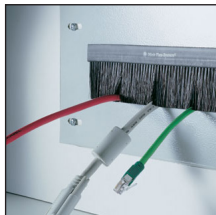


- Flexible in terms of positioning and fitting.


Applications



- Splash guard for wheel arches on a lorry

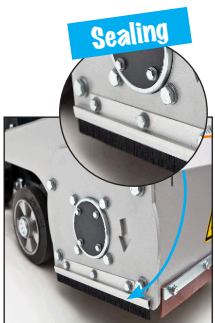

- Waterproofness of floor cleaning machines

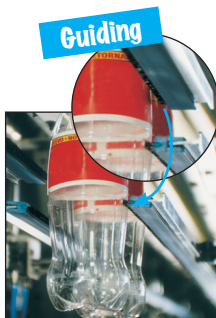

- Guiding PET bottles

Brush strip **horsehair fibres** Ø0.2

For ensuring a seal up to 125°C

FBL6000
FBL6001

Brush strip to cut to desired length.

Uses


- Sealing
- Cable entries
- Guiding parts

Materials


- **Fibres:** Horsehair. No risk of static charge, excellent for dusting, brushing, sealing and for applying liquids (can be used as paintbrush)
 - **Support:** Thermoplastic rubber. Good UV and ozone resistance. Practically unaffected by most chemicals.
- Maximum temperature: +150°C
Working temperature: -40 to +125°C

Info.

- Sold in 5 metre lengths.
 - Maximum length of a single brush is 25 metres.
 - Special scissors for cutting to length
- FBL-TOOL**

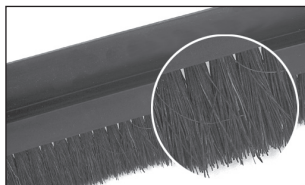

Horsehair fibres

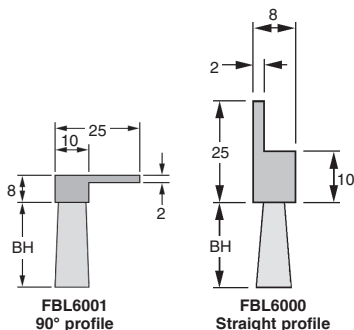

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-10%	On request

Part number	Bristle diameter (mm)	BH	Length	Stock*		Price each	
				Straight profile	90° profile	Straight profile	90° profile
Black horsehair							
FBL6000-K19	0,2	15	5m	✓	-	63,64 €	-
FBL6000-K20	0,2	20	5m	✓	-	68,86 €	-
FBL6000-K21	FBL6001-K21	0,2	25	5m	-	✓	74,33 € 74,33 €
FBL6000-K23	FBL6001-K23	0,2	40	5m	✓	✓	92,79 € 92,79 €
FBL6000-K24	FBL6001-K24	0,2	50	5m	✓	✓	108,10 € 108,10 €

Tools

FBL-TOOL	Cutting scissors	193,51 €
----------	------------------	----------

*Depending on availability - Dimensions in mm

Brush strip PA6 fibres Ø0.2 to Ø0.3 Stock

FBL6000 FBL6001

For ensuring an internal seal

Brush strip to cut to desired length.

Uses


- Sealing
- Cable entries
- Guiding parts

Materials

- **Fibres:** Polyamide PA6. Standard material for brushes used for cleaning, transporting, guiding or sealing moving pieces.
- **Working temperature:** -20 to 100°C
- **Support:** Thermoplastic rubber. Good UV and ozone resistance. Practically unaffected by most chemicals.
- **Working temperature:** -40 to +125°C

Info.

- Sold in 5 metre lengths.
 - Maximum length of a single brush is 25 metres.
 - Special scissors for cutting to length
- FBL-TOOL**

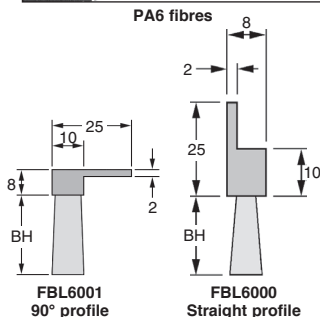

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-10%	On request

Part number		Bristle diameter (mm)	BH	Length	Stock*		Price each	
Straight profile	90° profile				Straight profile	90° profile	Straight profile	90° profile
Black Polyamide 6 (PA6) fibres								
FBL6000-K1	FBL6001-K1	0,2	10	5m	✓	✓	48,53 €	48,53 €
FBL6000-K2	FBL6001-K2	0,2	15	5m	✓	✓	49,78 €	49,78 €
FBL6000-K3	FBL6001-K3	0,2	20	5m	✓	✓	51,26 €	51,26 €
FBL6000-K4	-	0,2	25	5m	✓	-	52,74 €	-
FBL6000-K5	FBL6001-K5	0,2	30	5m	✓	✓	54,21 €	54,21 €
FBL6000-K7	-	0,3	15	5m	✓	-	49,78 €	-
FBL6000-K8	-	0,3	20	5m	✓	-	51,26 €	-
FBL6000-K9	-	0,3	25	5m	✓	-	52,74 €	-
FBL6000-K10	-	0,3	30	5m	✓	-	54,21 €	-
FBL6000-K11	-	0,3	40	5m	✓	-	57,33 €	-
FBL6000-K12	-	0,3	50	5m	✓	-	60,29 €	-

Tools

FBL-TOOL	Cutting scissors	193,51 €
----------	------------------	----------

*Depending on availability - Dimensions in mm



Brush strip PA6 fibres Ø0.3 to Ø0.5

For ensuring an internal seal

FBL4004
FBL4005

Brush strip to cut to desired length.

Uses

- Sealing
- Cable entries
- Guiding parts

Materials


- **Fibres:** Polyamide PA6. Standard material for brushes used for cleaning, transporting, guiding or sealing moving pieces.
Working temperature: -20 to 100°C
- **Support:** Thermoplastic rubber. Good UV and ozone resistance. Practically unaffected by most chemicals.
Working temperature: -40 to +125°C

Info.

- Sold in 5 metre lengths.
- Maximum length of a single brush is 25 metres.
- Special scissors for cutting to length
FBL-TOOL



PA6 fibres

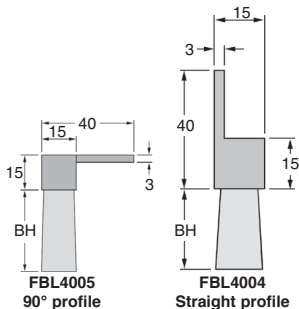

FBL4005
90° profile

FBL4004
Straight profile

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-10%	On request

Part number	Bristle diameter (mm)	BH	Length	Stock*		Price each		
				Straight profile	90° profile	Straight profile	90° profile	
Black Polyamide 6 (PA6) fibres								
FBL4004-K8	-	0,3	20	5m	✓	-	140,75 €	-
FBL4004-K9	-	0,3	30	5m	✓	-	147,61 €	-
FBL4004-K13	-	0,5	30	5m	✓	-	147,61 €	-
FBL4004-K14	-	0,5	40	5m	✓	-	154,69 €	-
FBL4004-K15	-	0,5	50	5m	✓	-	161,80 €	-
FBL4004-K18	FBL4005-K15	0,5	80	5m	✓	✓	193,81 €	193,81 €

Tools

FBL-TOOL	Cutting scissors	193,51 €
----------	------------------	----------

*Depending on availability - Dimensions in mm

Brush strip **PP fibres** Ø0.2



FBL6000
FBL6001

For ensuring an external seal

Brush strip to cut to desired length.

Uses

- Sealing
- Cable entries
- Guiding parts


Materials

- **Fibres:** Polypropylene. No water absorption, good resistance to chemicals... Working temperature: -20 (occasional) to 80°C
- **Support:** Thermoplastic rubber. Good UV and ozone resistance. Practically unaffected by most chemicals. Working temperature: -40 to +125°C

Info.

- Sold in 5 metre lengths.
- Maximum length of a single brush is 25 metres.
- Special scissors for cutting to length

FBL-TOOL

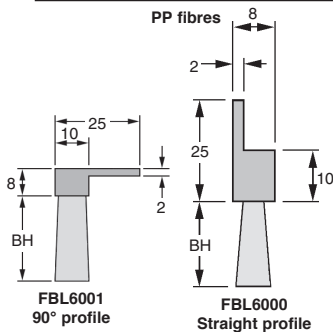

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-10%	On request

Part number	Straight profile	90° profile	Bristle diameter (mm)	BH	Length	Stock*		Price each	
						Straight profile	90° profile	Straight profile	90° profile

Black horsehair

FBL6000-K13	FBL6001-K13	0,2	10	5m	✓	✓	44,56 €	44,56 €
FBL6000-K14	FBL6001-K14	0,2	15	5m	✓	✓	44,98 €	44,98 €
FBL6000-K15	FBL6001-K15	0,2	20	5m	✓	✓	45,38 €	45,38 €
FBL6000-K17	FBL6001-K17	0,2	30	5m	✓	-	46,66 €	46,66 €
FBL6000-K18	FBL6001-K18	0,2	40	5m	✓	✓	47,69 €	47,69 €

Tools

FBL-TOOL	Cutting scissors	193,51 €
----------	------------------	----------

*Depending on availability - Dimensions in mm

For ensuring an external seal

FBL4004
FBL4005

Brush strip to cut to desired length.

Uses

- Sealing
- Cable entries
- Guiding parts

Materials

- **Fibres:** Polypropylene. No water absorption, good resistance to chemicals...
Working temperature: -20 (occasional) to 80°C
- **Support:** Thermoplastic rubber.
Good UV and ozone resistance. Practically unaffected by most chemicals.
Working temperature: -40 to +125°C


Info.

- Sold in 5 metre lengths.
- Maximum length of a single brush is 25 metres.
- Special scissors for cutting to length

FBL-TOOL



PP fibres

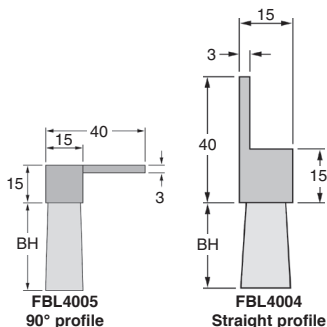

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-10%	On request


Part number	Bristle diameter (mm)	BH	Length	Stock*		Price each	
				Straight profile	90° profile	Straight profile	90° profile
Black Polyamide 6 (PA6) fibres							
FBL4004-K34	-	0,3	30	5m	✓	-	130,13 €
FBL4004-K35	-	0,3	40	5m	✓	-	132,49 €
FBL4004-K36	FBL4005-K31	0,3	50	5m	✓	✓	134,99 €
FBL4004-K37	FBL4005-K32	0,3	60	5m	✓	-	137,47 €
FBL4004-K38	-	0,3	70	5m	✓	-	151,08 €

Tools

FBL-TOOL	Cutting scissors	193,51 €
----------	------------------	----------

*Depending on availability - Dimensions in mm

Our other products

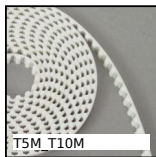

T5M T10M
T type timing belt per metre, T5 Steel cored polyurethane



GE1006
Elastic ringed latch, Hooks into a slot



PCS50SS
Chain sprocket - Stainless steel, 12.7mm (DIN 08B-1)



EHD12
Internal epicyclic servo reducers, from 60 to 140 Nm




UTKpwrr
V shaped channel UtiliTrak®, V rail



CHMR75
Worm and wheel gear reducer, up to 298 Nm



BPTR
End cap for round tube, Standard

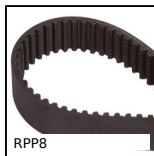

RPP8
RPP heavy duty timing belt, RPP8



PDR-RD
Mounting feet with integrated castors,



PW_PWG2
Worm - precision range, Steel



ESCON
Speed controller 5A accessories, Kit of 4



PM4
Worm and wheel set, Hardened steel

Complementary products



STRIP
Sealing brush strip, 3m length



STRIPF
Sealing brush strip, 1m length

Our other products



PO

Pull handle - Multi-sector, Tapped recessed insert



BOX-NINA

Self locking nut - DIN985, Box set of steel nuts



RTE

Rotex®, jaw coupling, Aluminium



PSG15

Spur gear - precision range, Pre-hardened Steel 35NCD6



ACM_AZ

Mounting bracket for bonnet fastener, Hook



ZHG5

Plastic spur gear, Machined plastic (delrin)



AT5-10ECO

AT type timing pulley, Economy range - AT5 aluminium



VPR

Wing screw Hygienic Usit®, Stainless steel



PPG

Indexing plunger with flange, With horizontal mounting flange



DB_ECO

Eco. range steel bevel gear, 2:1



YG3

HEAVY DUTY spur gear, Steel 35NCD6



SVG

Adjustable latch clamp with strike plate, Stroke from 106,7mm to 121...

Complementary products



STRIP

Sealing brush strip, 3m length



STRIPF

Sealing brush strip, 1m length