

Sealing brush strips

FBL

Advantages and applications

Advantages



- No wastage, only the length required is removed from the roll.
- Reduced storage/transport space, each box contains 25 metres.



- Special scissors allow the strip to be cut to the required length.




- Flexible in terms of positioning and fitting.


Applications



- Splash guard for wheel arches on a lorry

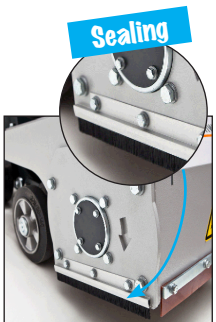

- Waterproofness of floor cleaning machines

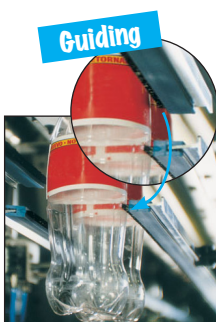

- Guiding PET bottles

Brush strip **horsehair fibres** Ø0.2

For ensuring a seal up to 125°C

FBL6000
FBL6001

Brush strip to cut to desired length.

Uses


- Sealing
- Cable entries
- Guiding parts

Materials


- **Fibres:** Horsehair. No risk of static charge, excellent for dusting, brushing, sealing and for applying liquids (can be used as paintbrush)
 - **Support:** Thermoplastic rubber. Good UV and ozone resistance. Practically unaffected by most chemicals.
- Maximum temperature: +150°C
Working temperature: -40 to +125°C

Info.

- Sold in 5 metre lengths.
 - Maximum length of a single brush is 25 metres.
 - Special scissors for cutting to length
- FBL-TOOL**

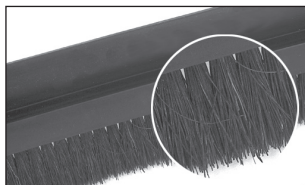

Horsehair fibres

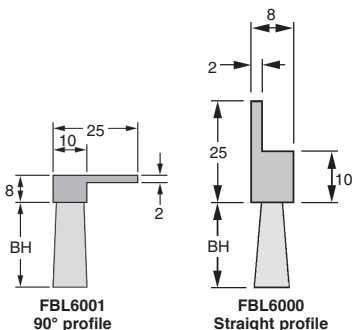

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-10%	On request

Part number	Bristle diameter (mm)	BH	Length	Price each	
				Straight profile	90° profile
FBL6000-K19	-	0,2	15	5m	63,64 €
FBL6000-K20	-	0,2	20	5m	68,86 €
FBL6000-K21	FBL6001-K21	0,2	25	5m	74,33 €
FBL6000-K23	FBL6001-K23	0,2	40	5m	92,79 €
FBL6000-K24	FBL6001-K24	0,2	50	5m	108,10 €

Tools

FBL-TOOL	Cutting scissors	193,51 €
----------	------------------	----------

*Depending on availability - Dimensions in mm

Brush strip PA6 fibres Ø0.2 to Ø0.3 Stock

FBL6000 FBL6001

For ensuring an internal seal

Brush strip to cut to desired length.

Uses


- Sealing
- Cable entries
- Guiding parts

Materials

- **Fibres:** Polyamide PA6. Standard material for brushes used for cleaning, transporting, guiding or sealing moving pieces.
- **Working temperature:** -20 to 100°C
- **Support:** Thermoplastic rubber. Good UV and ozone resistance. Practically unaffected by most chemicals.
- **Working temperature:** -40 to +125°C

Info.

- Sold in 5 metre lengths.
 - Maximum length of a single brush is 25 metres.
 - Special scissors for cutting to length
- FBL-TOOL**

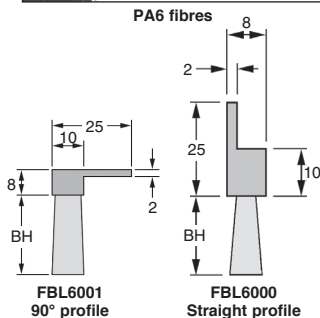

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-10%	On request

Part number		Bristle diameter (mm)	BH	Length	Stock*		Price each	
Straight profile	90° profile				Straight profile	90° profile	Straight profile	90° profile
Black Polyamide 6 (PA6) fibres								
FBL6000-K1	FBL6001-K1	0,2	10	5m	✓	✓	48,53 €	48,53 €
FBL6000-K2	FBL6001-K2	0,2	15	5m	✓	✓	49,78 €	49,78 €
FBL6000-K3	FBL6001-K3	0,2	20	5m	✓	✓	51,26 €	51,26 €
FBL6000-K4	-	0,2	25	5m	✓	-	52,74 €	-
FBL6000-K5	FBL6001-K5	0,2	30	5m	✓	✓	54,21 €	54,21 €
FBL6000-K7	-	0,3	15	5m	✓	-	49,78 €	-
FBL6000-K8	-	0,3	20	5m	✓	-	51,26 €	-
FBL6000-K9	-	0,3	25	5m	✓	-	52,74 €	-
FBL6000-K10	-	0,3	30	5m	✓	-	54,21 €	-
FBL6000-K11	-	0,3	40	5m	✓	-	57,33 €	-
FBL6000-K12	-	0,3	50	5m	✓	-	60,29 €	-

Tools

FBL-TOOL	Cutting scissors	193,51 €
----------	------------------	----------

*Depending on availability - Dimensions in mm



Brush strip PA6 fibres Ø0.3 to Ø0.5

For ensuring an internal seal

FBL4004
FBL4005

Brush strip to cut to desired length.

Uses

- Sealing
- Cable entries
- Guiding parts

Materials


- **Fibres:** Polyamide PA6. Standard material for brushes used for cleaning, transporting, guiding or sealing moving pieces.
Working temperature: -20 to 100°C
- **Support:** Thermoplastic rubber. Good UV and ozone resistance. Practically unaffected by most chemicals.
Working temperature: -40 to +125°C

Info.

- Sold in 5 metre lengths.
- Maximum length of a single brush is 25 metres.
- Special scissors for cutting to length
FBL-TOOL



PA6 fibres

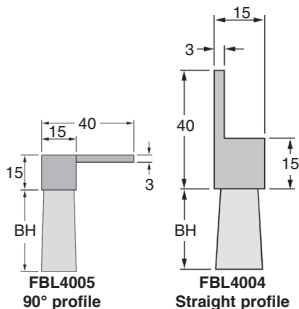

FBL4005
90° profile

FBL4004
Straight profile

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-10%	On request

Part number	Bristle diameter (mm)	BH	Length	Stock*		Price each		
				Straight profile	90° profile	Straight profile	90° profile	
Black Polyamide 6 (PA6) fibres								
FBL4004-K8	-	0,3	20	5m	✓	-	140,75 €	-
FBL4004-K9	-	0,3	30	5m	✓	-	147,61 €	-
FBL4004-K13	-	0,5	30	5m	✓	-	147,61 €	-
FBL4004-K14	-	0,5	40	5m	✓	-	154,69 €	-
FBL4004-K15	-	0,5	50	5m	✓	-	161,80 €	-
FBL4004-K18	FBL4005-K15	0,5	80	5m	✓	✓	193,81 €	193,81 €

Tools

FBL-TOOL	Cutting scissors	193,51 €
----------	------------------	----------

*Depending on availability - Dimensions in mm

Brush strip **PP fibres** Ø0.2



FBL6000 FBL6001

For ensuring an external seal

Brush strip to cut to desired length.

Uses

- Sealing
- Cable entries
- Guiding parts


Materials

- **Fibres:** Polypropylene. No water absorption, good resistance to chemicals... Working temperature: -20 (occasional) to 80°C
- **Support:** Thermoplastic rubber. Good UV and ozone resistance. Practically unaffected by most chemicals. Working temperature: -40 to +125°C

Info.

- Sold in 5 metre lengths.
- Maximum length of a single brush is 25 metres.
- Special scissors for cutting to length

FBL-TOOL

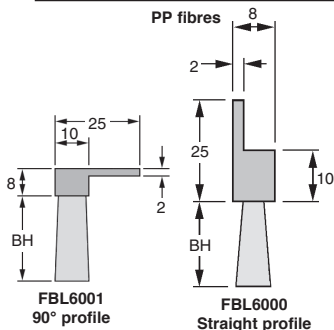

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-10%	On request

Part number	Straight profile	90° profile	Bristle diameter (mm)	BH	Length	Stock*		Price each	
						Straight profile	90° profile	Straight profile	90° profile
Black horsehair									
FBL6000-K13	FBL6001-K13		0,2	10	5m	✓	✓	44,56 €	44,56 €
FBL6000-K14	FBL6001-K14		0,2	15	5m	✓	✓	44,98 €	44,98 €
FBL6000-K15	FBL6001-K15		0,2	20	5m	✓	✓	45,38 €	45,38 €
FBL6000-K17	FBL6001-K17		0,2	30	5m	✓	-	46,66 €	46,66 €
FBL6000-K18	FBL6001-K18		0,2	40	5m	✓	✓	47,69 €	47,69 €

Tools

FBL-TOOL	Cutting scissors	193,51 €
----------	------------------	----------

*Depending on availability - Dimensions in mm

For ensuring an external seal

FBL4004
FBL4005

Brush strip to cut to desired length.

Uses

- Sealing
- Cable entries
- Guiding parts

Materials

- **Fibres:** Polypropylene. No water absorption, good resistance to chemicals...
Working temperature: -20 (occasional) to 80°C
- **Support:** Thermoplastic rubber.
Good UV and ozone resistance. Practically unaffected by most chemicals.
Working temperature: -40 to +125°C


Info.

- Sold in 5 metre lengths.
- Maximum length of a single brush is 25 metres.
- Special scissors for cutting to length

FBL-TOOL



PP fibres

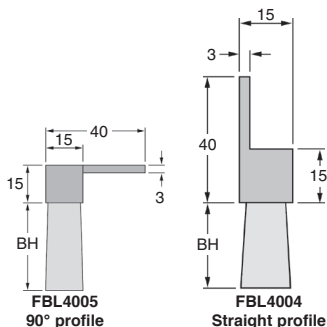

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-10%	On request


Part number	Bristle diameter (mm)	BH	Length	Stock*		Price each		
				Straight profile	90° profile	Straight profile	90° profile	
Black Polyamide 6 (PA6) fibres								
FBL4004-K34	-	0,3	30	5m	✓	-	130,13 €	-
FBL4004-K35	-	0,3	40	5m	✓	-	132,49 €	-
FBL4004-K36	FBL4005-K31	0,3	50	5m	✓	✓	134,99 €	134,99 €
FBL4004-K37	FBL4005-K32	0,3	60	5m	✓	-	137,47 €	137,47 €
FBL4004-K38	-	0,3	70	5m	✓	-	151,08 €	-

Tools

FBL-TOOL	Cutting scissors	193,51 €
----------	------------------	----------

*Depending on availability - Dimensions in mm

Our other products

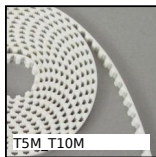

T type timing belt per metre, T5 Steel cored polyurethane



Elastic ringed latch, Hooks into a slot



Chain sprocket - Stainless steel, 12.7mm (DIN 08B-1)



Internal epicyclic servo reducers, from 60 to 140 Nm



 
V shaped channel UtiliTrak®, V rail



Worm and wheel gear reducer, up to 298 Nm



End cap for round tube, Standard



RPP heavy duty timing belt, RPP8



Mounting feet with integrated castors,



Worm - precision range, Steel



Speed controller 5A accessories, Kit of 4



Worm and wheel set, Hardened steel

Complementary products



Sealing brush strip, 3m length



Sealing brush strip, 1m length

Our other products



DOG319

Motor-gearbox 12V and 24V DC, from 4 to 9 Nm



MBF

Threaded blocking clamp, Threaded locking clamp



BABtss

303 Stainless steel ball pin, 303 Stainless steel



PW_PWG1

Wheel - precision range, Bronze



DZYSS

Stainless steel cylindrical stop, stainless steel



PRF_CH

Cable-carrier chain for aluminium profile, Supplied in metre lengths



FF15

Offset spur gear reducer, from 2.20 to 10 Nm



CLB_T

Die cast zinc clamping lever - male, Zamak



BAN

Angular clamp, Standard



PRF_T

Corner reinforcement, Corner reinforcement



RIMple

Locking castor, with mounting plate



PR125rehausse

Extension for articulated foot Ø123, articulated foot PR125

Complementary products



STRIP

Sealing brush strip, 3m length



STRIPF

Sealing brush strip, 1m length