

Sealing brush strips

FBL

Advantages and applications

Advantages



- No wastage, only the length required is removed from the roll.
- Reduced storage/transport space, each box contains 25 metres.



- Special scissors allow the strip to be cut to the required length.




- Flexible in terms of positioning and fitting.

Applications



- Splash guard for wheel arches on a lorry

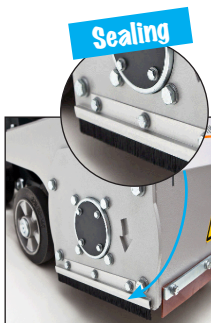

- Waterproofness of floor cleaning machines



- Guiding PET bottles

Brush strip **horsehair fibres** Ø0.2

For ensuring a seal up to 125°C

FBL6000
FBL6001

Brush strip to cut to desired length.

Uses


- Sealing
- Cable entries
- Guiding parts

Materials


- **Fibres:** Horsehair. No risk of static charge, excellent for dusting, brushing, sealing and for applying liquids (can be used as paintbrush)
Maximum temperature: +150°C
- **Support:** Thermoplastic rubber.
Good UV and ozone resistance. Practically unaffected by most chemicals.
Working temperature: -40 to +125°C

Info.

- Sold in 5 metre lengths.
- Maximum length of a single brush is 25 metres.
- Special scissors for cutting to length
FBL-TOOL

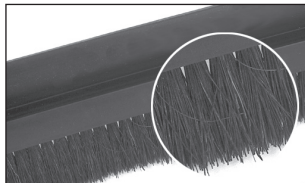

Horsehair fibres

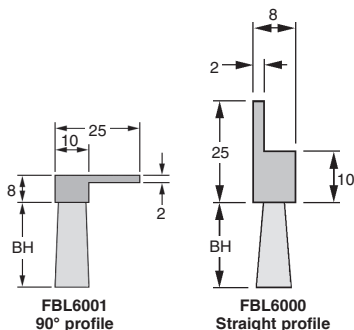

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-10%	On request

Part number		Bristle diameter (mm)	BH	Length			Price each	
Straight profile	90° profile				Straight profile	90° profile	Straight profile	90° profile
Black horsehair								
FBL6000-K19	-	0,2	15	5m	✓	-	63,64 €	-
FBL6000-K20	-	0,2	20	5m	✓	-	68,86 €	-
FBL6000-K21	FBL6001-K21	0,2	25	5m	-	✓	74,33 €	74,33 €
FBL6000-K23	FBL6001-K23	0,2	40	5m	✓	-	92,79 €	92,79 €
FBL6000-K24	FBL6001-K24	0,2	50	5m	✓	✓	108,10 €	108,10 €

Tools

FBL-TOOL	Cutting scissors	193,51 €
----------	------------------	----------

*Depending on availability - Dimensions in mm

Brush strip **PA6 fibres** Ø0.2 to Ø0.3 Stock

FBL6000 FBL6001

For ensuring an internal seal

Brush strip to cut to desired length.

Uses

- Sealing
- Cable entries
- Guiding parts

Materials


- **Fibres:** Polyamide PA6. Standard material for brushes used for cleaning, transporting, guiding or sealing moving pieces.
Working temperature: -20 to 100°C
- **Support:** Thermoplastic rubber.
Good UV and ozone resistance.
Practically unaffected by most chemicals.
Working temperature: -40 to +125°C

Info.

- Sold in 5 metre lengths.
 - Maximum length of a single brush is 25 metres.
 - Special scissors for cutting to length
- FBL-TOOL**



PA6 fibres

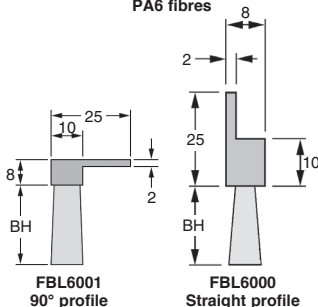

FBL6001
90° profile

FBL6000
Straight profile

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-10%	On request

Part number		Bristle diameter (mm)	BH	Length	Stock*	Stock*	Price each	
Straight profile	90° profile				Straight profile	90° profile	Straight profile	90° profile
Black Polyamide 6 (PA6) fibres								
FBL6000-K1	FBL6001-K1	0,2	10	5m	✓	✓	48,53 €	48,53 €
FBL6000-K2	FBL6001-K2	0,2	15	5m	✓	✓	49,78 €	49,78 €
FBL6000-K3	FBL6001-K3	0,2	20	5m	✓	✓	51,26 €	51,26 €
FBL6000-K4	-	0,2	25	5m	✓	-	52,74 €	-
FBL6000-K5	FBL6001-K5	0,2	30	5m	✓	✓	54,21 €	54,21 €
FBL6000-K7	-	0,3	15	5m	✓	-	49,78 €	-
FBL6000-K8	-	0,3	20	5m	✓	-	51,26 €	-
FBL6000-K9	-	0,3	25	5m	✓	-	52,74 €	-
FBL6000-K10	-	0,3	30	5m	✓	-	54,21 €	-
FBL6000-K11	-	0,3	40	5m	✓	-	57,33 €	-
FBL6000-K12	-	0,3	50	5m	✓	-	60,29 €	-

Tools

FBL-TOOL	Cutting scissors	193,51 €
-----------------	------------------	----------

*Depending on availability - Dimensions in mm

Brush strip to cut to desired length.

Uses

- Sealing
- Cable entries
- Guiding parts

Materials


- **Fibres:** Polyamide PA6. Standard material for brushes used for cleaning, transporting, guiding or sealing moving pieces.
Working temperature: -20 to 100°C
- **Support:** Thermoplastic rubber. Good UV and ozone resistance. Practically unaffected by most chemicals.
Working temperature: -40 to +125°C

Info.

- Sold in 5 metre lengths.
- Maximum length of a single brush is 25 metres.
- Special scissors for cutting to length
FBL-TOOL



PA6 fibres

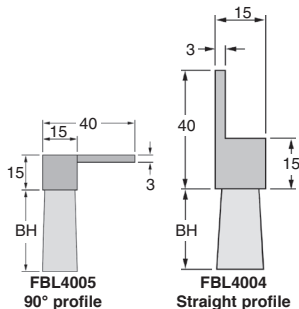

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-10%	On request

Part number		Bristle diameter (mm)	BH	Length	Stock*		Price each	
Straight profile	90° profile				Straight profile	90° profile	Straight profile	90° profile
Black Polyamide 6 (PA6) fibres								
FBL4004-K8	-	0,3	20	5m	✓	-	140,75 €	-
FBL4004-K9	-	0,3	30	5m	✓	-	147,61 €	-
FBL4004-K13	-	0,5	30	5m	✓	-	147,61 €	-
FBL4004-K14	-	0,5	40	5m	✓	-	154,69 €	-
FBL4004-K15	-	0,5	50	5m	✓	-	161,80 €	-
FBL4004-K18	FBL4005-K15	0,5	80	5m	✓	✓	193,81 €	193,81 €

Tools

FBL-TOOL	Cutting scissors	193,51 €
----------	------------------	----------

*Depending on availability - Dimensions in mm

Brush strip PP fibres Ø0.2



FBL6000
FBL6001

For ensuring an external seal

Brush strip to cut to desired length.

Uses

- Sealing
- Cable entries
- Guiding parts


Materials

- **Fibres:** Polypropylene. No water absorption, good resistance to chemicals...
Working temperature: -20 (occasional) to 80°C
- **Support:** Thermoplastic rubber.
Good UV and ozone resistance. Practically unaffected by most chemicals.
Working temperature: -40 to +125°C

Info.

- Sold in 5 metre lengths.
- Maximum length of a single brush is 25 metres.
- Special scissors for cutting to length

FBL-TOOL

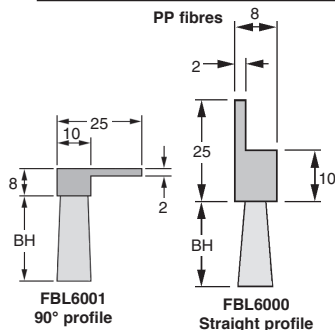

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-10%	On request

Part number		Bristle diameter (mm)	BH	Length	Stock*	Stock*	Price each	
Straight profile	90° profile				Straight profile	90° profile	Straight profile	90° profile
Black horsehair								
FBL6000-K13	FBL6001-K13	0,2	10	5m	✓	✓	44,56 €	44,56 €
FBL6000-K14	FBL6001-K14	0,2	15	5m	✓	✓	44,98 €	44,98 €
FBL6000-K15	FBL6001-K15	0,2	20	5m	✓	✓	45,38 €	45,38 €
FBL6000-K17	FBL6001-K17	0,2	30	5m	✓	-	46,66 €	46,66 €
FBL6000-K18	FBL6001-K18	0,2	40	5m	✓	✓	47,69 €	47,69 €

Tools

FBL-TOOL	Cutting scissors	193,51 €
----------	------------------	----------

*Depending on availability - Dimensions in mm

For ensuring an external seal

FBL4004
FBL4005

Brush strip to cut to desired length.

Uses

- Sealing
- Cable entries
- Guiding parts

Materials

- **Fibres:** Polypropylene. No water absorption, good resistance to chemicals...
Working temperature: -20 (occasional) to 80°C
- **Support:** Thermoplastic rubber.
Good UV and ozone resistance. Practically unaffected by most chemicals.
Working temperature: -40 to +125°C


Info.

- Sold in 5 metre lengths.
- Maximum length of a single brush is 25 metres.
- Special scissors for cutting to length

FBL-TOOL



PP fibres

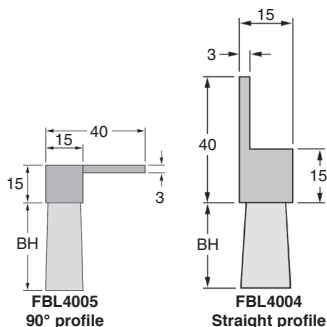

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-10%	On request

Part number		Bristle diameter (mm)	BH	Length	Stock*		Price each	
Straight profile	90° profile				Straight profile	90° profile	Straight profile	90° profile
Black Polyamide 6 (PA6) fibres								
FBL4004-K34	-	0,3	30	5m	✓	-	130,13 €	-
FBL4004-K35	-	0,3	40	5m	✓	-	132,49 €	-
FBL4004-K36	FBL4005-K31	0,3	50	5m	✓	✓	134,99 €	134,99 €
FBL4004-K37	FBL4005-K32	0,3	60	5m	✓	-	137,47 €	137,47 €
FBL4004-K38	-	0,3	70	5m	✓	-	151,08 €	-

Tools

FBL-TOOL	Cutting scissors	193,51 €
----------	------------------	----------

*Depending on availability - Dimensions in mm

Our other products



T type timing belt per metre, T5 Steel cored polyurethane



Elastic ringed latch, Hooks into a slot



Chain sprocket - Stainless steel, 12.7mm (DIN 08B-1)



Internal epicyclic servo reducers, from 60 to 140 Nm




V shaped channel UtiliTrak®, V rail



Worm and wheel gear reducer, up to 298 Nm



End cap for round tube, Standard

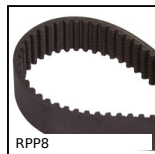

RPP heavy duty timing belt, RPP8



Mounting feet with integrated castors, 50mm



Worm - precision range, Steel



Speed controller 5A accessories, Kit of 4



Worm and wheel set, Hardened steel

Complementary products



Sealing brush strip, 3m length



Sealing brush strip, 1m length

Our other products



PTKFss
Fixable foot for the food industry, Stainless steel - 3-A standard



BAC105
Storage bin, 8mm



BOX-TOR-B
Box set of Nitrile O-rings in nitrile, 20.38 x 1.78mm to 50.16 x 5.34



RBS
Dynamic washer DIN2093, Steel



EML
Stainless steel hexagonal headed thumb nut, Lobed handscrew



AC144
Strike for toggle latch, 22mm



NCT
Square tube connector, Fixed angle



RJUM01
Closed polymer Drylin® R bearing, Drylin® R



BPF
Sheet steel flanged bearing for light loads, Sheet steel



MSP3815
Masterplate® glueable insert rectangular,



SUA4
Single chain supplied by the metre, Steel



CSS
Spherical bushing, Steel / self lubricating steel

Complementary products



STRIP
Sealing brush strip, 3m length



STRIPF
Sealing brush strip, 1m length