



# Brush strip **horsehair fibres** Ø0.2

For ensuring a seal up to 125°C

**FBL6000**  
**FBL6001**

Brush strip to cut to desired length.

## Uses

- Sealing
- Cable entries
- Guiding parts

## Materials


- **Fibres:** Horsehair. No risk of static charge, excellent for dusting, brushing, sealing and for applying liquids (can be used as paintbrush)
  - **Support:** Thermoplastic rubber. Good UV and ozone resistance. Practically unaffected by most chemicals.
- Maximum temperature: +150°C  
Working temperature: -40 to +125°C

## Info.

- Sold in 5 metre lengths.
  - Maximum length of a single brush is 25 metres.
  - Special scissors for cutting to length
- FBL-TOOL**



Horsehair fibres

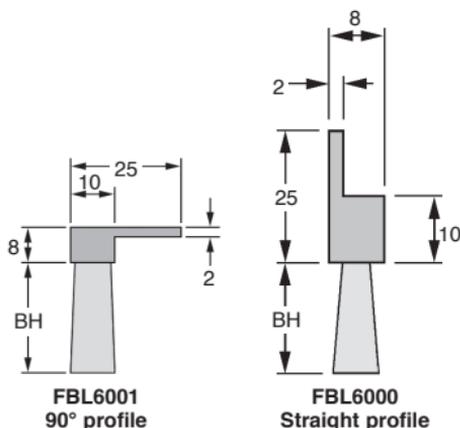

## DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-10%	On request

Part number	Bristle diameter (mm)	BH	Length	Stock*		Price each	
				Straight profile	90° profile	Straight profile	90° profile
<b>Black horsehair</b>							
FBL6000-K19	0,2	15	5m	✓	-	69,53 €	-
FBL6000-K20	0,2	20	5m	-	-	On request	-
FBL6000-K21	FBL6001-K21	0,2	25	5m	-	On request	On request
FBL6000-K23	FBL6001-K23	0,2	40	5m	-	On request	On request
FBL6000-K24	FBL6001-K24	0,2	50	5m	-	On request	On request

## Tools

FBL-TOOL	Cutting scissors	211,41 €
----------	------------------	----------

\*Depending on availability - Dimensions in mm

# Brush strip **PA6 fibres** Ø0.2 to Ø0.3 Stock

## FBL6000 FBL6001

For ensuring a sealing indoor

Brush strip to cut to desired length.

### Uses


- Sealing
- Cable entries
- Guiding parts

### Materials

- **Fibres:** Polyamide PA6. Standard material for brushes used for cleaning, transporting, guiding or sealing moving pieces.
- **Working temperature:** -20 to 100°C
- **Support:** Thermoplastic rubber. Good UV and ozone resistance. Practically unaffected by most chemicals.
- **Working temperature:** -40 to +125°C

### Info.

- Sold in 5 metre lengths.
  - Maximum length of a single brush is 25 metres.
  - Special scissors for cutting to length
- FBL-TOOL**

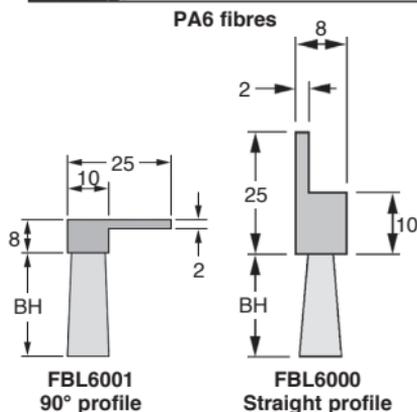

### DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-10%	On request

Part number		Bristle diameter (mm)	BH	Length	Stock*		Price each	
Straight profile	90° profile				Straight profile	90° profile	Straight profile	90° profile
<b>Black Polyamide 6 (PA6) fibres</b>								
FBL6000-K1	FBL6001-K1	0,2	10	5m	✓	-	53,03 €	On request
FBL6000-K2	FBL6001-K2	0,2	15	5m	✓	✓	54,39 €	54,39 €
FBL6000-K3	FBL6001-K3	0,2	20	5m	✓	-	56,00 €	On request
FBL6000-K4	-	0,2	25	5m	✓	-	57,62 €	-
FBL6000-K5	FBL6001-K5	0,2	30	5m	✓	-	59,23 €	On request
FBL6000-K7	-	0,3	15	5m	-	-	On request	-
FBL6000-K8	-	0,3	20	5m	-	-	On request	-
FBL6000-K9	-	0,3	25	5m	-	-	On request	-
FBL6000-K10	-	0,3	30	5m	✓	-	59,23 €	-
FBL6000-K11	-	0,3	40	5m	✓	-	62,63 €	-
FBL6000-K12	-	0,3	50	5m	✓	-	65,87 €	-

### Tools

FBL-TOOL	Cutting scissors	211,41 €
----------	------------------	----------

\*Depending on availability - Dimensions in mm



# Brush strip PA6 fibres Ø0.3 to Ø0.5

For ensuring a sealing indoor

**FBL4004**  
**FBL4005**

Brush strip to cut to desired length.

## Uses

- Sealing
- Cable entries
- Guiding parts

## Materials

- **Fibres:** Polyamide PA6. Standard material for brushes used for cleaning, transporting, guiding or sealing moving pieces.

Working temperature: -20 to 100°C

- **Support:** Thermoplastic rubber. Good UV and ozone resistance. Practically unaffected by most chemicals.


Working temperature: -40 to +125°C

## Info.

- Sold in 5 metre lengths.
- Maximum length of a single brush is 25 metres.
- Special scissors for cutting to length **FBL-TOOL**



PA6 fibres

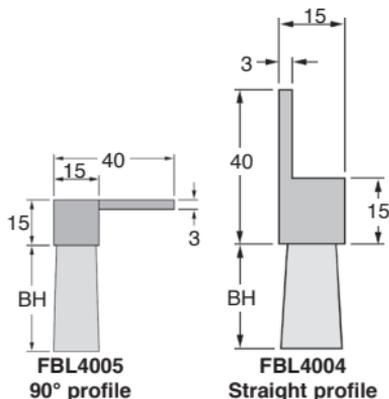

## DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-10%	On request

Part number	Bristle diameter (mm)	BH	Length	Stock*		Price each		
				Straight profile	90° profile	Straight profile	90° profile	
<b>Black Polyamide 6 (PA6) fibres</b>								
FBL4004-K8	-	0,3	20	5m	-	-	On request	-
FBL4004-K9	-	0,3	30	5m	-	-	On request	-
FBL4004-K13	-	0,5	30	5m	✓	-	161,27 €	-
FBL4004-K14	-	0,5	40	5m	-	-	On request	-
FBL4004-K15	-	0,5	50	5m	-	-	On request	-
FBL4004-K18	FBL4005-K15	0,5	80	5m	✓	✓	211,75 €	211,75 €

## Tools

FBL-TOOL	Cutting scissors	211,41 €
----------	------------------	----------

\*Depending on availability - Dimensions in mm

# Brush strip **PP fibres** Ø0.2



## FBL6000 For ensuring a sealing outdoor FBL6001

Brush strip to cut to desired length.

### Uses

- Sealing
- Cable entries
- Guiding parts


### Materials

- **Fibres:** Polypropylene. No water absorption, good resistance to chemicals... Working temperature: -20 (occasional) to 80°C
- **Support:** Thermoplastic rubber. Good UV and ozone resistance. Practically unaffected by most chemicals. Working temperature: -40 to +125°C

### Info.

- Sold in 5 metre lengths.
- Maximum length of a single brush is 25 metres.
- Special scissors for cutting to length

**FBL-TOOL**

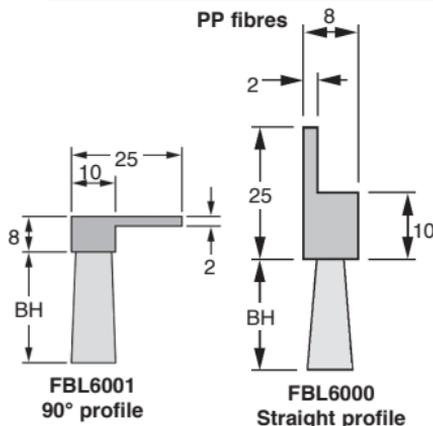

### DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-10%	On request

Part number	Straight profile	90° profile	Bristle diameter (mm)	BH	Length	Stock*		Price each	
						Straight profile	90° profile	Straight profile	90° profile
<b>Black horsehair</b>									
FBL6000-K13	FBL6001-K13		0,2	10	5m	✓	✓	48,68 €	48,68 €
FBL6000-K14	FBL6001-K14		0,2	15	5m	✓	-	49,15 €	On request
FBL6000-K15	FBL6001-K15		0,2	20	5m	✓	-	49,58 €	On request
FBL6000-K17	FBL6001-K17		0,2	30	5m	-	-	On request	50,97 €
FBL6000-K18	FBL6001-K18		0,2	40	5m	✓	✓	52,11 €	52,11 €

### Tools

FBL-TOOL	Cutting scissors	211,41 €
----------	------------------	----------

\*Depending on availability - Dimensions in mm

For ensuring a sealing outdoor

**FBL4004**  
**FBL4005**

Brush strip to cut to desired length.

## Uses

- Sealing
- Cable entries
- Guiding parts

## Materials

- **Fibres:** Polypropylene. No water absorption, good resistance to chemicals...  
Working temperature: -20 (occasional) to 80°C
- **Support:** Thermoplastic rubber. Good UV and ozone resistance. Practically unaffected by most chemicals.  
Working temperature: -40 to +125°C


## Info.

- Sold in 5 metre lengths.
- Maximum length of a single brush is 25 metres.
- Special scissors for cutting to length

### FBL-TOOL



PP fibres

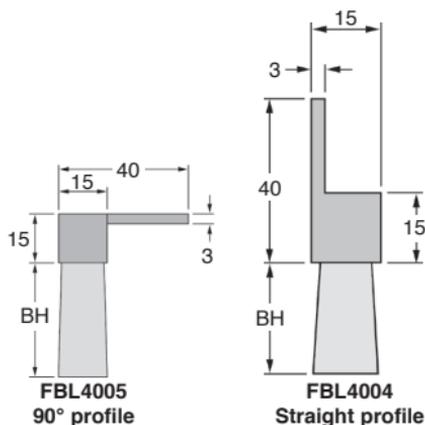

## DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-10%	On request

Part number	Bristle diameter (mm)	BH	Length	Stock*		Price each	
				Straight profile	90° profile	Straight profile	90° profile
<b>Black Polyamide 6 (PA6) fibres</b>							
FBL4004-K34	-	0,3	30	5m	-	-	On request -
FBL4004-K35	-	0,3	40	5m	-	-	On request -
FBL4004-K36	FBL4005-K31	0,3	50	5m	-	✓	On request 147,48 €
FBL4004-K37	FBL4005-K32	0,3	60	5m	✓	-	150,19 € On request
FBL4004-K38	-	0,3	70	5m	✓	-	165,05 € -

### Tools

FBL-TOOL	Cutting scissors	211,41 €
----------	------------------	----------

\*Depending on availability - Dimensions in mm