
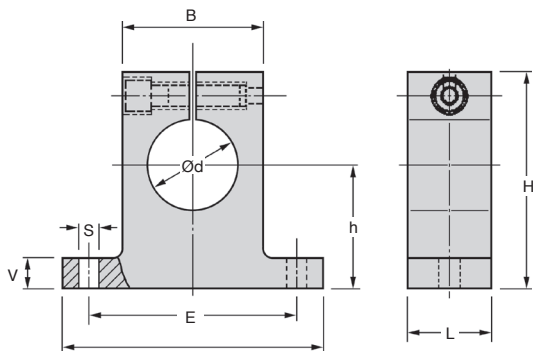


- End support for linear guide shaft
- Material: Aluminium
- Adjustable backlash
- Mounting holes conform to DIN912 8.8

Accessories

- Ground shafts Z-A, Z-B

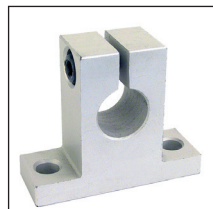

DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	List	-6%	-12%	On request

Part number	Ød	h	B	H	L	A	S	V	E	Stock*	Price each 1 to 4
FGWA-12	12	20	20	35	12	42	5,5	5,5	32	✓	14,55 €
FGWA-16	16	25	26	42	15	50	5,5	6,5	40	✓	16,19 €
FGWA-20	20	30	32	50	20	60	5,5	8,0	45	✓	20,23 €
FGWA-25	25	35	38	58	25	74	6,6	9,0	60	✓	23,06 €
FGWA-30	30	40	45	68	30	84	9,0	10,0	68	✓	35,65 €
FGWA-40	40	50	56	86	30	108	11,0	12,0	86	✓	68,12 €
FGWA-50	50	60	80	100	40	130	11,0	14,0	108	-	105,41 €

*Depending on availability - Dimensions in mm

Our other products



MHX
Hexagonal threaded sleeve, Hexagonal - steel



ZDB
Machined plastic bevel gear , 2:1



GAC
Lock for latch clamp, Strike plate



UTKswrr
V shaped channel UtiliTrak®, V rail



PLM-20SC
Threaded cylindrical magnet, With threaded hole



 
MFBS
Stainless steel flexible bellows coupling, Stainless steel - with se...



CHN CHNSS
Straight long link stainless steel chain, Stainless steel



NCT
Square tube connector, Fixed angle




LAT1
1A motorised linear actuator, 1 ampere



RFV63
Stainless steel worm and wheel gearbox, up to 152 Nm



 PRES5HR
Manual workbench press, Force up to 500kg



SBF
Sealed flange bearing unit for Food Industry, cover

Complementary products



ZA
Shaft for linear guides, Hardened ground steel



ZB
Shaft for linear guides, Hardened ground stainless steel



AWMP
Aluminium shaft for linear guide, Aluminium