
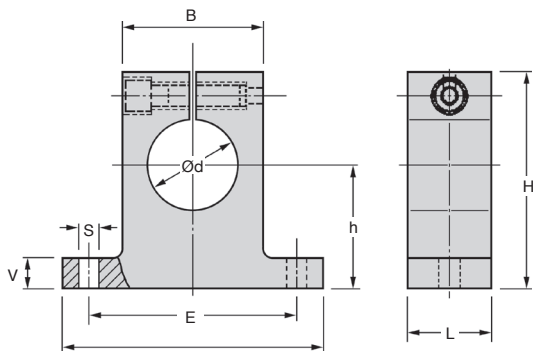


- End support for linear guide shaft
- Material: Aluminium
- Adjustable backlash
- Mounting holes conform to DIN912 8.8

Accessories

- Ground shafts Z-A, Z-B

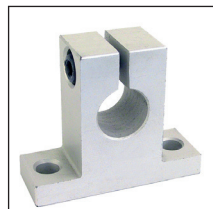

DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	List	-6%	-12%	On request

Part number	Ød	h	B	H	L	A	S	V	E	Stock*	Price each 1 to 4
FGWA-12	12	20	20	35	12	42	5,5	5,5	32	✓	14,55 €
FGWA-16	16	25	26	42	15	50	5,5	6,5	40	✓	16,19 €
FGWA-20	20	30	32	50	20	60	5,5	8,0	45	✓	20,23 €
FGWA-25	25	35	38	58	25	74	6,6	9,0	60	✓	23,06 €
FGWA-30	30	40	45	68	30	84	9,0	10,0	68	✓	35,65 €
FGWA-40	40	50	56	86	30	108	11,0	12,0	86	✓	68,12 €
FGWA-50	50	60	80	100	40	130	11,0	14,0	108	-	105,41 €

*Depending on availability - Dimensions in mm

Our other products



SMLS
Linear table, For small lengths



BAG55
Stainless steel
Clamping collar,
Stainless steel



ZH66
Plastic spur gear,
Machined plastic
(delrin)



GAL22
Conveyor wheel, Zinc plated steel



RDS
Safety washer
Hygienic Usit®,
Stainless steel



TB8
Cylindrical roller
thrust bearing, Steel



RTN
BoWex® curved tooth
gear coupling, Nylon



 
DTR
Chain idler sprocket,
Chain idler sprocket -
Plastic



KSTM
Igubal® pillow block
bearing, Polymer



AKN
Bellows coupling
Gerwah®, from 22 to
180Nm



RPPM
RPP type belt per
metre, RPP8 Steel
cored polyurethane



PP60
Worm and wheel gear
reducer, from 17.80
to 34 Nm

Complementary products



ZA
Shaft for linear
guides, Hardened
ground steel



ZB
Shaft for linear
guides, Hardened
ground stainless steel



AWMP
Aluminium shaft for
linear guide,
Aluminium