

Countersunk screw **DIN 7991**

Sta **DIN**

FHCss

Stainless steel A2


- Material: Stainless steel 302/304 - A2
- Hexagonal socket
- Sold by the packet

Uses

- Suitable for harsh environments

Info.


- Dimension B is for information only and can vary depending on manufacture

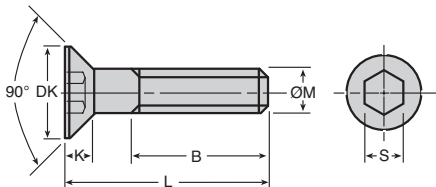

Designer's Note

Countersunk heads

Thread	ØF (H13)		T
	num.	max.	
M3	6,60	6,82	1,60
M4	9,80	10,02	2,65
M5	10,90	11,17	2,70
M6	13,20	13,47	3,30
M8	18,10	18,43	4,55
M10	21,00	21,33	5,00
M12	25,20	25,53	5,85

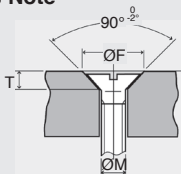

DISCOUNTS

N° packets	1+	2+	4+
Disc.	List	-20%	On request

Part number	Thread		Total length L	B	DK	K	S	Qty per packet	Stock*	Price per packet
	ØM	Pitch								
FHC3-8/SS/B	M3	0,50	8	-	6	1,6	2,0	500	✓	21,59 €
FHC3-12/SS/B	M3	0,50	12	-	6	1,6	2,0	500	✓	23,56 €
FHC3-16/SS/B	M3	0,50	16	-	6	1,6	2,0	500	✓	23,91 €
FHC3-20/SS/B	M3	0,50	20	-	6	1,6	2,0	500	✓	25,70 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel


DISCOUNTS

N° packets	1+	2+	4+
Disc.	List	-20%	On request

Part number	Thread		Total length L	B	DK	K	S	Qty per packet	Stock*	Price per packet
	ØM	Pitch								
FHC4-10/SS/B	M4	0,70	10	-	8	2,3	2,5	500	✓	14,81 €
FHC4-12/SS/B	M4	0,70	12	-	8	2,3	2,5	500	✓	13,92 €
FHC4-16/SS/B	M4	0,70	16	-	8	2,3	2,5	500	✓	20,87 €
FHC4-20/SS/B	M4	0,70	20	-	8	2,3	2,5	500	✓	20,87 €
FHC4-25/SS/B	M4	0,70	25	-	8	2,3	2,5	500	✓	31,77 €
FHC4-30/SS/B	M4	0,70	30	20	8	2,3	2,5	200	✓	15,63 €
FHC5-10/SS/B	M5	0,80	10	-	10	2,8	3,0	500	✓	26,59 €
FHC5-12/SS/B	M5	0,80	12	-	10	2,8	3,0	500	✓	22,66 €
FHC5-16/SS/B	M5	0,80	16	-	10	2,8	3,0	500	✓	29,98 €
FHC5-20/SS/B	M5	0,80	20	-	10	2,8	3,0	500	✓	35,51 €
FHC5-25/SS/B	M5	0,80	25	-	10	2,8	3,0	500	✓	37,12 €
FHC5-30/SS/B	M5	0,80	30	-	10	2,8	3,0	200	✓	18,27 €
FHC5-35/SS/B	M5	0,80	35	22	10	2,8	3,0	200	✓	23,41 €
FHC6-10/SS/B	M6	1,00	10	-	12	3,3	4,0	500	✓	27,30 €
FHC6-12/SS/B	M6	1,00	12	-	12	3,3	4,0	500	✓	35,87 €
FHC6-16/SS/B	M6	1,00	16	-	12	3,3	4,0	500	✓	36,23 €
FHC6-20/SS/B	M6	1,00	20	-	12	3,3	4,0	200	✓	16,63 €
FHC6-25/SS/B	M6	1,00	25	-	12	3,3	4,0	200	✓	20,56 €
FHC6-30/SS/B	M6	1,00	30	-	12	3,3	4,0	200	✓	23,99 €
FHC6-35/SS/B	M6	1,00	35	-	12	3,3	4,0	200	✓	21,91 €
FHC6-40/SS/B	M6	1,00	40	-	12	3,3	4,0	200	✓	31,13 €
FHC6-45/SS/B	M6	1,00	45	-	12	3,3	4,0	100	-	13,99 €
FHC6-60/SS/B	M6	1,00	60	20	12	3,3	4,0	100	-	21,70 €
FHC6-70/SS/B	M6	1,00	70	20	12	3,3	4,0	100	-	30,87 €
FHC8-16/SS/B	M8	1,25	16	-	16	4,4	5,0	200	✓	27,77 €
FHC8-20/SS/B	M8	1,25	20	-	16	4,4	5,0	200	✓	29,63 €
FHC8-25/SS/B	M8	1,25	25	-	16	4,4	5,0	100	✓	17,52 €
FHC8-30/SS/B	M8	1,25	30	-	16	4,4	5,0	100	✓	20,63 €
FHC8-40/SS/B	M8	1,25	40	-	16	4,4	5,0	100	✓	25,48 €
FHC8-50/SS/B	M8	1,25	50	-	16	4,4	5,0	100	✓	35,62 €
FHC10-35/SS/B	M10	1,50	35	-	20	5,5	6,0	100	✓	37,72 €
FHC10-40/SS/B	M10	1,50	40	-	20	5,5	6,0	100	⚠	33,62 €
FHC10-50/SS/B	M10	1,50	50	32	20	5,5	6,0	100	-	41,15 €
FHC12-30/SS/B	M12	1,75	30	-	24	6,5	8,0	50	⚠	20,42 €
FHC12-40/SS/B	M12	1,75	40	36	24	6,5	8,0	50	-	25,56 €
FHC12-50/SS/B	M12	1,75	50	36	24	6,5	8,0	50	-	30,27 €
FHC12-60/SS/B	M12	1,75	60	36	24	6,5	8,0	50	-	39,55 €
FHC12-70/SS/B	M12	1,75	70	36	24	6,5	8,0	50	-	44,29 €
FHC12-80/SS/B	M12	1,75	80	36	24	6,5	8,0	50	-	51,43 €


*Depending on availability - Dimensions in mm

 Our other products



CFC

 Spring loaded position switch, Electric contact



UCF PBT

Stainless steel/Polymer flanged bearing, Polymer and stainless steel



PW_PWG15

Worm - precision range, Stainless steel



BAG-MI

Split shaft collar with clamp lever, Steel



BUH77

Motor-gearbox 12V and 24V DC, from 0.1 to 2 Nm



SSDB

Stainless steel bevel gear, 2:1



LVT

Miniature motorised actuator 1A, 1 ampere



EKN

Bellows coupling Gerwah®, from 0.5 to 12Nm




SDC

Positioning sleeve for indexing pin, For pin



PR125

 Articulated foot Ø123, Ø 123



RIMtce

Locking castor, with central hole



PW_PWG1

Worm - precision range, Stainless steel

Complementary products



SHN

Hexagonal nut DIN934, A2 Stainless steel



CHA35

Hinge for aluminium profile, Hinge



ACLCHARJ

Hinge for aluminium profile, Adjusts in 2 directions



NIN

Self-locking nut, A2 Stainless steel