

Countersunk screw **DIN 7991**



FHCss

Stainless steel A2


- Material: Stainless steel 302/304 - A2
- Hexagonal socket
- Sold by the packet

Uses

- Suitable for harsh environments

Info.


- Dimension B is for information only and can vary depending on manufacture

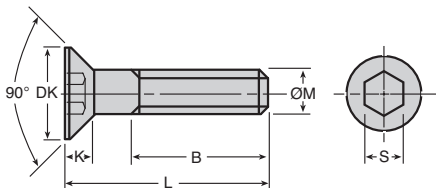

Designer's Note

Countersunk heads

Thread	ØF (H13)		T
	num.	max.	
M3	6,60	6,82	1,60
M4	9,80	10,02	2,65
M5	10,90	11,17	2,70
M6	13,20	13,47	3,30
M8	18,10	18,43	4,55
M10	21,00	21,33	5,00
M12	25,20	25,53	5,85

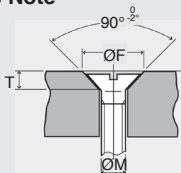

DISCOUNTS

N° packets	1+	2+	4+
Disc.	List	-20%	On request

Part number	Thread		Total length L	B	DK	K	S	Qty per packet	Stock*	Price per packet
	ØM	Pitch								
FHC3-8/SS/B	M3	0,50	8	-	6	1,6	2,0	500	✓	21,59 €
FHC3-12/SS/B	M3	0,50	12	-	6	1,6	2,0	500	✓	23,56 €
FHC3-16/SS/B	M3	0,50	16	-	6	1,6	2,0	500	✓	23,91 €
FHC3-20/SS/B	M3	0,50	20	-	6	1,6	2,0	500	✓	25,70 €

*Depending on availability - Dimensions in mm

DISCOUNTS

N° packets	1+	2+	4+
Disc.	List	-20%	On request

Part number	Thread		Total length L	B	DK	K	S	Qty per packet	Stock*	Price per packet
	ØM	Pitch								
FHC4-10/SS/B	M4	0,70	10	-	8	2,3	2,5	500	✓	14,81 €
FHC4-12/SS/B	M4	0,70	12	-	8	2,3	2,5	500	✓	13,92 €
FHC4-16/SS/B	M4	0,70	16	-	8	2,3	2,5	500	✓	20,87 €
FHC4-20/SS/B	M4	0,70	20	-	8	2,3	2,5	500	✓	20,87 €
FHC4-25/SS/B	M4	0,70	25	-	8	2,3	2,5	500	✓	31,77 €
FHC4-30/SS/B	M4	0,70	30	20	8	2,3	2,5	200	✓	15,63 €
FHC5-10/SS/B	M5	0,80	10	-	10	2,8	3,0	500	✓	26,59 €
FHC5-12/SS/B	M5	0,80	12	-	10	2,8	3,0	500	✓	22,66 €
FHC5-16/SS/B	M5	0,80	16	-	10	2,8	3,0	500	✓	29,98 €
FHC5-20/SS/B	M5	0,80	20	-	10	2,8	3,0	500	✓	35,51 €
FHC5-25/SS/B	M5	0,80	25	-	10	2,8	3,0	500	✓	37,12 €
FHC5-30/SS/B	M5	0,80	30	-	10	2,8	3,0	200	✓	18,27 €
FHC5-35/SS/B	M5	0,80	35	22	10	2,8	3,0	200	✓	23,41 €
FHC6-10/SS/B	M6	1,00	10	-	12	3,3	4,0	500	✓	27,30 €
FHC6-12/SS/B	M6	1,00	12	-	12	3,3	4,0	500	✓	35,87 €
FHC6-16/SS/B	M6	1,00	16	-	12	3,3	4,0	500	✓	36,23 €
FHC6-20/SS/B	M6	1,00	20	-	12	3,3	4,0	200	✓	16,63 €
FHC6-25/SS/B	M6	1,00	25	-	12	3,3	4,0	200	✓	20,56 €
FHC6-30/SS/B	M6	1,00	30	-	12	3,3	4,0	200	✓	23,99 €
FHC6-35/SS/B	M6	1,00	35	-	12	3,3	4,0	200	✓	21,91 €
FHC6-40/SS/B	M6	1,00	40	-	12	3,3	4,0	200	✓	31,13 €
FHC6-45/SS/B	M6	1,00	45	-	12	3,3	4,0	100	-	13,99 €
FHC6-60/SS/B	M6	1,00	60	20	12	3,3	4,0	100	-	21,70 €
FHC6-70/SS/B	M6	1,00	70	20	12	3,3	4,0	100	-	30,87 €
FHC8-16/SS/B	M8	1,25	16	-	16	4,4	5,0	200	✓	27,77 €
FHC8-20/SS/B	M8	1,25	20	-	16	4,4	5,0	200	✓	29,63 €
FHC8-25/SS/B	M8	1,25	25	-	16	4,4	5,0	100	✓	17,52 €
FHC8-30/SS/B	M8	1,25	30	-	16	4,4	5,0	100	✓	20,63 €
FHC8-40/SS/B	M8	1,25	40	-	16	4,4	5,0	100	✓	25,48 €
FHC8-50/SS/B	M8	1,25	50	-	16	4,4	5,0	100	✓	35,62 €
FHC10-35/SS/B	M10	1,50	35	-	20	5,5	6,0	100	✓	37,72 €
FHC10-40/SS/B	M10	1,50	40	-	20	5,5	6,0	100	⚠	33,62 €
FHC10-50/SS/B	M10	1,50	50	32	20	5,5	6,0	100	-	41,15 €
FHC12-30/SS/B	M12	1,75	30	-	24	6,5	8,0	50	⚠	20,42 €
FHC12-40/SS/B	M12	1,75	40	36	24	6,5	8,0	50	-	25,56 €
FHC12-50/SS/B	M12	1,75	50	36	24	6,5	8,0	50	-	30,27 €
FHC12-60/SS/B	M12	1,75	60	36	24	6,5	8,0	50	-	39,55 €
FHC12-70/SS/B	M12	1,75	70	36	24	6,5	8,0	50	-	44,29 €
FHC12-80/SS/B	M12	1,75	80	36	24	6,5	8,0	50	-	51,43 €

*Depending on availability - Dimensions in mm

Our other products



HRV

V- rail guidance
Simple Select®
system, Rail with
carriage




SH2

Parallel axis helical
gear, Steel 20NCD2



BOX-TOR-MAX

Box set of Nitrile O-
rings in nitrile, 2.90 x
1.78mm to 82.14 x
3.53

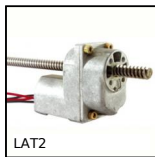

LAT2

2A motorised linear
actuator, 2 amperes



PRF_GAL

Roller for aluminium
profile, Fixing kit for
roller eccentric



GE_ES

Spherical bushing,
Steel / steel



PPOss

Pad eye on mounting
plate oval, Stainless
steel



PSG08

Spur gear - precision
range, Case hardened
steel 20NCD2



RTE

Rotex®, jaw coupling,
steel



NRR

Adjustable support
clamp, Adjustable



HRV

V- rail guidance
Simple Select®



HAR9

Captive C washer, DIN
6371

Complementary products



SHN

Hexagonal nut
DIN934, A2 Stainless
steel



CHA35

Hinge for aluminium
profile, Hinge



ACLCHARJ

Hinge for aluminium
profile, Adjusts in 2
directions



NIN

Self-locking nut, A2
Stainless steel