

Countersunk screw **DIN 7991**



FHCss

Stainless steel A2


- Material: Stainless steel 302/304 - A2
- Hexagonal socket
- Sold by the packet

Uses

- Suitable for harsh environments

Info.


- Dimension B is for information only and can vary depending on manufacture

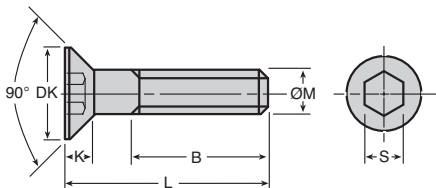

Designer's Note

Countersunk heads

Thread	ØF (H13)		T
	num.	max.	
M3	6,60	6,82	1,60
M4	9,80	10,02	2,65
M5	10,90	11,17	2,70
M6	13,20	13,47	3,30
M8	18,10	18,43	4,55
M10	21,00	21,33	5,00
M12	25,20	25,53	5,85

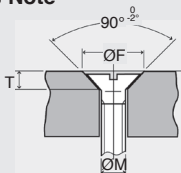

DISCOUNTS

N° packets	1+	2+	4+
Disc.	List	-20%	On request

Part number	Thread		Total length L	B	DK	K	S	Qty per packet	Stock*	Price per packet
	ØM	Pitch								
FHC3-8/SS/B	M3	0,50	8	-	6	1,6	2,0	500	✓	21,59 €
FHC3-12/SS/B	M3	0,50	12	-	6	1,6	2,0	500	✓	23,56 €
FHC3-16/SS/B	M3	0,50	16	-	6	1,6	2,0	500	✓	23,91 €
FHC3-20/SS/B	M3	0,50	20	-	6	1,6	2,0	500	✓	25,70 €

*Depending on availability - Dimensions in mm

DISCOUNTS

N° packets	1+	2+	4+
Disc.	List	-20%	On request

Part number	Thread		Total length L	B	DK	K	S	Qty per packet	Stock*	Price per packet
	ØM	Pitch								
FHC4-10/SS/B	M4	0,70	10	-	8	2,3	2,5	500	✓	14,81 €
FHC4-12/SS/B	M4	0,70	12	-	8	2,3	2,5	500	✓	13,92 €
FHC4-16/SS/B	M4	0,70	16	-	8	2,3	2,5	500	✓	20,87 €
FHC4-20/SS/B	M4	0,70	20	-	8	2,3	2,5	500	✓	20,87 €
FHC4-25/SS/B	M4	0,70	25	-	8	2,3	2,5	500	✓	31,77 €
FHC4-30/SS/B	M4	0,70	30	20	8	2,3	2,5	200	✓	15,63 €
FHC5-10/SS/B	M5	0,80	10	-	10	2,8	3,0	500	✓	26,59 €
FHC5-12/SS/B	M5	0,80	12	-	10	2,8	3,0	500	✓	22,66 €
FHC5-16/SS/B	M5	0,80	16	-	10	2,8	3,0	500	✓	29,98 €
FHC5-20/SS/B	M5	0,80	20	-	10	2,8	3,0	500	✓	35,51 €
FHC5-25/SS/B	M5	0,80	25	-	10	2,8	3,0	500	✓	37,12 €
FHC5-30/SS/B	M5	0,80	30	-	10	2,8	3,0	200	✓	18,27 €
FHC5-35/SS/B	M5	0,80	35	22	10	2,8	3,0	200	✓	23,41 €
FHC6-10/SS/B	M6	1,00	10	-	12	3,3	4,0	500	✓	27,30 €
FHC6-12/SS/B	M6	1,00	12	-	12	3,3	4,0	500	✓	35,87 €
FHC6-16/SS/B	M6	1,00	16	-	12	3,3	4,0	500	✓	36,23 €
FHC6-20/SS/B	M6	1,00	20	-	12	3,3	4,0	200	✓	16,63 €
FHC6-25/SS/B	M6	1,00	25	-	12	3,3	4,0	200	✓	20,56 €
FHC6-30/SS/B	M6	1,00	30	-	12	3,3	4,0	200	✓	23,99 €
FHC6-35/SS/B	M6	1,00	35	-	12	3,3	4,0	200	✓	21,91 €
FHC6-40/SS/B	M6	1,00	40	-	12	3,3	4,0	200	✓	31,13 €
FHC6-45/SS/B	M6	1,00	45	-	12	3,3	4,0	100	-	13,99 €
FHC6-60/SS/B	M6	1,00	60	20	12	3,3	4,0	100	-	21,70 €
FHC6-70/SS/B	M6	1,00	70	20	12	3,3	4,0	100	-	30,87 €
FHC8-16/SS/B	M8	1,25	16	-	16	4,4	5,0	200	✓	27,77 €
FHC8-20/SS/B	M8	1,25	20	-	16	4,4	5,0	200	✓	29,63 €
FHC8-25/SS/B	M8	1,25	25	-	16	4,4	5,0	100	✓	17,52 €
FHC8-30/SS/B	M8	1,25	30	-	16	4,4	5,0	100	✓	20,63 €
FHC8-40/SS/B	M8	1,25	40	-	16	4,4	5,0	100	✓	25,48 €
FHC8-50/SS/B	M8	1,25	50	-	16	4,4	5,0	100	✓	35,62 €
FHC10-35/SS/B	M10	1,50	35	-	20	5,5	6,0	100	✓	37,72 €
FHC10-40/SS/B	M10	1,50	40	-	20	5,5	6,0	100	⚠	33,62 €
FHC10-50/SS/B	M10	1,50	50	32	20	5,5	6,0	100	-	41,15 €
FHC12-30/SS/B	M12	1,75	30	-	24	6,5	8,0	50	⚠	20,42 €
FHC12-40/SS/B	M12	1,75	40	36	24	6,5	8,0	50	-	25,56 €
FHC12-50/SS/B	M12	1,75	50	36	24	6,5	8,0	50	-	30,27 €
FHC12-60/SS/B	M12	1,75	60	36	24	6,5	8,0	50	-	39,55 €
FHC12-70/SS/B	M12	1,75	70	36	24	6,5	8,0	50	-	44,29 €
FHC12-80/SS/B	M12	1,75	80	36	24	6,5	8,0	50	-	51,43 €

*Depending on availability - Dimensions in mm

Our other products



RIMple

Locking castor, with mounting plate




CHM40

Worm and wheel gear reducer, up to 57 Nm



VTAP

 Magnetic head screw, With rubber coating
With rubber coating



TPR

High helix leadscrew, Leadscrew only - up to 40mm per rotation



HLA19

Right angle spiro bevel gearbox, Up to 43Nm



TBE16

Economic mini-table with trapezoidal leadscrew, 5kg



SLBWSS

Indexing plunger, weldable, Weldable - Stainless steel



F7-SF-SM

Multifunction display, Mounting bracket for front mounting



GCA

Linch pin, Linch



CLQ

12.7mm wide steel feeler strip on rolls, Feeler strip on rolls



UGH16

H Type Guide units, For Ø12 and Ø16 actuators



SH2

Parallel axis helical gear, Machined plastic (delrin)

Complementary products



SHN

Hexagonal nut DIN934, A2 Stainless steel



CHA35

Hinge for aluminium profile, Hinge



ACLCHARJ

Hinge for aluminium profile, Adjusts in 2 directions



NIN

Self-locking nut, A2 Stainless steel