

Countersunk screw **DIN 7991**

Sta **DIN**

FHCss

Stainless steel A2


- Material: Stainless steel 302/304 - A2
- Hexagonal socket
- Sold by the packet

Uses

- Suitable for harsh environments

Info.


- Dimension B is for information only and can vary depending on manufacture

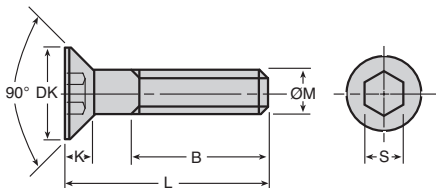

Designer's Note

Countersunk heads

Thread	ØF (H13)		T
	num.	max.	
M3	6,60	6,82	1,60
M4	9,80	10,02	2,65
M5	10,90	11,17	2,70
M6	13,20	13,47	3,30
M8	18,10	18,43	4,55
M10	21,00	21,33	5,00
M12	25,20	25,53	5,85

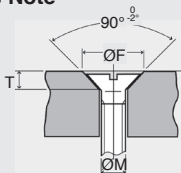

DISCOUNTS

N° packets	1+	2+	4+
Disc.	List	-20%	On request

Part number	Thread		Total length L	B	DK	K	S	Qty per packet	Stock*	Price per packet
	ØM	Pitch								
FHC3-8/SS/B	M3	0,50	8	-	6	1,6	2,0	500	✓	21,59 €
FHC3-12/SS/B	M3	0,50	12	-	6	1,6	2,0	500	✓	23,56 €
FHC3-16/SS/B	M3	0,50	16	-	6	1,6	2,0	500	✓	23,91 €
FHC3-20/SS/B	M3	0,50	20	-	6	1,6	2,0	500	✓	25,70 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

DISCOUNTS

N° packets	1+	2+	4+
Disc.	List	-20%	On request

Part number	Thread		Total length L	B	DK	K	S	Qty per packet	Stock*	Price per packet
	ØM	Pitch								
FHC4-10/SS/B	M4	0,70	10	-	8	2,3	2,5	500	✓	14,81 €
FHC4-12/SS/B	M4	0,70	12	-	8	2,3	2,5	500	✓	13,92 €
FHC4-16/SS/B	M4	0,70	16	-	8	2,3	2,5	500	✓	20,87 €
FHC4-20/SS/B	M4	0,70	20	-	8	2,3	2,5	500	✓	20,87 €
FHC4-25/SS/B	M4	0,70	25	-	8	2,3	2,5	500	✓	31,77 €
FHC4-30/SS/B	M4	0,70	30	20	8	2,3	2,5	200	✓	15,63 €
FHC5-10/SS/B	M5	0,80	10	-	10	2,8	3,0	500	✓	26,59 €
FHC5-12/SS/B	M5	0,80	12	-	10	2,8	3,0	500	✓	22,66 €
FHC5-16/SS/B	M5	0,80	16	-	10	2,8	3,0	500	✓	29,98 €
FHC5-20/SS/B	M5	0,80	20	-	10	2,8	3,0	500	✓	35,51 €
FHC5-25/SS/B	M5	0,80	25	-	10	2,8	3,0	500	✓	37,12 €
FHC5-30/SS/B	M5	0,80	30	-	10	2,8	3,0	200	✓	18,27 €
FHC5-35/SS/B	M5	0,80	35	22	10	2,8	3,0	200	✓	23,41 €
FHC6-10/SS/B	M6	1,00	10	-	12	3,3	4,0	500	✓	27,30 €
FHC6-12/SS/B	M6	1,00	12	-	12	3,3	4,0	500	✓	35,87 €
FHC6-16/SS/B	M6	1,00	16	-	12	3,3	4,0	500	✓	36,23 €
FHC6-20/SS/B	M6	1,00	20	-	12	3,3	4,0	200	✓	16,63 €
FHC6-25/SS/B	M6	1,00	25	-	12	3,3	4,0	200	✓	20,56 €
FHC6-30/SS/B	M6	1,00	30	-	12	3,3	4,0	200	✓	23,99 €
FHC6-35/SS/B	M6	1,00	35	-	12	3,3	4,0	200	✓	21,91 €
FHC6-40/SS/B	M6	1,00	40	-	12	3,3	4,0	200	✓	31,13 €
FHC6-45/SS/B	M6	1,00	45	-	12	3,3	4,0	100	-	13,99 €
FHC6-60/SS/B	M6	1,00	60	20	12	3,3	4,0	100	-	21,70 €
FHC6-70/SS/B	M6	1,00	70	20	12	3,3	4,0	100	-	30,87 €
FHC8-16/SS/B	M8	1,25	16	-	16	4,4	5,0	200	✓	27,77 €
FHC8-20/SS/B	M8	1,25	20	-	16	4,4	5,0	200	✓	29,63 €
FHC8-25/SS/B	M8	1,25	25	-	16	4,4	5,0	100	✓	17,52 €
FHC8-30/SS/B	M8	1,25	30	-	16	4,4	5,0	100	✓	20,63 €
FHC8-40/SS/B	M8	1,25	40	-	16	4,4	5,0	100	✓	25,48 €
FHC8-50/SS/B	M8	1,25	50	-	16	4,4	5,0	100	✓	35,62 €
FHC10-35/SS/B	M10	1,50	35	-	20	5,5	6,0	100	✓	37,72 €
FHC10-40/SS/B	M10	1,50	40	-	20	5,5	6,0	100	⚠	33,62 €
FHC10-50/SS/B	M10	1,50	50	32	20	5,5	6,0	100	-	41,15 €
FHC12-30/SS/B	M12	1,75	30	-	24	6,5	8,0	50	⚠	20,42 €
FHC12-40/SS/B	M12	1,75	40	36	24	6,5	8,0	50	-	25,56 €
FHC12-50/SS/B	M12	1,75	50	36	24	6,5	8,0	50	-	30,27 €
FHC12-60/SS/B	M12	1,75	60	36	24	6,5	8,0	50	-	39,55 €
FHC12-70/SS/B	M12	1,75	70	36	24	6,5	8,0	50	-	44,29 €
FHC12-80/SS/B	M12	1,75	80	36	24	6,5	8,0	50	-	51,43 €

*Depending on availability - Dimensions in mm

Our other products



NJM

Multiple junction clamp, Multiple



CABma

Swaging sleeve for fitting cable, To crimp a wire rope



PCS3755

Chain sprocket - Stainless steel, 9.525 (DIN 06B-1)



TMR

Rigid manual tensioner, Adjustable



ZA

Shaft for linear guides, Hardened ground steel



BHC

Socket head button screw, Stainless steel A2



MPE

Hexagonal spacer, Steel



 
MHQMEP

Arm with rotating handle, Square bore



CHTRP

Single and dual output gearboxes, Up to 34,5 Nm



TIFbout

Threaded stud - DIN976A, Steel



ACAss

Stainless steel splined shaft, Stainless steel



DOG316

Motor-gearbox 12V and 24V DC, from 1.5 to 2 Nm

Complementary products



SHN

Hexagonal nut DIN934, A2 Stainless steel



CHA35

Hinge for aluminium profile, Hinge



ACLCHARJ

Hinge for aluminium profile, Adjusts in 2 directions



NIN

Self-locking nut, A2 Stainless steel