

Damping torque from 2 to 3 Ncm




FRTC FRNC

- Supplied with a spur gear
- Working temperature from 0°C to +50°C
- Max. speed 50 rpm
- Damping torque varies depending on the speed of rotation and the temperature: see table below
- Data given based on life of 50,000 cycles
- Materials:

Casing: polycarbonate

Gear: polyacetal

Fluid: silicone

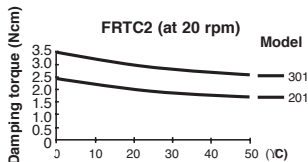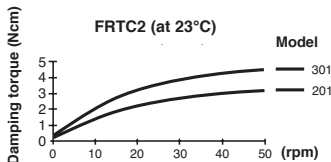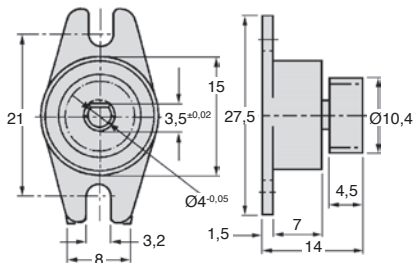

DISCOUNTS

Qty	1+	6+	20+	40+
Disc. List	-	-15%	-20%	On request

Part number	No of teeth	Module	PCD (mm)	Damping torque (Ncm)	Stock*	Price each 1 to 5
Bidirectional						
FRTC2201G1	11	0,8	8,8	2 $\pm 0,6$	-	22,72 €
FRTC2301G1	11	0,8	8,8	3 $\pm 0,8$	✓	22,72 €
Unidirectional (clockwise)						
FRNC2R201G1	11	0,8	8,8	2 $\pm 0,6$	✓	27,01 €
Unidirectional (anticlockwise)						
FRNC2L201G1	11	0,8	8,8	2 $\pm 0,6$	✓	27,01 €

*Depending on availability - Dimensions in mm

Our other products



PDD

Spring operated plunger, Non-rotating detector shaft



PM4

Worm, Non hardened steel




INS_BR

Self tapping insert, Brass



DG1

 Double spur gear, Steel 20NCD2



CDRs

Ball pin, Retaining cable



CHA138

Screw-in hinge, 138 degrees



G0

Spur gear, Steel 20NCD2



PEM

Magnetic label holder, Flexible magnet 100mm



H3

90° crossed axis helical gear, Machined plastic (delrin)



SH4

Parallel axis helical gear, Steel 20NCD2



PXHG25

Crossed helical gear - precision range, 35NCD6 Pre-hardened steel



BPM-Z

Slotted spring plunger with ball tip, Plastic body + stainless steel ball

Complementary products



ZG0

Spur gear, Machined plastic (delrin)