

Thread inserts

FR_{TOOL}

Assembly tool



✓ INCREASED STOCK

DISCOUNTS

Qty	1+	10+	20+	30+	50+
Disc.	List	-5%	-10%	-15%	On request

Part number	Corresponding diameter D1	Stock*	Price each 1 to 9
FR-M5/TOOL	M5	✓	31,05 €
FR-M6/TOOL	M6	✓	32,08 €
FR-M8/TOOL	M8, M8x1	✓	33,46 €
FR-M10/TOOL	M10, M10x1,25	✓	35,86 €
FR-M12/TOOL	M12, M12x1,25	✓	38,74 €

 
*Depending on availability - Dimensions in mm

Our other products



WINGbrEcrou

Manually tightened wing nut DIN315, Brass DIN 315



PF40NM

Worm and wheel gear reducer, up to 18 Nm



M2

Worm and wheel set, Bronze



RFK58B

Hypoid gearbox - Stainless steel, up to 500 Nm



AC

Strike for toggle latch, 15mm



SLB

Indexing plunger, stainless steel



ZA

Shaft for linear guides, Hardened ground steel



PSG15

Spur gear - precision range, Case hardened steel 20NCD2



FTSN

Supported shaft for linear guide, Steel shaft / Aluminium



NPTF30

Spacer for tube carrier, Fixing accessory $\varnothing 14$ to $\varnothing 20$



CHA_GC_95S

Stainless steel garnet hinge, To be welded



T39_T49


Extension spring in metre length steel, by the metre

Complementary products



FR

Steel thread inserts, Steel

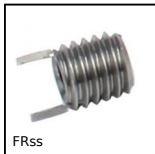

FRss

Stainless steel thread inserts, Stainless steel