


## FTSN

## Mounts without sagging or deformation

- **Comprises a shaft and its support**
- Normally used where the load is heavy when compared to the shaft length
- Shaft support has closely spaced pre-drilled mounting holes
- Material:
  - Support: Ground aluminium
  - Shaft: CK55 steel hardened ( 62HRC) and ground


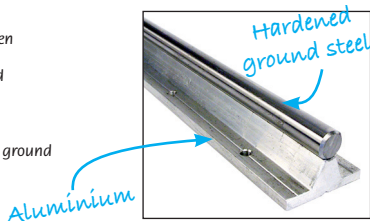


### Options

- Other lengths possible (up to 6000mm)

### Accessories

- **KB-OP** and **TK-OB** linear bearings

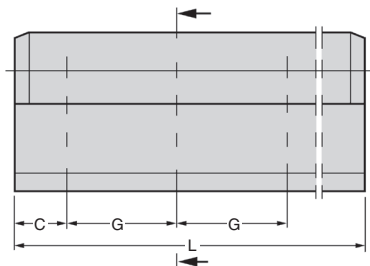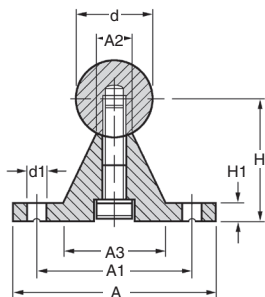

### DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-20%	On request

Part number	d	A	H	A1	A2	A3	H1	C	d1	G	Standard length (mm)	Stock*	Price each
FTSN-12G	12	40	22	29	5,4	15	5	37,5	4,5	75	1000	✓	296,69 €
FTSN-16G	16	45	26	33	7,0	19	5	50,0	5,5	100	1000	✓	228,23 €
FTSN-20G	20	52	32	37	8,1	23	6	50,0	6,6	100	1000	✓	262,46 €
FTSN-25G	25	57	36	42	10,3	26	6	60,0	6,6	120	1000	✓	279,56 €
FTSN-30G	30	69	42	51	11,0	29	7	75,0	9,0	150	1000	-	365,17 €
FTSN-40G	40	73	50	55	15,0	36	9	100,0	9,0	200	1000	-	456,51 €


\*Depending on availability - Dimensions in mm

## Our other products



MFB

Flexible bellows coupling, Aluminium and Bronze - With set screw

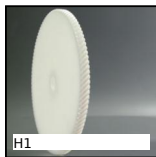

H1

Crossed helical gear crossed axis at 90°, Machined plastic (delrin)



PCF4

Conical flexible mount, Square base plate



PTMR

Telescopic furniture foot, threaded stud plate



SLVVlok

Vertical toggle clamp, Vertical toggle clamp / vertical foot



DB

Steel bevel gear, 2:1



WJUM10

Drylin® W bearing block, Slide



 
BOX-TOR-INCH

Box set of Nitrile O-rings in inch NBR90Sh A, For fasteners and fittings...



ETP

Modular handle for aluminium profile, Modular handle



CAB

Stainless steel cable, Stainless steel



AT5-BAR

AT type tooth bar stock, AT5



SCE\_SS

Stainless steel U-shaped clamp, Stainless steel

## Complementary products



KB\_OP

Open precision linear bearing, Precision - steel



KB\_OP

Open precision linear bearing, Precision - steel



TK\_UUOP

Topball self-aligning linear bearing, Topball self-aligning



ZAmm

Shaft for linear guides, Hardened ground steel