


FTSN

Mounts without sagging or deformation

- **Comprises a shaft and its support**
- Normally used where the load is heavy when compared to the shaft length
- Shaft support has closely spaced pre-drilled mounting holes
- Material:
 - Support: Ground aluminium
 - Shaft: CK55 steel hardened (62HRC) and ground


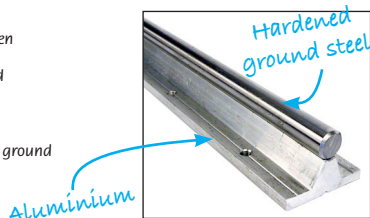


Options

- Other lengths possible (up to 6000mm)

Accessories

- **KB-OP** and **TK-OB** linear bearings

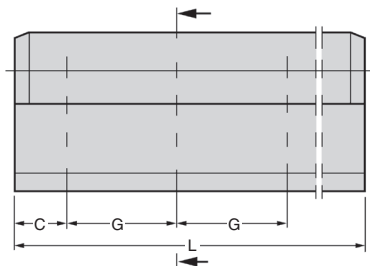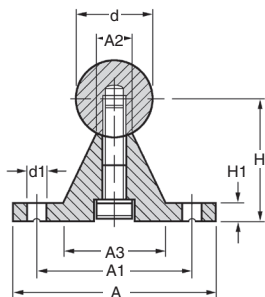

DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-20%	On request

Part number	d	A	H	A1	A2	A3	H1	C	d1	G	Standard length (mm)	Stock*	Price each
FTSN-12G	12	40	22	29	5,4	15	5	37,5	4,5	75	1000	✓	296,69 €
FTSN-16G	16	45	26	33	7,0	19	5	50,0	5,5	100	1000	✓	228,23 €
FTSN-20G	20	52	32	37	8,1	23	6	50,0	6,6	100	1000	✓	262,46 €
FTSN-25G	25	57	36	42	10,3	26	6	60,0	6,6	120	1000	✓	279,56 €
FTSN-30G	30	69	42	51	11,0	29	7	75,0	9,0	150	1000	-	365,17 €
FTSN-40G	40	73	50	55	15,0	36	9	100,0	9,0	200	1000	-	456,51 €

*Depending on availability - Dimensions in mm

Our other products



MDB_MTB
Moulded plastic bevel gear (nylon), 2:1



BS2
Panamech, Multi-Beam, Aluminium - with set screw



TPEf
Castor for aluminium profile, Fixed



BPVM
Miniature ball transfer unit, Miniature to screw




TBE12
Economic mini-table with trapezoidal leadscrew, 2kg



IN1
Internal gear, Steel 20NCD2



 
ACLBD8
Closing mechanism for aluminium profile, Dual ball catch



ZR
Plastic rack, Delrin



 BAN
Angular clamp, Universal



LRH
Bi-directional leadscrew, Bi-



UGPL
Actuator guide kit, Long bearing



PW_PWG05
Worm - precision range, Stainless steel

Complementary products



KB_OP
Open precision linear bearing, Precision - steel



KB_OP
Open precision linear bearing, Precision - steel



TK_UUOP
Topball self-aligning linear bearing, Topball self-aligning



ZAmm
Shaft for linear guides, Hardened ground steel