

## FTSN

## Mounts without sagging or deformation

- Comprises a shaft and its support
- Normally used where the load is heavy when compared to the shaft length
- Shaft support has closely spaced pre-drilled mounting holes
- Material:

Support: Ground aluminium




Shaft: CK55 steel hardened ( 62HRC) and ground

### Options

- Other lengths possible (up to 6000mm)

### Accessories

- KB-OP (tome 3 p.266) linear bearing
- TK-OB (tome 3 p.267) linear bearing

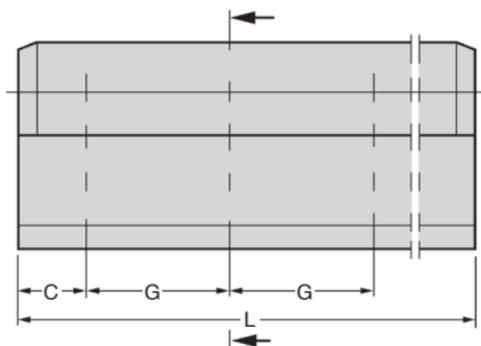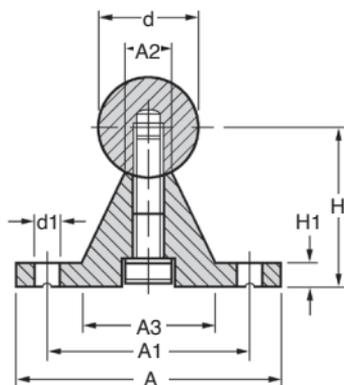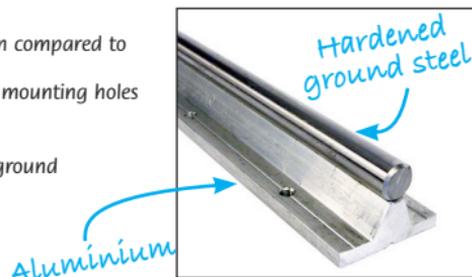

### DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-20%	On request

Part number	d	A	H	A1	A2	A3	H1	C	d1	G	Standard length (mm)	Stock*	Price each
												✓	
FTSN-12G	12	40	22	29	5,4	15	5	37,5	4,5	75	1000	✓	363,18 €
FTSN-16G	16	45	26	33	7,0	19	5	50,0	5,5	100	1000	✓	279,38 €
FTSN-20G	20	52	32	37	8,1	23	6	50,0	6,6	100	1000	✓	321,28 €
FTSN-25G	25	57	36	42	10,3	26	6	60,0	6,6	120	1000	✓	342,22 €
FTSN-30G	30	69	42	51	11,0	29	7	75,0	9,0	150	1000	-	447,01 €
FTSN-40G	40	73	50	55	15,0	36	9	100,0	9,0	200	1000	-	558,82 €

\*Depending on availability - Dimensions in mm