


MODULE 0.25

Stainless steel 303

- **Quality standard 9**
- Pressure angle 20°
- Material:
stainless steel (303) Z10CNF18.09
- Linear speed 300m/min

Torque and power indication				
For 50 teeth at 1000 rpm				
	20NCD2 Z10CNF18.09	20NCD2 hardened	brass	fibre
Nm	0.050	0.230	0.024	0.019
kW	0.005	0.031	0.002	0.002

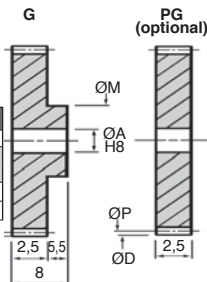

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part number	Teeth Z	PCD ØP	Outside ØD	Boss ØM	Bore ØA	Weight (kg)		Price each 1 to 5	
						G	PG	G	PG
G0.25-20	20	5,00	5,50	5,50	2	0,0004	0,0003	20,50 €	On request
G0.25-21	21	5,25	5,75	5,75	2	0,0004	0,0004	20,71 €	
G0.25-22	22	5,50	6,00	6,00	2	0,0005	0,0004	20,82 €	
G0.25-23	23	5,75	6,25	6,25	2	0,0005	0,0004	25,98 €	
G0.25-24	24	6,00	6,50	6,50	2	0,0005	0,0005	21,21 €	
G0.25-25	25	6,25	6,75	6,75	2	0,0006	0,0005	26,48 €	
G0.25-26	26	6,50	7,00	7,00	2	0,0006	0,0006	21,53 €	
G0.25-27	27	6,75	7,25	7,25	2	0,0007	0,0006	26,86 €	
G0.25-28	28	7,00	7,50	7,50	2	0,0007	0,0007	27,01 €	
G0.25-29	29	7,25	7,75	7,75	2	0,0008	0,0007	27,29 €	
G0.25-30	30	7,50	8,00	8,00	3	0,0008	0,0007	27,54 €	
G0.25-31	31	7,75	8,25	8,00	3	0,0009	0,0008	27,71 €	
G0.25-32	32	8,00	8,50	8,00	3	0,0010	0,0008	27,92 €	
G0.25-33	33	8,25	8,75	8,00	3	0,0010	0,0009	28,19 €	
G0.25-34	34	8,50	9,00	8,00	3	0,0011	0,0010	28,41 €	
G0.25-35	35	8,75	9,25	8,00	3	0,0012	0,0010	28,70 €	
G0.25-36	36	9,00	9,50	8,00	3	0,0012	0,0011	28,95 €	
G0.25-37	37	9,25	9,75	8,00	3	0,0013	0,0012	29,17 €	
G0.25-38	38	9,50	10,00	8,00	3	0,0014	0,0012	23,79 €	
G0.25-39	39	9,75	10,25	8,00	3	0,0014	0,0013	23,93 €	
G0.25-40	40	10,00	10,50	8,00	3	0,0015	0,0014	24,13 €	
G0.25-41	41	10,25	10,75	8,00	3	0,0016	0,0014	30,04 €	
G0.25-42	42	10,50	11,00	8,00	3	0,0017	0,0015	30,30 €	

Dimensions in mm

Part number	Teeth Z	PCD ØP	Outside ØD	Boss ØM	Bore ØA	Weight (kg)		Price each 1 to 5	
						G	PG	G	PG
G0.25-43	43	10,75	11,25	8,00	3	0,0017	0,0016	30,48 €	
G0.25-44	44	11,00	11,50	8,00	3	0,0018	0,0017	30,67 €	
G0.25-45	45	11,25	11,75	8,00	3	0,0019	0,0018	30,88 €	
G0.25-46	46	11,50	12,00	8,00	3	0,0020	0,0019	31,13 €	
G0.25-47	47	11,75	12,25	8,00	3	0,0021	0,0019	31,37 €	
G0.25-48	48	12,00	12,50	10,00	3	0,0022	0,0020	31,57 €	
G0.25-49	49	12,25	12,75	10,00	3	0,0023	0,0021	31,79 €	
G0.25-50	50	12,50	13,00	10,00	3	0,0023	0,0022	32,00 €	
G0.25-52	52	13,00	13,50	10,00	3	0,0025	0,0024	32,16 €	
G0.25-55	55	13,75	14,25	10,00	3	0,0028	0,0027	26,58 €	
G0.25-60	60	15,00	15,50	12,00	4	0,0034	0,0031	33,53 €	
G0.25-62	62	15,50	16,00	12,00	4	0,0036	0,0034	33,76 €	
G0.25-63	63	15,75	16,25	12,00	4	0,0037	0,0035	33,93 €	
G0.25-64	64	16,00	16,50	12,00	4	0,0038	0,0036	34,27 €	
G0.25-65	65	16,25	16,75	12,00	4	0,0040	0,0037	34,63 €	
G0.25-68	68	17,00	17,50	12,00	4	0,0043	0,0041	28,23 €	
G0.25-70	70	17,50	18,00	12,00	4	0,0046	0,0044	28,41 €	
G0.25-72	72	18,00	18,50	12,00	4	0,0049	0,0046	35,52 €	
G0.25-75	75	18,75	19,25	12,00	4	0,0053	0,0050	35,76 €	
G0.25-76	76	19,00	19,50	12,00	4	0,0054	0,0052	36,13 €	
G0.25-80	80	20,00	20,50	12,00	4	0,0060	0,0058	36,48 €	
G0.25-84	84	21,00	21,50	12,00	4	0,0066	0,0064	29,63 €	
G0.25-86	86	21,50	22,00	12,00	4	0,0069	0,0067	29,75 €	
G0.25-88	88	22,00	22,50	12,00	4	0,0073	0,0070	36,97 €	
G0.25-90	90	22,50	23,00	12,00	4	0,0076	0,0074	37,07 €	
G0.25-93	93	23,25	23,75	12,00	4	0,0081	0,0079	37,28 €	
G0.25-95	95	23,75	24,25	12,00	4	0,0085	0,0082	37,61 €	
G0.25-96	96	24,00	24,50	12,00	4	0,0087	0,0084	37,75 €	
G0.25-97	97	24,25	24,75	12,00	4	0,0088	0,0086	37,92 €	
G0.25-99	99	24,75	25,25	12,00	4	0,0092	0,0090	38,07 €	
G0.25-100	100	25,00	25,50	12,00	4	0,0094	0,0092	38,29 €	
G0.25-108	108	27,00	27,50	12,00	4	0,0110	0,0107	38,58 €	
G0.25-110	110	27,50	28,00	12,00	4	0,0114	0,0111	38,82 €	
G0.25-115	115	28,75	29,25	12,00	4	0,0124	0,0122	39,20 €	
G0.25-120	120	30,00	30,50	12,00	4	0,0135	0,0133	39,86 €	
G0.25-124	124	31,00	31,50	12,00	4	0,0144	0,0142	40,43 €	
G0.25-127	127	31,75	32,25	12,00	4	0,0151	0,0149	40,95 €	
G0.25-130	130	32,50	33,00	12,00	4	0,0159	0,0156	41,59 €	
G0.25-132	132	33,00	33,50	12,00	4	0,0164	0,0161	42,36 €	
G0.25-136	136	34,00	34,50	12,00	4	0,0174	0,0171	44,27 €	
G0.25-140	140	35,00	35,50	12,00	4	0,0184	0,0182	46,09 €	
G0.25-148	148	37,00	37,50	12,00	4	0,0206	0,0203	49,18 €	
G0.25-150	150	37,50	38,00	12,00	4	0,0211	0,0209	53,66 €	
G0.25-156	156	39,00	39,50	12,00	4	0,0229	0,0226	57,44 €	
G0.25-180	180	45,00	45,50	12,00	4	0,0304	0,0302	49,71 €	
G0.25-200	200	50,00	50,50	12,00	4	0,0376	0,0373	72,07 €	
G0.25-250	250	62,50	63,00	20,00	6	0,0587	0,0585	62,88 €	
↓ Gears available up to this size ↓									
G0.25-558	558	139,50	140,00	Dimensions: contact us				On request	

On request

Our other products



PRF_ECL
Nut for aluminium
profile, Steel square
nut with tab



LRR
Catch-plate for latch,
Catch-plate



BMF
Knurled knob -
female, Knurled -
blind



AZY
Cylindrical elasto
mount, Steel




LRR
Spring loaded latch,
Spring loaded latch



PDD
Spring plunger, With
sensor adaptor



ACLCHAR
Hinge for aluminium
profile, With
elongated holes

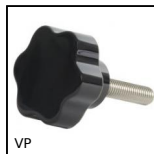

VP
Small 6 lobe threaded
handle - male,
Duroplast - Steel



AT5P_AT10P
Connecting plate for
AT type timing belts,
Steel



BDPR
Holding arm, Rigid



ATZY
Diabolo shaped elasto
mount, Steel

 


SCA
Flat cable clamp,
Steel

Complementary products



SR
Narrow spur rack,
Stainless steel



TR
Spur round rack,
Stainless steel -
module 0,25-1,5