

Steel spur gear




Module 0.5

Steel 20NCD2



- Precision class 9
- Pressure angle 20°
- Linear speed 300m/min

| Torque and power indication | | | |
|-----------------------------|-------------|----------|-------|
| For 50 teeth at 1000 rpm | | | |
| | 20NCD2 | 20NCD2 | |
| | Z10CNF18.09 | hardened | brass |
| Nm | 0.391 | 1.850 | 0.195 |
| kW | 0.041 | 0.194 | 0.021 |

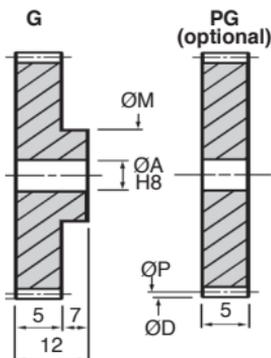

DISCOUNTS

| Qty | 1+ | 6+ | 20+ | 50+ |
|-------|------|------|------|------------|
| Disc. | List | -12% | -25% | On request |

| Part number | Teeth Z | PCD ØP | External ØD | Boss ØM | Bore ØA | Weight G | (kg) PG | Stock* | Price each 1 to 5 | |
|-------------|---------|--------|-------------|---------|---------|----------|---------|--------|-------------------|----|
| | | | | | | | | | G | PG |
| G0.5-20 | 20 | 10,00 | 11,00 | 8,50 | 4 | 0,0049 | 0,0025 | ✓ | 28,42 € | |
| G0.5-21 | 21 | 10,50 | 11,50 | 8,50 | 4 | 0,0052 | 0,0028 | - | 28,71 € | |
| G0.5-22 | 22 | 11,00 | 12,00 | 8,50 | 4 | 0,0055 | 0,0032 | - | 28,99 € | |
| G0.5-23 | 23 | 11,50 | 12,50 | 8,50 | 4 | 0,0059 | 0,0035 | ✓ | 29,39 € | |
| G0.5-24 | 24 | 12,00 | 13,00 | 10,00 | 5 | 0,0067 | 0,0036 | ✓ | 29,69 € | |
| G0.5-25 | 25 | 12,50 | 13,50 | 10,00 | 5 | 0,0071 | 0,0039 | ✓ | 30,04 € | |
| G0.5-26 | 26 | 13,00 | 14,00 | 10,00 | 5 | 0,0075 | 0,0043 | - | 30,42 € | |
| G0.5-27 | 27 | 13,50 | 14,50 | 10,00 | 5 | 0,0079 | 0,0047 | - | 30,84 € | |
| G0.5-28 | 28 | 14,00 | 15,00 | 10,00 | 5 | 0,0083 | 0,0051 | ✓ | 31,28 € | |
| G0.5-29 | 29 | 14,50 | 15,50 | 10,00 | 5 | 0,0087 | 0,0056 | - | 31,28 € | |
| G0.5-30 | 30 | 15,00 | 16,00 | 10,00 | 5 | 0,0092 | 0,0060 | ✓ | 31,43 € | |
| G0.5-31 | 31 | 15,50 | 16,50 | 10,00 | 5 | 0,0096 | 0,0065 | - | 31,83 € | |
| G0.5-32 | 32 | 16,00 | 17,00 | 10,00 | 5 | 0,0101 | 0,0069 | ✓ | 32,22 € | |
| G0.5-33 | 33 | 16,50 | 17,50 | 10,00 | 5 | 0,0106 | 0,0074 | - | 32,48 € | |
| G0.5-34 | 34 | 17,00 | 18,00 | 10,00 | 5 | 0,0111 | 0,0079 | - | On request | |
| G0.5-35 | 35 | 17,50 | 18,50 | 10,00 | 5 | 0,0116 | 0,0085 | - | 33,33 € | |
| G0.5-36 | 36 | 18,00 | 19,00 | 10,00 | 5 | 0,0121 | 0,0090 | ✓ | 33,63 € | |
| G0.5-37 | 37 | 18,50 | 19,50 | 10,00 | 5 | 0,0127 | 0,0095 | - | 34,00 € | |
| G0.5-38 | 38 | 19,00 | 20,00 | 10,00 | 5 | 0,0133 | 0,0101 | - | 34,27 € | |
| G0.5-39 | 39 | 19,50 | 20,50 | 10,00 | 5 | 0,0138 | 0,0107 | - | 34,65 € | |
| G0.5-40 | 40 | 20,00 | 21,00 | 10,00 | 5 | 0,0144 | 0,0113 | ✓ | 34,99 € | |

On request

*Depending on availability - Dimensions in mm

DISCOUNTS

| | | | | |
|-------|------|------|------|------------|
| Qty | 1+ | 6+ | 20+ | 50+ |
| Disc. | List | -12% | -25% | On request |

| Part number | Teeth Z | PCD ØP | External ØD | Boss ØM | Bore ØA | Weight G | (kg) PG | Price each 1 to 5 G | PG |
|-------------|---------|--------|-------------|---------|---------|----------|---------|---------------------|------------|
| G0.5-41 | 41 | 20,50 | 21,50 | 10,00 | 5 | 0,0150 | 0,0119 | - | 35,39 € |
| G0.5-42 | 42 | 21,00 | 22,00 | 10,00 | 5 | 0,0157 | 0,0125 | - | 35,77 € |
| G0.5-43 | 43 | 21,50 | 22,50 | 10,00 | 5 | 0,0163 | 0,0131 | - | 36,00 € |
| G0.5-44 | 44 | 22,00 | 23,00 | 10,00 | 5 | 0,0169 | 0,0138 | ✓ | 36,41 € |
| G0.5-45 | 45 | 22,50 | 23,50 | 10,00 | 5 | 0,0176 | 0,0145 | - | 36,77 € |
| G0.5-46 | 46 | 23,00 | 24,00 | 10,00 | 5 | 0,0183 | 0,0151 | - | On request |
| G0.5-47 | 47 | 23,50 | 24,50 | 10,00 | 5 | 0,0190 | 0,0158 | - | 37,46 € |
| G0.5-48 | 48 | 24,00 | 25,00 | 10,00 | 5 | 0,0197 | 0,0166 | ✓ | 38,29 € |
| G0.5-49 | 49 | 24,50 | 25,50 | 10,00 | 5 | 0,0204 | 0,0173 | ✓ | 38,29 € |
| G0.5-50 | 50 | 25,00 | 26,00 | 12,00 | 6 | 0,0222 | 0,0177 | ✓ | 38,65 € |
| G0.5-51 | 51 | 25,50 | 26,50 | 12,00 | 6 | 0,0230 | 0,0185 | - | 38,92 € |
| G0.5-52 | 52 | 26,00 | 27,00 | 12,00 | 6 | 0,0238 | 0,0192 | - | 39,13 € |
| G0.5-53 | 53 | 26,50 | 27,50 | 12,00 | 6 | 0,0246 | 0,0200 | - | 39,48 € |
| G0.5-54 | 54 | 27,00 | 28,00 | 12,00 | 6 | 0,0254 | 0,0208 | ✓ | 39,68 € |
| G0.5-55 | 55 | 27,50 | 28,50 | 12,00 | 6 | 0,0262 | 0,0216 | - | 39,97 € |
| G0.5-56 | 56 | 28,00 | 29,00 | 12,00 | 6 | 0,0270 | 0,0225 | - | 40,21 € |
| G0.5-57 | 57 | 28,50 | 29,50 | 12,00 | 6 | 0,0279 | 0,0233 | - | 40,50 € |
| G0.5-58 | 58 | 29,00 | 30,00 | 12,00 | 6 | 0,0287 | 0,0242 | - | 40,77 € |
| G0.5-59 | 59 | 29,50 | 30,50 | 12,00 | 6 | 0,0296 | 0,0251 | - | 41,04 € |
| G0.5-60 | 60 | 30,00 | 31,00 | 12,00 | 6 | 0,0305 | 0,0260 | ✓ | 41,30 € |
| G0.5-61 | 61 | 30,50 | 31,50 | 12,00 | 6 | 0,0314 | 0,0269 | - | 41,47 € |
| G0.5-62 | 62 | 31,00 | 32,00 | 12,00 | 6 | 0,0323 | 0,0278 | - | 41,78 € |
| G0.5-64 | 64 | 32,00 | 33,00 | 12,00 | 6 | 0,0342 | 0,0297 | ✓ | 42,36 € |
| G0.5-65 | 65 | 32,50 | 33,50 | 12,00 | 6 | 0,0352 | 0,0307 | - | 42,67 € |
| G0.5-68 | 68 | 34,00 | 35,00 | 12,00 | 6 | 0,0382 | 0,0337 | - | 42,91 € |
| G0.5-70 | 70 | 35,00 | 36,00 | 12,00 | 6 | 0,0403 | 0,0357 | ✓ | 43,43 € |
| G0.5-72 | 72 | 36,00 | 37,00 | 12,00 | 6 | 0,0424 | 0,0379 | ✓ | 43,86 € |
| G0.5-75 | 75 | 37,50 | 38,50 | 12,00 | 6 | 0,0457 | 0,0412 | - | 44,21 € |
| G0.5-77 | 77 | 38,50 | 39,50 | 12,00 | 6 | 0,0480 | 0,0435 | - | 44,72 € |
| G0.5-80 | 80 | 40,00 | 41,00 | 12,00 | 6 | 0,0515 | 0,0470 | ✓ | 45,15 € |
| G0.5-84 | 84 | 42,00 | 43,00 | 12,00 | 6 | 0,0565 | 0,0519 | ✓ | 45,49 € |
| G0.5-86 | 86 | 43,00 | 44,00 | 12,00 | 6 | 0,0590 | 0,0545 | - | 46,08 € |
| G0.5-88 | 88 | 44,00 | 45,00 | 12,00 | 6 | 0,0616 | 0,0571 | - | 46,44 € |
| G0.5-90 | 90 | 45,00 | 46,00 | 12,00 | 6 | 0,0643 | 0,0598 | ✓ | 47,01 € |
| G0.5-96 | 96 | 48,00 | 49,00 | 12,00 | 6 | 0,0727 | 0,0682 | - | 47,42 € |
| G0.5-100 | 100 | 50,00 | 51,00 | 12,00 | 6 | 0,0786 | 0,0740 | ✓ | 47,58 € |
| G0.5-120 | 120 | 60,00 | 61,00 | 18,00 | 6 | 0,1116 | 0,1071 | ✓ | 57,60 € |
| G0.5-140 | 140 | 70,00 | 71,00 | 18,00 | 6 | 0,1507 | 0,1462 | - | 68,83 € |
| G0.5-150 | 150 | 75,00 | 76,00 | 18,00 | 6 | 0,1725 | 0,1679 | - | 74,84 € |
| G0.5-180 | 180 | 90,00 | 91,00 | 20,00 | 8 | 0,2469 | 0,2423 | - | 84,69 € |
| G0.5-200 | 200 | 100,00 | 101,00 | 20,00 | 8 | 0,3040 | 0,2994 | - | 92,48 € |
| G0.5-220 | 220 | 110,00 | 111,00 | 20,00 | 10 | 0,3671 | 0,3625 | - | 100,84 € |
| G0.5-250 | 250 | 125,00 | 126,00 | 20,00 | 10 | 0,4730 | 0,4684 | - | 110,84 € |

On request

↓ **Gears available up to this size**

G0.5-278 278 139,00 140,00 Dimensions: contact us

*Depending on availability - Dimensions in mm

Module 0,5



Brass CuZn39Pb3



- Spur gear with JIS grade 8teeth (JISB1702-1:1998)
- Pressure angle 20°
- Material:
Brass CuZn39Pb3 (C6304)

Info

- *Torque (bending strength)

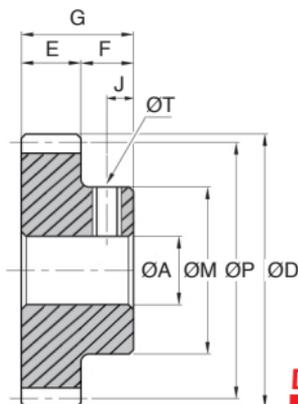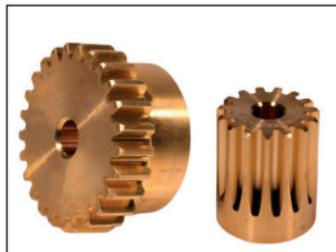

DISCOUNTS

| | | | |
|-------|-------|------|------------|
| Qty | 1+ | 6+ | 10+ |
| Disc. | Price | -12% | On request |

| Part number | Teeth | | ØA | | | Torque* | | Weight (kg) | Price each 1 to 5 | | | | |
|----------------|-------|------|------|---------|---|---------|------|-------------|-------------------|-----|-------|-------|---------|
| | Z | ØP | ØD | ØM (H7) | E | F | (Nm) | | | | | | |
| GB0.5-15-RA03T | 15 | 7,5 | 8,5 | 8,5 | 3 | 3 | 11 | 14 | M3 | 2,5 | 0,058 | 0,005 | 27,45 € |
| GB0.5-16-RA03T | 16 | 8,0 | 9,0 | 9,0 | 3 | 3 | 11 | 14 | M3 | 2,5 | 0,065 | 0,006 | 27,45 € |
| GB0.5-20-RA04 | 20 | 10,0 | 11,0 | 8,5 | 4 | 3 | 7 | 10 | - | - | 0,091 | 0,004 | 27,98 € |
| GB0.5-20-RA03T | 20 | 10,0 | 11,0 | 11,0 | 3 | 3 | 11 | 14 | M3 | 2,5 | 0,091 | 0,010 | 31,86 € |
| GB0.5-22-RA03T | 22 | 11,0 | 12,0 | 9,0 | 3 | 3 | 7 | 10 | M3 | 3,5 | 0,10 | 0,005 | 33,93 € |
| GB0.5-24-RA04T | 24 | 12,0 | 13,0 | 10,0 | 4 | 3 | 7 | 10 | M3 | 3,5 | 0,12 | 0,006 | 35,58 € |
| GB0.5-25-RA04 | 25 | 12,5 | 13,5 | 11,0 | 4 | 3 | 7 | 10 | - | - | 0,12 | 0,008 | 35,58 € |
| GB0.5-30-RA04 | 30 | 15,0 | 16,0 | 13,0 | 4 | 3 | 7 | 10 | - | - | 0,16 | 0,011 | 36,35 € |
| GB0.5-30-RA03T | 30 | 15,0 | 16,0 | 12,0 | 3 | 3 | 7 | 10 | M3 | 3,5 | 0,16 | 0,010 | 39,92 € |
| GB0.5-30-RA04T | 30 | 15,0 | 16,0 | 12,0 | 4 | 3 | 7 | 10 | M3 | 3,5 | 0,16 | 0,010 | 39,92 € |
| GB0.5-30-RA05T | 30 | 15,0 | 16,0 | 12,0 | 5 | 3 | 7 | 10 | M4 | 3,5 | 0,16 | 0,009 | 39,92 € |
| GB0.5-38-RA04T | 38 | 19,0 | 20,0 | 16,0 | 4 | 3 | 7 | 10 | M3 | 3,5 | 0,22 | 0,018 | 41,38 € |
| GB0.5-40-RA04 | 40 | 20,0 | 21,0 | 17,0 | 4 | 3 | 7 | 10 | - | - | 0,23 | 0,020 | 41,49 € |
| GB0.5-50-RA04T | 50 | 25,0 | 26,0 | 22,0 | 4 | 3 | 7 | 10 | M3 | 3,5 | 0,31 | 0,033 | 45,76 € |

Dimensions in mm


304L stainless steel

Module 0.5



- Quality standard 9
- Pressure angle 20°

| Torque and power indication For 50 teeth at 1000 rpm | | | |
|---|--------------|-------|-------|
| | STS 304L | brass | fibre |
| Nm | 0.391 | 0.195 | 0.156 |
| kW | 0.041 | 0.021 | 0.016 |

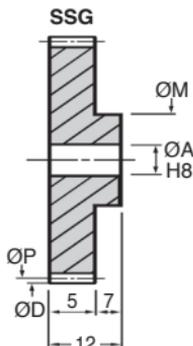

stainless steel

DISCOUNTS

| Qty | 1+ | 6+ | 20+ |
|-------|------|------|------------|
| Disc. | List | -12% | On request |

| Part number | Teeth Z | PCD ØP | External ØD | Boss ØM | Bore ØA | Price each 1 to 5 |
|----------------|------------|-----------|----------------|------------|------------|----------------------|
| SSG0.5-20-304L | 20 | 10 | 11 | 8,5 | 4 | 37,74 € |
| SSG0.5-22-304L | 22 | 11 | 12 | 8,5 | 4 | 38,65 € |
| SSG0.5-24-304L | 24 | 12 | 13 | 10 | 5 | 39,65 € |
| SSG0.5-25-304L | 25 | 12,5 | 13,5 | 10 | 5 | 40,05 € |
| SSG0.5-26-304L | 26 | 13 | 14 | 10 | 5 | 40,58 € |
| SSG0.5-28-304L | 28 | 14 | 15 | 10 | 5 | 41,67 € |
| SSG0.5-30-304L | 30 | 15 | 16 | 10 | 5 | 41,92 € |
| SSG0.5-32-304L | 32 | 16 | 17 | 10 | 5 | 42,90 € |
| SSG0.5-36-304L | 36 | 18 | 19 | 10 | 5 | 44,85 € |
| SSG0.5-40-304L | 40 | 20 | 21 | 10 | 5 | 46,65 € |
| SSG0.5-44-304L | 44 | 22 | 23 | 10 | 5 | 48,58 € |
| SSG0.5-48-304L | 48 | 24 | 25 | 10 | 5 | 50,98 € |
| SSG0.5-50-304L | 50 | 25 | 26 | 12 | 6 | 51,46 € |
| SSG0.5-54-304L | 54 | 27 | 28 | 12 | 6 | 52,84 € |
| SSG0.5-56-304L | 56 | 28 | 29 | 12 | 6 | 53,62 € |
| SSG0.5-60-304L | 60 | 30 | 31 | 12 | 6 | 55,03 € |
| SSG0.5-64-304L | 64 | 32 | 33 | 12 | 6 | 60,31 € |
| SSG0.5-70-304L | 70 | 35 | 36 | 12 | 6 | 61,80 € |
| SSG0.5-80-304L | 80 | 40 | 41 | 12 | 6 | 64,22 € |



Gears available up to this size

SSG0.5-278-304L 278 139 140 Dimensions: contact us

*Depending on availability - Dimensions in mm

Plastic spur gear




Module 0.5

Machined Delrin



- Machined parts
- Quality standard 9
- Pressure angle 20°
- Working temp. -50°C to +80°C

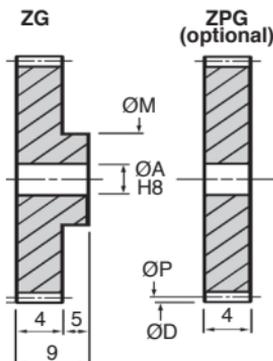

| Torque indication | |
|--------------------------|---------------|
| For 50 teeth at 1000 rpm | |
| | Delrin |
| Nm | 0.1 |

DISCOUNTS

| | | | |
|-------|-----------|----|------------|
| Qty | 1+ | 6+ | 30+ |
| Disc. | List -22% | | On request |

| Part number | Teeth Z | PCD ØP | External ØD | Boss ØM | Bore ØA | Stock ¹ | Weight (kg) | | Price each 1 to 5 | |
|-------------|------------|-----------|----------------|------------|------------|--------------------|-------------|--------|-------------------|------------|
| | | | | | | | ZG | ZPG | ZG | ZPG |
| ZG0.5-20 | 20 | 10,00 | 11,00 | 9 | 3 | ✓ | 0,0007 | 0,0004 | 14,13 € | On request |
| ZG0.5-21 | 21 | 10,50 | 11,50 | 9 | 3 | - | 0,0008 | 0,0004 | 14,36 € | |
| ZG0.5-22 | 22 | 11,00 | 12,00 | 9 | 3 | - | 0,0008 | 0,0005 | 14,42 € | |
| ZG0.5-23 | 23 | 11,50 | 12,50 | 10 | 3 | - | 0,0010 | 0,0005 | 14,78 € | |
| ZG0.5-24 | 24 | 12,00 | 13,00 | 10 | 3 | ✓ | 0,0010 | 0,0005 | 14,89 € | |
| ZG0.5-25 | 25 | 12,50 | 13,50 | 10 | 3 | ✓ | 0,0011 | 0,0006 | 14,98 € | |
| ZG0.5-26 | 26 | 13,00 | 14,00 | 10 | 3 | - | 0,0011 | 0,0006 | 15,27 € | |
| ZG0.5-27 | 27 | 13,50 | 14,50 | 10 | 3 | - | 0,0012 | 0,0007 | 15,34 € | |
| ZG0.5-28 | 28 | 14,00 | 15,00 | 10 | 3 | - | 0,0012 | 0,0008 | 15,66 € | |
| ZG0.5-29 | 29 | 14,50 | 15,50 | 10 | 3 | - | 0,0013 | 0,0008 | 15,66 € | |
| ZG0.5-30 | 30 | 15,00 | 16,00 | 12 | 4 | ✓ | 0,0015 | 0,0008 | 15,73 € | |
| ZG0.5-31 | 31 | 15,50 | 16,50 | 12 | 4 | - | 0,0016 | 0,0009 | 15,87 € | |
| ZG0.5-32 | 32 | 16,00 | 17,00 | 12 | 4 | ✓ | 0,0016 | 0,0010 | 16,17 € | |
| ZG0.5-33 | 33 | 16,50 | 17,50 | 12 | 4 | - | 0,0017 | 0,0010 | 16,23 € | |
| ZG0.5-34 | 34 | 17,00 | 18,00 | 12 | 4 | - | 0,0017 | 0,0011 | 16,27 € | |
| ZG0.5-35 | 35 | 17,50 | 18,50 | 12 | 4 | ✓ | 0,0018 | 0,0012 | 16,64 € | |
| ZG0.5-36 | 36 | 18,00 | 19,00 | 12 | 4 | - | 0,0019 | 0,0012 | 16,80 € | |
| ZG0.5-40 | 40 | 20,00 | 21,00 | 12 | 4 | ✓ | 0,0022 | 0,0016 | 17,51 € | |

¹Depending on availability- Dimensions in mm

DISCOUNTS

| | | | |
|------------|------|------------|-----|
| Qty | 1+ | 6+ | 30+ |
| Disc. List | -22% | On request | |

| Part number | Teeth Z | PCD ØP | External ØD | Boss ØM | Bore ØA | Stock* | Weight (kg) | | Price each 1 to 5 | |
|-------------|------------|-----------|----------------|------------|------------|--------|-------------|--------|-------------------|-----|
| | | | | | | | ZG | ZPG | ZG | ZPG |
| ZG0.5-41 | 41 | 20,50 | 21,50 | 12 | 4 | - | 0,0023 | 0,0016 | 17,65 | € |
| ZG0.5-42 | 42 | 21,00 | 22,00 | 12 | 4 | - | 0,0024 | 0,0017 | 17,88 | € |
| ZG0.5-43 | 43 | 21,50 | 22,50 | 12 | 4 | - | 0,0024 | 0,0018 | 18,05 | € |
| ZG0.5-44 | 44 | 22,00 | 23,00 | 12 | 4 | - | 0,0025 | 0,0019 | 18,38 | € |
| ZG0.5-45 | 45 | 22,50 | 23,50 | 12 | 4 | - | 0,0026 | 0,0020 | 18,42 | € |
| ZG0.5-46 | 46 | 23,00 | 24,00 | 12 | 4 | - | 0,0027 | 0,0021 | 18,54 | € |
| ZG0.5-47 | 47 | 23,50 | 24,50 | 12 | 4 | - | 0,0028 | 0,0022 | 18,76 | € |
| ZG0.5-48 | 48 | 24,00 | 25,00 | 12 | 4 | - | 0,0029 | 0,0023 | 19,25 | € |
| ZG0.5-49 | 49 | 24,50 | 25,50 | 12 | 4 | - | 0,0030 | 0,0024 | 19,25 | € |
| ZG0.5-50 | 50 | 25,00 | 26,00 | 12 | 4 | ✓ | 0,0031 | 0,0025 | 19,38 | € |
| ZG0.5-51 | 51 | 25,50 | 26,50 | 12 | 4 | - | 0,0032 | 0,0026 | 19,49 | € |
| ZG0.5-52 | 52 | 26,00 | 27,00 | 12 | 4 | - | 0,0033 | 0,0027 | 19,55 | € |
| ZG0.5-53 | 53 | 26,50 | 27,50 | 12 | 4 | - | 0,0034 | 0,0028 | 19,67 | € |
| ZG0.5-54 | 54 | 27,00 | 28,00 | 14 | 4 | - | 0,0038 | 0,0029 | 19,88 | € |
| ZG0.5-55 | 55 | 27,50 | 28,50 | 14 | 4 | - | 0,0039 | 0,0030 | 19,97 | € |
| ZG0.5-56 | 56 | 28,00 | 29,00 | 14 | 4 | - | 0,0040 | 0,0031 | 20,17 | € |
| ZG0.5-57 | 57 | 28,50 | 29,50 | 14 | 4 | - | 0,0041 | 0,0032 | 20,28 | € |
| ZG0.5-58 | 58 | 29,00 | 30,00 | 14 | 4 | - | 0,0042 | 0,0033 | 22,57 | € |
| ZG0.5-59 | 59 | 29,50 | 30,50 | 14 | 4 | - | 0,0044 | 0,0035 | 22,64 | € |
| ZG0.5-60 | 60 | 30,00 | 31,00 | 14 | 4 | ✓ | 0,0045 | 0,0036 | 22,77 | € |
| ZG0.5-61 | 61 | 30,50 | 31,50 | 14 | 4 | - | 0,0046 | 0,0037 | 22,91 | € |
| ZG0.5-62 | 62 | 31,00 | 32,00 | 14 | 4 | - | 0,0047 | 0,0038 | 23,01 | € |
| ZG0.5-63 | 63 | 31,50 | 32,50 | 14 | 4 | - | 0,0049 | 0,0039 | 23,17 | € |
| ZG0.5-64 | 64 | 32,00 | 33,00 | 14 | 4 | - | 0,0050 | 0,0041 | 23,49 | € |
| ZG0.5-65 | 65 | 32,50 | 33,50 | 14 | 4 | - | 0,0051 | 0,0042 | 23,64 | € |
| ZG0.5-68 | 68 | 34,00 | 35,00 | 14 | 4 | - | 0,0055 | 0,0046 | 23,68 | € |
| ZG0.5-70 | 70 | 35,00 | 36,00 | 14 | 4 | ✓ | 0,0058 | 0,0049 | 23,91 | € |
| ZG0.5-72 | 72 | 36,00 | 37,00 | 14 | 4 | - | 0,0061 | 0,0052 | 24,17 | € |
| ZG0.5-75 | 75 | 37,50 | 38,50 | 14 | 4 | - | 0,0065 | 0,0056 | 24,44 | € |
| ZG0.5-77 | 77 | 38,50 | 39,50 | 14 | 4 | - | 0,0068 | 0,0059 | 24,81 | € |
| ZG0.5-80 | 80 | 40,00 | 41,00 | 16 | 5 | ✓ | 0,0075 | 0,0064 | 28,25 | € |
| ZG0.5-84 | 84 | 42,00 | 43,00 | 16 | 5 | - | 0,0082 | 0,0070 | 28,50 | € |
| ZG0.5-86 | 86 | 43,00 | 44,00 | 16 | 5 | - | 0,0085 | 0,0074 | 28,99 | € |
| ZG0.5-88 | 88 | 44,00 | 45,00 | 16 | 5 | - | 0,0089 | 0,0077 | 29,15 | € |
| ZG0.5-90 | 90 | 45,00 | 46,00 | 16 | 5 | ✓ | 0,0092 | 0,0081 | 29,39 | € |
| ZG0.5-96 | 96 | 48,00 | 49,00 | 16 | 5 | - | 0,0104 | 0,0092 | 29,69 | € |
| ZG0.5-100 | 100 | 50,00 | 51,00 | 16 | 5 | ✓ | 0,0112 | 0,0100 | 36,00 | € |
| ZG0.5-120 | 120 | 60,00 | 61,00 | 16 | 5 | ✓ | 0,0156 | 0,0144 | 49,27 | € |
| ZG0.5-150 | 150 | 75,00 | 76,00 | 20 | 8 | ✓ | 0,0238 | 0,0226 | 67,98 | € |
| ZG0.5-180 | 180 | 90,00 | 91,00 | 20 | 8 | - | 0,0338 | 0,0326 | 85,43 | € |
| ZG0.5-200 | 200 | 100,00 | 101,00 | 30 | 10 | - | 0,0415 | 0,0403 | 69,38 | € |
| ZG0.5-220 | 220 | 110,00 | 111,00 | 30 | 10 | - | 0,0499 | 0,0488 | 69,38 | € |
| ZG0.5-250 | 250 | 125,00 | 126,00 | 50 | 12 | - | 0,0642 | 0,0630 | 85,43 | € |

On request

↓ **Gears available up to this size**

ZG0.5-278 278 139,00 140,00 Dimensions: contact us

*Depending on availability- Dimensions in mm