

Steel spur gear



Module

Steel 20NCD2



0.6



- Precision class 9
- Pressure angle 20°
- Linear speed 300m/min

Option

- Alternative number of teeth, up to 231

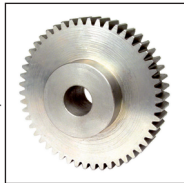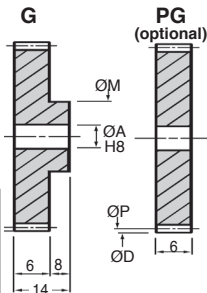

Torque and power indication				
For 50 teeth at 1000 rpm				
	20NCD2 Z10CNF18.09	20NCD2 hardened	brass	fibre
Nm	0.630	2.910	0.315	0.240
kW	0.067	0.306	0.033	0.022



DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-12%	-25%	On request

Part number	Teeth Z	PCD ØP	External ØD	Boss ØM	Bore ØA	Weight (kg) G	Weight (kg) PG	Stock*	Price each	1 to 5 PG
G0.6-10	10	6,60	7,80	7,80	3	0,004	0,001	-	20,65 €	
G0.6-12	12	7,80	9,00	9,00	3	0,005	0,002	✓	20,65 €	
G0.6-14	14	8,40	9,60	9,60	4	0,006	0,002	-	20,65 €	
G0.6-16	16	9,60	10,80	10,80	4	0,008	0,003	✓	21,15 €	
G0.6-18	18	10,80	12,00	12,00	4	0,010	0,004	-	22,05 €	
G0.6-20	20	12,00	13,20	12,00	4	0,011	0,005	✓	23,32 €	
G0.6-22	22	13,20	14,40	12,00	4	0,012	0,006	-	24,14 €	
G0.6-24	24	14,40	15,60	12,00	4	0,013	0,007	-	24,35 €	
G0.6-28	28	16,80	18,00	12,00	4	0,016	0,010	-	25,31 €	
G0.6-29	29	17,40	18,60	12,00	4	0,016	0,010	-	25,62 €	
G0.6-35	35	21,00	22,20	15,00	5	0,025	0,015	-	26,63 €	
G0.6-40	40	24,00	25,20	15,00	5	0,029	0,020	✓	26,93 €	
G0.6-50	50	30,00	31,60	20,00	6	0,049	0,030	-	27,41 €	
G0.6-55	55	33,00	34,20	20,00	6	0,055	0,038	-	27,74 €	
G0.6-60	60	36,00	37,20	20,00	6	0,063	0,045	-	28,22 €	
G0.6-63	63	37,80	39,00	20,00	6	0,068	0,050	-	28,59 €	
G0.6-80	80	48,00	49,20	20,00	6	0,099	0,082	-	30,25 €	
G0.6-84	84	50,40	51,60	30,00	8	0,129	0,089	-	30,98 €	
G0.6-120	120	72,00	73,20	30,00	8	0,225	0,185	-	47,18 €	
G0.6-150	150	90,00	91,20	30,00	8	0,330	0,290	-	62,79 €	
Gears available up to this size										
G0.6-231	231	138,60	139,80	Dimensions: contact us				On request		

On request

*Depending on availability - Dimensions in mm

Our other products



BIM

Indexing plunger mini,
miniature



F7-SF-SM

Multifunction display,
Mounting bracket for
front mounting



PRF_VTM

Hammerhead screw,
Hammerhead screw



MF

Shock Absorber
-universal flange,
Universal fixing



FAD

Threaded swivel feet,
Swivel feet without
anti-slip plate




DEP

Tools Hygienic Usit®
and Hygienic
Design®, Socket for
mounting Hyg...



UTKswc

Utilitrac® 3 wheels
carriage, Series V
precision steel wheel

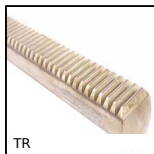

TR

Spur round rack,
Stainless steel -
module 0,25-1,5



KB_OP

Open precision linear
bearing, Precision -



SSHBRA

Stainless steel bevel
gear, 1,5:1 2:1 3:1



STU

Stroke rotary bushing,
Steel



PW_PWG2

Worm - precision
range, Steel

Complementary products



G0

Steel spur gear, Steel
20NCD2



G0

Steel spur gear, Steel
20NCD2