

Steel spur gear



Module

Steel 20NCD2

0.6




- Precision class 9
- Pressure angle 20°
- Linear speed 300m/min

Option

- Alternative number of teeth, up to 231

Torque and power indication				
For 50 teeth at 1000 rpm				
	20NCD2 Z10CNF18.09	20NCD2 hardened	brass	fibre
Nm	0.630	2.910	0.315	0.240
kW	0.067	0.306	0.033	0.022

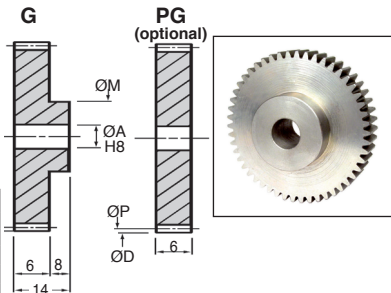

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-12%	-25%	On request

Part number	Teeth Z	PCD ØP	External ØD	Boss ØM	Bore ØA	Weight (kg)		Stock*	Price each	1 to 5 PG
						G	PG			
G0.6-10	10	6,60	7,80	7,80	3	0,004	0,001	-	20,65 €	On request
G0.6-12	12	7,80	9,00	9,00	3	0,005	0,002	✓	20,65 €	
G0.6-14	14	8,40	9,60	9,60	4	0,006	0,002	-	20,65 €	
G0.6-16	16	9,60	10,80	10,80	4	0,008	0,003	✓	21,15 €	
G0.6-18	18	10,80	12,00	12,00	4	0,010	0,004	-	22,05 €	
G0.6-20	20	12,00	13,20	12,00	4	0,011	0,005	✓	23,32 €	
G0.6-22	22	13,20	14,40	12,00	4	0,012	0,006	-	24,14 €	
G0.6-24	24	14,40	15,60	12,00	4	0,013	0,007	-	24,35 €	
G0.6-28	28	16,80	18,00	12,00	4	0,016	0,010	-	25,31 €	
G0.6-29	29	17,40	18,60	12,00	4	0,016	0,010	-	25,62 €	
G0.6-35	35	21,00	22,20	15,00	5	0,025	0,015	-	26,63 €	
G0.6-40	40	24,00	25,20	15,00	5	0,029	0,020	✓	26,93 €	
G0.6-50	50	30,00	31,60	20,00	6	0,049	0,030	-	27,41 €	
G0.6-55	55	33,00	34,20	20,00	6	0,055	0,038	-	27,74 €	
G0.6-60	60	36,00	37,20	20,00	6	0,063	0,045	-	28,22 €	
G0.6-63	63	37,80	39,00	20,00	6	0,068	0,050	-	28,59 €	
G0.6-80	80	48,00	49,20	20,00	6	0,099	0,082	-	30,25 €	
G0.6-84	84	50,40	51,60	30,00	8	0,129	0,089	-	30,98 €	
G0.6-120	120	72,00	73,20	30,00	8	0,225	0,185	-	47,18 €	
G0.6-150	150	90,00	91,20	30,00	8	0,330	0,290	-	62,79 €	
Gears available up to this size										
G0.6-231	231	138,60	139,80	Dimensions: contact us				On request		

*Depending on availability - Dimensions in mm

Our other products



CHTRB

Single and dual output gearboxes, Up to 87,3 Nm



T2,5-BAR

T type tooth bar stock, T2.5



KB_WW

Closed linear precision bearing, Economy range



LVT

Miniature motorised actuator 4A, 4 amperes



CHA1056_U4

Screw-in hinge, Section 40X40



CHTRP

Single and dual output gearboxes, Up to 87,3Nm



TBbutee

Axial thrust bearing, Steel balls



GCB880

Curved track for slat top chain, Ranges 880 and 881



CHN_CHNSS

Straight long link stainless steel chain, Stainless steel




TIFss

Threaded stud - DIN976A, Stainless steel



SH2

 Parallel axis helical gear, Steel 20NCD2



ACLBTS

Closing system for aluminium profile, 90° bracket for spherical end...

Complementary products



G0

Steel spur gear, Steel 20NCD2



G0

Steel spur gear, Steel 20NCD2