

Steel spur gear



Module

Steel 20NCD2



0.6



- Precision class 9
- Pressure angle 20°
- Linear speed 300m/min

Option

- Alternative number of teeth, up to 231

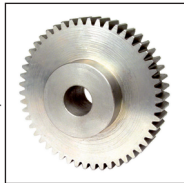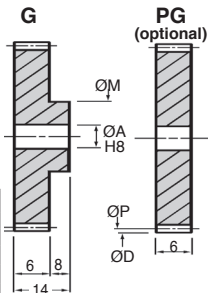

Torque and power indication				
For 50 teeth at 1000 rpm				
	20NCD2 Z10CNF18.09	20NCD2 hardened	brass	fibre
Nm	0.630	2.910	0.315	0.240
kW	0.067	0.306	0.033	0.022



DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-12%	-25%	On request

Part number	Teeth Z	PCD ØP	External ØD	Boss ØM	Bore ØA	Weight (kg)		Stock*	Price each	1 to 5 PG
						G	PG			
G0.6-10	10	6,60	7,80	7,80	3	0,004	0,001	-	20,65 €	On request
G0.6-12	12	7,80	9,00	9,00	3	0,005	0,002	✓	20,65 €	
G0.6-14	14	8,40	9,60	9,60	4	0,006	0,002	-	20,65 €	
G0.6-16	16	9,60	10,80	10,80	4	0,008	0,003	✓	21,15 €	
G0.6-18	18	10,80	12,00	12,00	4	0,010	0,004	-	22,05 €	
G0.6-20	20	12,00	13,20	12,00	4	0,011	0,005	✓	23,32 €	
G0.6-22	22	13,20	14,40	12,00	4	0,012	0,006	-	24,14 €	
G0.6-24	24	14,40	15,60	12,00	4	0,013	0,007	-	24,35 €	
G0.6-28	28	16,80	18,00	12,00	4	0,016	0,010	-	25,31 €	
G0.6-29	29	17,40	18,60	12,00	4	0,016	0,010	-	25,62 €	
G0.6-35	35	21,00	22,20	15,00	5	0,025	0,015	-	26,63 €	
G0.6-40	40	24,00	25,20	15,00	5	0,029	0,020	✓	26,93 €	
G0.6-50	50	30,00	31,60	20,00	6	0,049	0,030	-	27,41 €	
G0.6-55	55	33,00	34,20	20,00	6	0,055	0,038	-	27,74 €	
G0.6-60	60	36,00	37,20	20,00	6	0,063	0,045	-	28,22 €	
G0.6-63	63	37,80	39,00	20,00	6	0,068	0,050	-	28,59 €	
G0.6-80	80	48,00	49,20	20,00	6	0,099	0,082	-	30,25 €	
G0.6-84	84	50,40	51,60	30,00	8	0,129	0,089	-	30,98 €	
G0.6-120	120	72,00	73,20	30,00	8	0,225	0,185	-	47,18 €	
G0.6-150	150	90,00	91,20	30,00	8	0,330	0,290	-	62,79 €	
↓ Gears available up to this size										
G0.6-231	231	138,60	139,80	Dimensions: contact us				On request		

*Depending on availability - Dimensions in mm

Our other products



G0
Steel spur gear, Steel
20NCD2



DB
Steel bevel gear, 2:1



T2,5-BAR
T type tooth bar
stock, T2.5



GLB
Small 6 lobe threaded
handle - female,
Technopolymer -
Stainless steel




DBL821
Idler for slat top
chain, Range 821



PNA
PERIFLEX® elastic
coupling, Complete
coupling



VPSS
Small 6 lobe threaded
handle - male,
Duroplast - Stainless
steel

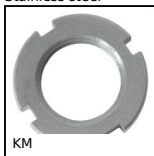

KM
Bearing locknut,
Locknut KM



SDC55
Positioning sleeve for
indexing pin, For pin



GPLbr
Brush, brass



CLQ
12.7mm wide steel
feeler strip on rolls,



F7-P-AM
Multifunction display,
Magnetic band

Complementary products



G0
Steel spur gear, Steel
20NCD2



G0
Steel spur gear, Steel
20NCD2