

Steel spur gear



Module

Steel 20NCD2

0.6




- Precision class 9
- Pressure angle 20°
- Linear speed 300m/min

Option

- Alternative number of teeth, up to 231

Torque and power indication			
For 50 teeth at 1000 rpm			
	20NCD2	20NCD2	
	Z10CNF18.09	hardened	brass
Nm	0.630	2.910	0.315
kW	0.067	0.306	0.033

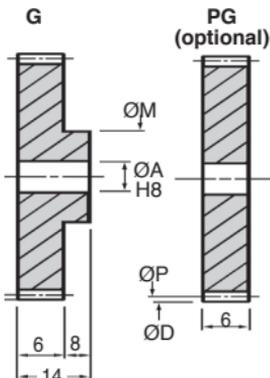

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-12%	-25%	On request

Part number	Teeth Z	PCD ØP	External ØD	Boss ØM	Bore ØA	Weight (kg)		Price each 1 to 5		
						G	PG	G	PG	
G0.6-16	16	9,60	10,80	10,80	4	0,008	0,003	27,70 €		
G0.6-18	18	10,80	12,00	12,00	4	0,010	0,004	28,89 €		
G0.6-20	20	12,00	13,20	12,00	4	0,011	0,005	30,55 €		
G0.6-22	22	13,20	14,40	12,00	4	0,012	0,006	31,62 €		
G0.6-24	24	14,40	15,60	12,00	4	0,013	0,007	31,91 €		
G0.6-28	28	16,80	18,00	12,00	4	0,016	0,010	33,17 €		
G0.6-29	29	17,40	18,60	12,00	4	0,016	0,010	33,56 €		
G0.6-35	35	21,00	22,20	15,00	5	0,025	0,015	34,88 €		
G0.6-40	40	24,00	25,20	15,00	5	0,029	0,020	35,29 €		
G0.6-50	50	30,00	31,60	20,00	6	0,049	0,030	35,90 €		
G0.6-55	55	33,00	34,20	20,00	6	0,055	0,038	36,35 €		
G0.6-60	60	36,00	37,20	20,00	6	0,063	0,045	36,98 €		
G0.6-63	63	37,80	39,00	20,00	6	0,068	0,050	37,46 €		
G0.6-80	80	48,00	49,20	20,00	6	0,099	0,082	39,63 €		
G0.6-84	84	50,40	51,60	30,00	8	0,129	0,089	40,59 €		
G0.6-120	120	72,00	73,20	30,00	8	0,225	0,185	61,82 €		
G0.6-150	150	90,00	91,20	30,00	8	0,330	0,290	82,25 €		
↓ Gears available up to this size										
G0.6-231	231	138,60	139,80	Dimensions: contact us						

On request

*Depending on availability - Dimensions in mm