

Steel spur gear



Module 0.75


Steel 20NCD2



- Precision class 9
- Pressure angle 20°
- Linear speed 300m/min

Option

- Alternative number of teeth, up to 198

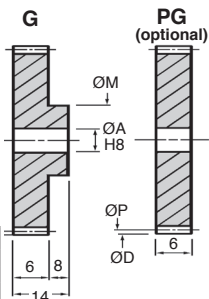

Torque and power indication

For 50 teeth at 1000 rpm

	20NCD2	20NCD2 Z10CNF18.09 hardened	brass	fibre
Nm	0.990	4.570	0.480	0.380
kW	0.104	0.477	0.057	0.037

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-12%	-25%	On request

Part number	Teeth Z	PCD ØP	External ØD	Boss ØM	Bore ØA	Weight (kg)		Price each 1 to 5	
						G	PG	G	PG
G0.75-10	10	8,25	9,75	9,75	4	0,006	0,002	20,65 €	On request
G0.75-11	11	9,00	10,50	10,50	4	0,007	0,002	21,15 €	
G0.75-13	13	9,75	11,25	11,25	5	0,008	0,003	21,59 €	
G0.75-14	14	10,50	12,00	12,00	5	0,009	0,003	22,07 €	
G0.75-15	15	11,25	12,75	12,00	5	0,009	0,004	22,64 €	
G0.75-17	17	12,75	14,25	12,00	5	0,011	0,005	23,87 €	
G0.75-18	18	13,50	15,00	12,00	5	0,011	0,006	24,35 €	
G0.75-20	20	15,00	16,50	12,00	5	0,013	0,007	24,80 €	
G0.75-22	22	16,50	18,00	12,00	5	0,015	0,009	25,31 €	
G0.75-24	24	18,00	19,50	12,00	5	0,017	0,011	25,82 €	
G0.75-25	25	18,75	20,25	12,00	5	0,017	0,012	26,09 €	
G0.75-28	28	21,00	22,50	12,00	5	0,021	0,015	26,63 €	
G0.75-30	30	22,50	24,00	12,00	5	0,023	0,017	26,85 €	
G0.75-40	40	30,00	31,50	16,00	6	0,042	0,031	27,41 €	
G0.75-45	45	33,75	35,25	16,00	6	0,050	0,040	27,86 €	
G0.75-60	60	45,00	46,50	16,00	6	0,082	0,072	29,87 €	
G0.75-70	70	52,50	54,00	16,00	8	0,106	0,097	31,33 €	
G0.75-72	72	54,00	55,50	16,00	8	0,112	0,103	32,22 €	
G0.75-100	100	75,00	76,50	16,00	8	0,210	0,201	53,03 €	
G0.75-150	150	112,50	114,00	20,00	10	0,470	0,454	86,76 €	
G0.75-180	180	135,00	136,50	30,00	12	0,671	0,655	118,15 €	

Gears available up to this size

G0.75-184	184	138,00	139,50	Dimensions: contact us		On request
-----------	-----	--------	--------	------------------------	--	------------

 
Dimensions in mm

Our other products



STRIP

Sealing brush strip,
3m length



VAB

Ballscrew, supplied by
the metre, Rolled
ballscrew, per metre



DOM120

Connecting kits, XZ
linking kit



SVT30

Screwjack with
travelling screw, with
translating screw



BLHT40

Right angled gearbox,
from 4 to 10.30 Nm




HCSS

Set screw with
hexagonal socket,
Cup point



PGM52-M4

 Pull handle, Brass



M0

Worm and wheel set,
Machined plastic
(delrin)



AT10-50ECO

AT type timing pulley,
Economy range -



LVT

Miniature motorised
actuator 4A, 4 ampers



T39_T49

 
Extension spring in
metre length stainless



VTLF


3 lobed handle,
Polyamide - Brass

Complementary products



G0

 Steel spur gear, Steel
20NCD2



G1

Steel spur gear, Steel
20NCD2