

Steel spur gear



Module 0.75



Steel 20NCD2



- Precision class 9
- Pressure angle 20°
- Linear speed 300m/min

Option

- Alternative number of teeth, up to 198

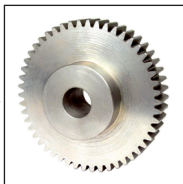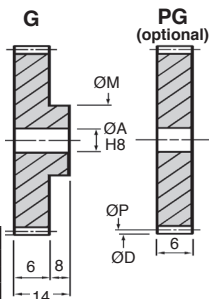

Torque and power indication

For 50 teeth at 1000 rpm

	20NCD2	20NCD2 Z10CNF18.09	hardened	brass	fibre
Nm	0.990	4.570	0.480	0.380	
kW	0.104	0.477	0.057	0.037	

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-12%	-25%	On request

Part number	Teeth Z	PCD ØP	External ØD	Boss ØM	Bore ØA	Weight (kg)		Price each 1 to 5	
						G	PG	G	PG
G0.75-10	10	8,25	9,75	9,75	4	0,006	0,002	20,65 €	On request
G0.75-11	11	9,00	10,50	10,50	4	0,007	0,002	21,15 €	
G0.75-13	13	9,75	11,25	11,25	5	0,008	0,003	21,59 €	
G0.75-14	14	10,50	12,00	12,00	5	0,009	0,003	22,07 €	
G0.75-15	15	11,25	12,75	12,00	5	0,009	0,004	22,64 €	
G0.75-17	17	12,75	14,25	12,00	5	0,011	0,005	23,87 €	
G0.75-18	18	13,50	15,00	12,00	5	0,011	0,006	24,35 €	
G0.75-20	20	15,00	16,50	12,00	5	0,013	0,007	24,80 €	
G0.75-22	22	16,50	18,00	12,00	5	0,015	0,009	25,31 €	
G0.75-24	24	18,00	19,50	12,00	5	0,017	0,011	25,82 €	
G0.75-25	25	18,75	20,25	12,00	5	0,017	0,012	26,09 €	
G0.75-28	28	21,00	22,50	12,00	5	0,021	0,015	26,63 €	
G0.75-30	30	22,50	24,00	12,00	5	0,023	0,017	26,85 €	
G0.75-40	40	30,00	31,50	16,00	6	0,042	0,031	27,41 €	
G0.75-45	45	33,75	35,25	16,00	6	0,050	0,040	27,86 €	
G0.75-60	60	45,00	46,50	16,00	6	0,082	0,072	29,87 €	
G0.75-70	70	52,50	54,00	16,00	8	0,106	0,097	31,33 €	
G0.75-72	72	54,00	55,50	16,00	8	0,112	0,103	32,22 €	
G0.75-100	100	75,00	76,50	16,00	8	0,210	0,201	53,03 €	
G0.75-150	150	112,50	114,00	20,00	10	0,470	0,454	86,76 €	
G0.75-180	180	135,00	136,50	30,00	12	0,671	0,655	118,15 €	

Gears available up to this size

G0.75-184	184	138,00	139,50	Dimensions: contact us		On request
-----------	-----	--------	--------	------------------------	--	------------

Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15€/min + prix appel

Our other products



CHMR63
Worm and wheel gear reducer, up to 196 Nm



SSDB
Stainless steel bevel gear, 2:1



BABam
Self-locking ball pin lifting ring for threaded hole, Self-locking



MRASSeco
Low cost stainless steel quick link, Stainless steel



CF
Cam follower, Standard - steel




SBF
Sealed flange bearing unit for Food Industry, cover



RBNpl
Swivel castor with plate, Steel - rubber



 WS10
Drylin® W rail, Rail



MO
Worm and wheel set, Machined plastic (delrin)



VPSS
Small 6 lobe threaded handle - male, Duroplast - Stainless



HLA19
Right angle spiro bevel gearbox, Up to 43Nm

 


CHT
Asynchronous AC motor 0.12 to 0.22kW, 0.12 to 0.22kW

Complementary products



G0
Steel spur gear, Steel 20NCD2



G1
Steel spur gear, Steel 20NCD2