

Steel spur gear



Module


Steel 20NCD2

0.8



- Precision class 9
- Pressure angle 20°
- Linear speed 300m/min

Torque and power indication				
For 50 teeth at 1000 rpm				
	20NCD2	20NCD2		
	Z10CNF18.09	hardened	brass	fibre
Nm	1	5	0.54	0.450
kW	0.104	0.522	0.06	0.045

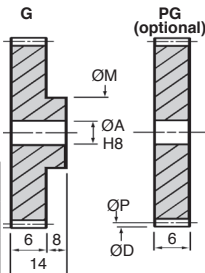

✓ IN STOCK*
Otherwise contact us

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-12%	-25%	On request

Part number	Teeth Z	PCD ØP	External ØD	Boss ØM	Bore ØA	Weight (kg)		Stock*	Price each.	
						G	PG		G	1 to 5 PG
G0.8-9	9	8,00	9,60	9,60	5	0,006	0,002	-	22,05 €	
G0.8-10	10	8,80	10,40	10,40	5	0,007	0,003	✓	22,05 €	
G0.8-11	11	9,60	11,20	11,20	5	0,009	0,004	-	22,05 €	
G0.8-12	12	9,60	11,20	11,20	5	0,009	0,004	✓	22,05 €	
G0.8-13	13	10,40	12,00	12,00	5	0,011	0,005	-	22,64 €	
G0.8-14	14	11,20	12,80	12,00	5	0,012	0,006	-	23,10 €	
G0.8-15	15	12,00	13,60	12,00	5	0,013	0,007	✓	23,66 €	
G0.8-16	16	12,80	14,40	12,00	5	0,014	0,008	✓	24,25 €	
G0.8-17	17	13,60	15,20	12,00	5	0,015	0,010	-	25,02 €	
G0.8-18	18	14,40	16,00	12,00	5	0,017	0,011	✓	25,51 €	
G0.8-19	19	15,20	16,80	12,00	5	0,018	0,012	-	25,97 €	
G0.8-20	20	16,00	17,60	12,00	5	0,020	0,014	✓	26,05 €	
G0.8-21	21	16,80	18,40	12,00	5	0,021	0,015	-	26,33 €	
G0.8-22	22	17,60	19,20	12,00	5	0,023	0,017	✓	26,63 €	
G0.8-23	23	18,40	20,00	12,00	5	0,025	0,019	-	26,91 €	
G0.8-24	24	19,20	20,80	12,00	5	0,026	0,021	✓	27,10 €	
G0.8-25	25	20,00	21,60	12,00	5	0,028	0,023	✓	27,41 €	
G0.8-26	26	20,80	22,40	12,00	5	0,030	0,024	-	27,71 €	
G0.8-27	27	21,60	23,20	12,00	5	0,032	0,027	-	27,94 €	
G0.8-28	28	22,40	24,00	12,00	5	0,034	0,029	-	28,07 €	
G0.8-29	29	23,20	24,80	12,00	5	0,037	0,031	-	28,29 €	
G0.8-30	30	24,00	25,60	16,00	6	0,043	0,032	✓	28,52 €	
G0.8-31	31	24,80	26,40	16,00	6	0,045	0,035	-	28,54 €	
G0.8-32	32	25,60	27,20	16,00	6	0,048	0,037	✓	28,59 €	

On request

*Depending on availability - Dimensions in mm

Part number	Teeth Z	PCD ØP	External ØD	Boss ØM	Bore ØA	Weight (kg)		Stock*	Price each 1 to 5	
						G	PG		G	PG
G0.8-33	33	26,40	28,00	16,00	6	0,050	0,040	-	28,71 €	
G0.8-34	34	27,20	28,80	16,00	6	0,053	0,042	-	28,73 €	
G0.8-35	35	28,00	29,60	16,00	6	0,056	0,045	-	28,77 €	
G0.8-36	36	28,80	30,40	16,00	6	0,058	0,048	✓	28,85 €	
G0.8-37	37	29,60	31,20	16,00	6	0,061	0,050	-	28,92 €	
G0.8-38	38	30,40	32,00	16,00	6	0,064	0,053	✓	29,01 €	
G0.8-39	39	31,20	32,80	16,00	6	0,067	0,056	-	29,01 €	
G0.8-40	40	32,00	33,60	16,00	6	0,070	0,059	✓	29,22 €	
G0.8-41	41	32,80	34,40	16,00	6	0,073	0,062	-	29,25 €	
G0.8-42	42	33,60	35,20	16,00	6	0,076	0,066	-	29,32 €	
G0.8-43	43	34,40	36,00	16,00	6	0,080	0,069	-	29,36 €	
G0.8-44	44	35,20	36,80	16,00	6	0,083	0,072	✓	29,42 €	
G0.8-45	45	36,00	37,60	16,00	6	0,086	0,076	-	29,50 €	
G0.8-46	46	36,80	38,40	16,00	6	0,090	0,079	-	29,63 €	
G0.8-47	47	37,60	39,20	16,00	6	0,093	0,083	-	29,71 €	
G0.8-48	48	38,40	40,00	16,00	6	0,097	0,086	-	29,81 €	
G0.8-49	49	39,20	40,80	16,00	6	0,101	0,090	-	29,87 €	
G0.8-50	50	40,00	41,60	16,00	6	0,105	0,094	✓	29,92 €	
G0.8-51	51	40,80	42,40	16,00	6	0,108	0,098	-	30,14 €	
G0.8-52	52	41,60	43,20	16,00	6	0,112	0,102	-	27,99 €	
G0.8-53	53	42,40	44,00	16,00	6	0,116	0,106	✓	30,37 €	
G0.8-54	54	43,20	44,80	16,00	6	0,121	0,110	-	30,51 €	
G0.8-55	55	44,00	45,60	16,00	6	0,125	0,114	-	30,62 €	
G0.8-56	56	44,80	46,40	16,00	6	0,129	0,118	-	30,76 €	
G0.8-57	57	45,60	47,20	16,00	6	0,133	0,123	-	30,91 €	
G0.8-58	58	46,40	48,00	16,00	6	0,138	0,127	-	30,98 €	
G0.8-59	59	47,20	48,80	16,00	6	0,142	0,132	-	31,17 €	
G0.8-60	60	48,00	49,60	16,00	8	0,144	0,135	✓	31,33 €	
G0.8-61	61	48,80	50,40	16,00	8	0,149	0,139	-	31,43 €	
G0.8-62	62	49,60	51,20	16,00	8	0,153	0,144	-	31,59 €	
G0.8-63	63	50,40	52,00	16,00	8	0,158	0,149	✓	31,65 €	
G0.8-64	64	51,20	52,80	16,00	8	0,163	0,154	✓	31,82 €	
G0.8-66	66	52,80	54,40	16,00	8	0,173	0,164	-	31,95 €	
G0.8-68	68	54,40	56,00	16,00	8	0,183	0,174	-	32,10 €	
G0.8-70	70	56,00	57,60	16,00	8	0,194	0,185	-	32,34 €	
G0.8-75	75	60,00	61,60	16,00	8	0,222	0,213	-	32,73 €	
G0.8-76	76	60,80	62,40	16,00	8	0,228	0,218	-	33,57 €	
G0.8-80	80	64,00	65,60	16,00	8	0,252	0,242	-	34,47 €	
G0.8-86	86	68,80	70,40	16,00	8	0,290	0,281	-	35,05 €	
G0.8-88	88	70,40	72,00	16,00	8	0,303	0,294	-	35,55 €	
G0.8-90	90	72,00	73,60	20,00	8	0,324	0,308	✓	36,32 €	
G0.8-96	96	76,80	78,40	20,00	8	0,367	0,351	-	36,99 €	
G0.8-100	100	80,00	81,60	20,00	8	0,397	0,381	✓	40,49 €	
G0.8-112	112	89,60	91,20	20,00	8	0,495	0,479	-	46,94 €	
G0.8-120	120	96,00	97,60	20,00	8	0,566	0,550	-	53,46 €	
G0.8-127	127	101,60	103,20	25,00	10	0,633	0,617	-	64,21 €	
G0.8-128	128	102,40	104,00	25,00	10	0,653	0,626	-	66,24 €	
G0.8-140	140	112,00	113,60	25,00	10	0,777	0,750	-	69,94 €	
G0.8-150	150	120,00	121,60	25,00	12	0,889	0,862	-	80,93 €	

On request

↓ **Gears available up to this size** ↓

G0.8-173 173 138,40 140,00 Dimensions : contact us on request

*Depending on availability - Dimensions in mm

Our other products



DGS1

Female rod ends,
Steel / steel -
Economy range



CHB

Feet, For CHB gearbox



CHM40

Worm and wheel gear
reducer, up to 57 Nm



M0

Worm and wheel set,
Machined plastic
(delrin)



TSRTC

Stem support for
caster, For swivel
caster with central
hole



G3

Steel spur gear, Steel
20NCD2



PTAF80-PAMF80

Articulated fixable
foot with pressed
base Ø80, Ø 80



CHAsb28

Roll of hinge without
pin, Plastic hinge



VTLM

3 lobed handle,
Polyamide - Steel



T5-10ECO

T type timing pulley,
Economy range - T5



P55

Worm and wheel gear
reducer, up to 57 Nm



DIA

Ring operated locking
bolt, with ring

Complementary products




YG0

HEAVY DUTY spur
gear, Steel 35NCD6




ZG0

 Plastic spur gear,
Machined plastic
(delrin)



R_RR

 Narrow spur rack,
Steel



TR

Spur round rack,
Stainless steel -
module 0,25-1,5