

Steel spur gear



Module


Steel 20NCD2

0.8



- Precision class 9
- Pressure angle 20°
- Linear speed 300m/min

Torque and power indication				
For 50 teeth at 1000 rpm				
	20NCD2	20NCD2		
	Z10CNF18.09	hardened	brass	fibre
Nm	1	5	0.54	0.450
kW	0.104	0.522	0.06	0.045

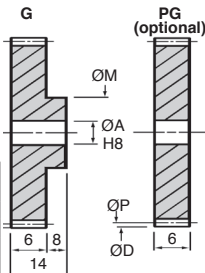

IN STOCK*
Otherwise contact us

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-12%	-25%	On request

Part number	Teeth Z	PCD ØP	External ØD	Boss ØM	Bore ØA	Weight (kg)		Stock*	Price each.	
						G	PG		G	1 to 5 PG
G0.8-9	9	8,00	9,60	9,60	5	0,006	0,002	-	22,05 €	
G0.8-10	10	8,80	10,40	10,40	5	0,007	0,003	✓	22,05 €	
G0.8-11	11	9,60	11,20	11,20	5	0,009	0,004	-	22,05 €	
G0.8-12	12	9,60	11,20	11,20	5	0,009	0,004	✓	22,05 €	
G0.8-13	13	10,40	12,00	12,00	5	0,011	0,005	-	22,64 €	
G0.8-14	14	11,20	12,80	12,00	5	0,012	0,006	-	23,10 €	
G0.8-15	15	12,00	13,60	12,00	5	0,013	0,007	✓	23,66 €	
G0.8-16	16	12,80	14,40	12,00	5	0,014	0,008	✓	24,25 €	
G0.8-17	17	13,60	15,20	12,00	5	0,015	0,010	-	25,02 €	
G0.8-18	18	14,40	16,00	12,00	5	0,017	0,011	✓	25,51 €	
G0.8-19	19	15,20	16,80	12,00	5	0,018	0,012	-	25,97 €	
G0.8-20	20	16,00	17,60	12,00	5	0,020	0,014	✓	26,05 €	
G0.8-21	21	16,80	18,40	12,00	5	0,021	0,015	-	26,33 €	
G0.8-22	22	17,60	19,20	12,00	5	0,023	0,017	✓	26,63 €	
G0.8-23	23	18,40	20,00	12,00	5	0,025	0,019	-	26,91 €	
G0.8-24	24	19,20	20,80	12,00	5	0,026	0,021	✓	27,10 €	
G0.8-25	25	20,00	21,60	12,00	5	0,028	0,023	✓	27,41 €	
G0.8-26	26	20,80	22,40	12,00	5	0,030	0,024	-	27,71 €	
G0.8-27	27	21,60	23,20	12,00	5	0,032	0,027	-	27,94 €	
G0.8-28	28	22,40	24,00	12,00	5	0,034	0,029	-	28,07 €	
G0.8-29	29	23,20	24,80	12,00	5	0,037	0,031	-	28,29 €	
G0.8-30	30	24,00	25,60	16,00	6	0,043	0,032	✓	28,52 €	
G0.8-31	31	24,80	26,40	16,00	6	0,045	0,035	-	28,54 €	
G0.8-32	32	25,60	27,20	16,00	6	0,048	0,037	✓	28,59 €	

On request

*Depending on availability - Dimensions in mm

Part number	Teeth Z	PCD ØP	External ØD	Boss ØM	Bore ØA	Weight (kg)		Stock*	Price each 1 to 5	
						G	PG		G	PG
G0.8-33	33	26,40	28,00	16,00	6	0,050	0,040	-	28,71 €	
G0.8-34	34	27,20	28,80	16,00	6	0,053	0,042	-	28,73 €	
G0.8-35	35	28,00	29,60	16,00	6	0,056	0,045	-	28,77 €	
G0.8-36	36	28,80	30,40	16,00	6	0,058	0,048	✓	28,85 €	
G0.8-37	37	29,60	31,20	16,00	6	0,061	0,050	-	28,92 €	
G0.8-38	38	30,40	32,00	16,00	6	0,064	0,053	✓	29,01 €	
G0.8-39	39	31,20	32,80	16,00	6	0,067	0,056	-	29,01 €	
G0.8-40	40	32,00	33,60	16,00	6	0,070	0,059	✓	29,22 €	
G0.8-41	41	32,80	34,40	16,00	6	0,073	0,062	-	29,25 €	
G0.8-42	42	33,60	35,20	16,00	6	0,076	0,066	-	29,32 €	
G0.8-43	43	34,40	36,00	16,00	6	0,080	0,069	-	29,36 €	
G0.8-44	44	35,20	36,80	16,00	6	0,083	0,072	✓	29,42 €	
G0.8-45	45	36,00	37,60	16,00	6	0,086	0,076	-	29,50 €	
G0.8-46	46	36,80	38,40	16,00	6	0,090	0,079	-	29,63 €	
G0.8-47	47	37,60	39,20	16,00	6	0,093	0,083	-	29,71 €	
G0.8-48	48	38,40	40,00	16,00	6	0,097	0,086	-	29,81 €	
G0.8-49	49	39,20	40,80	16,00	6	0,101	0,090	-	29,87 €	
G0.8-50	50	40,00	41,60	16,00	6	0,105	0,094	✓	29,92 €	
G0.8-51	51	40,80	42,40	16,00	6	0,108	0,098	-	30,14 €	
G0.8-52	52	41,60	43,20	16,00	6	0,112	0,102	-	27,99 €	
G0.8-53	53	42,40	44,00	16,00	6	0,116	0,106	✓	30,37 €	
G0.8-54	54	43,20	44,80	16,00	6	0,121	0,110	-	30,51 €	
G0.8-55	55	44,00	45,60	16,00	6	0,125	0,114	-	30,62 €	
G0.8-56	56	44,80	46,40	16,00	6	0,129	0,118	-	30,76 €	
G0.8-57	57	45,60	47,20	16,00	6	0,133	0,123	-	30,91 €	
G0.8-58	58	46,40	48,00	16,00	6	0,138	0,127	-	30,98 €	
G0.8-59	59	47,20	48,80	16,00	6	0,142	0,132	-	31,17 €	
G0.8-60	60	48,00	49,60	16,00	8	0,144	0,135	✓	31,33 €	
G0.8-61	61	48,80	50,40	16,00	8	0,149	0,139	-	31,43 €	
G0.8-62	62	49,60	51,20	16,00	8	0,153	0,144	-	31,59 €	
G0.8-63	63	50,40	52,00	16,00	8	0,158	0,149	✓	31,65 €	
G0.8-64	64	51,20	52,80	16,00	8	0,163	0,154	✓	31,82 €	
G0.8-66	66	52,80	54,40	16,00	8	0,173	0,164	-	31,95 €	
G0.8-68	68	54,40	56,00	16,00	8	0,183	0,174	-	32,10 €	
G0.8-70	70	56,00	57,60	16,00	8	0,194	0,185	-	32,34 €	
G0.8-75	75	60,00	61,60	16,00	8	0,222	0,213	-	32,73 €	
G0.8-76	76	60,80	62,40	16,00	8	0,228	0,218	-	33,57 €	
G0.8-80	80	64,00	65,60	16,00	8	0,252	0,242	-	34,47 €	
G0.8-86	86	68,80	70,40	16,00	8	0,290	0,281	-	35,05 €	
G0.8-88	88	70,40	72,00	16,00	8	0,303	0,294	-	35,55 €	
G0.8-90	90	72,00	73,60	20,00	8	0,324	0,308	✓	36,32 €	
G0.8-96	96	76,80	78,40	20,00	8	0,367	0,351	-	36,99 €	
G0.8-100	100	80,00	81,60	20,00	8	0,397	0,381	✓	40,49 €	
G0.8-112	112	89,60	91,20	20,00	8	0,495	0,479	-	46,94 €	
G0.8-120	120	96,00	97,60	20,00	8	0,566	0,550	-	53,46 €	
G0.8-127	127	101,60	103,20	25,00	10	0,633	0,617	-	64,21 €	
G0.8-128	128	102,40	104,00	25,00	10	0,653	0,626	-	66,24 €	
G0.8-140	140	112,00	113,60	25,00	10	0,777	0,750	-	69,94 €	
G0.8-150	150	120,00	121,60	25,00	12	0,889	0,862	-	80,93 €	

On request

↓ **Gears available up to this size** ↓

G0.8-173	173	138,40	140,00	Dimensions : contact us	on request
----------	-----	--------	--------	-------------------------	------------

*Depending on availability - Dimensions in mm

Our other products



PGNT

Thermoplastic T handle, With threaded spindle



MSP38

Masterplate® glueable insert Ø38, Cylindrical Ø38 with tapped ins...



CHT

Asynchronous AC Motor, 0.55 to 1.1kW



M1

Worm and wheel set, Non hardened steel



PRF4590_E

Bracket for aluminium profile, PRF4590



SCA

Flat cable clamp, Steel



RTL450

Self-centering locking assembly, High torque



ADL_M

Male eye bolt conforms to DIN580, Stainless steel




DOG319

Motor-gearbox 12V and 24V DC, from 4 to



BOX-CS

 Hose clamp, Box set of steel hose clamps



BEAB

Knob star grip antibacterial, Star,



AC

Strike for toggle latch, 12,13,18 and 20mm

Complementary products



YG0

HEAVY DUTY spur gear, Steel 35NCD6




ZG0

Plastic spur gear, Machined plastic (delrin)



R_RR

 Narrow spur rack, Steel



TR

Spur round rack, Stainless steel - module 0,25-1,5