

Steel spur gear





Module 1.25



- Precision class 9
- Pressure angle 20°
- Linear speed 300m/min

Steel 20NCD2

Torque and power indication				
For 50 teeth at 1000 rpm				
	20NCD2 Z10CNF18.09	20NCD2 hardened	brass	fibre
Nm	3.80	18	1.90	1.52
kW	0.40	1.89	0.19	0.16

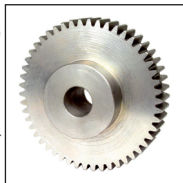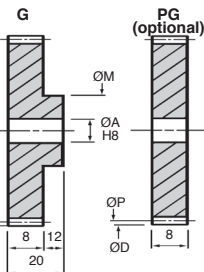

IN STOCK*
Otherwise contact us

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-12%	-25%	On request

Part number	Teeth Z	PCD OP	External OD	Boss OM	Bore OA	Weight (kg)		Stock*	Price each 1 to 5	
						G	PG		G	PG
G1.25-9	9	12,50	15,00	15,00	6	0,019	0,006	-	83,05	€
G1.25-10	10	13,75	16,25	16,25	6	0,024	0,007	✓	25,44	€
G1.25-11	11	15,00	17,50	17,50	6	0,029	0,009	-	25,44	€
G1.25-12	12	15,00	17,50	17,50	6	0,029	0,009	✓	25,44	€
G1.25-13	13	16,25	18,75	18,25	6	0,032	0,011	-	26,63	€
G1.25-14	14	17,50	20,00	20,00	6	0,039	0,013	✓	27,10	€
G1.25-15	15	18,75	21,25	12,00	6	0,023	0,015	-	27,56	€
G1.25-16	16	20,00	22,50	12,00	8	0,022	0,016	✓	28,52	€
G1.25-17	17	21,25	23,75	12,00	8	0,024	0,019	✓	29,25	€
G1.25-18	18	22,50	25,00	15,00	8	0,033	0,021	-	29,96	€
G1.25-19	19	23,75	26,25	15,00	8	0,036	0,024	-	31,17	€
G1.25-20	20	25,00	27,50	15,00	8	0,039	0,027	✓	31,59	€
G1.25-21	21	26,25	28,75	15,00	8	0,042	0,030	-	32,05	€
G1.25-22	22	27,50	30,00	15,00	8	0,045	0,033	✓	32,34	€
G1.25-23	23	28,75	31,25	15,00	8	0,048	0,037	-	32,73	€
G1.25-24	24	30,00	32,50	15,00	8	0,052	0,040	-	33,30	€
G1.25-25	25	31,25	33,75	15,00	8	0,055	0,044	-	34,02	€
G1.25-26	26	32,50	35,00	15,00	8	0,059	0,048	-	34,42	€
G1.25-27	27	33,75	36,25	15,00	8	0,063	0,052	-	35,19	€
G1.25-28	28	35,00	37,50	15,00	8	0,067	0,056	-	36,71	€
G1.25-29	29	36,25	38,75	15,00	8	0,072	0,060	-	37,68	€
G1.25-30	30	37,50	40,00	20,00	8	0,089	0,065	-	38,93	€
G1.25-31	31	38,75	41,25	20,00	8	0,093	0,069	-	39,73	€
G1.25-32	32	40,00	42,50	20,00	8	0,098	0,074	✓	40,53	€
G1.25-33	33	41,25	43,75	20,00	8	0,103	0,079	-	41,30	€

On request

*Depending on availability - Dimensions in mm

Part number	Teeth Z	PCD ØP	External ØD	Boss ØM	Bore ØA	Weight G	PG	Stock*	Price each 1 to 5 G
G1.25-34	34	42,50	45,00	20,00	8	0,108	0,084	✓	41,84 €
G1.25-35	35	43,75	46,25	20,00	8	0,113	0,089	-	42,77 €
G1.25-36	36	45,00	47,50	20,00	8	0,119	0,094	✓	43,31 €
G1.25-37	37	46,25	48,75	20,00	8	0,124	0,100	-	43,73 €
G1.25-38	38	47,50	50,00	20,00	8	0,130	0,105	-	44,21 €
G1.25-39	39	48,75	51,25	20,00	8	0,135	0,111	-	44,80 €
G1.25-40	40	50,00	52,50	30,00	10	0,173	0,115	✓	45,09 €
G1.25-41	41	51,25	53,75	30,00	10	0,179	0,121	✓	45,29 €
G1.25-42	42	52,50	55,00	30,00	10	0,185	0,128	-	45,49 €
G1.25-43	43	53,75	56,25	30,00	10	0,192	0,134	-	45,79 €
G1.25-44	44	55,00	57,50	30,00	10	0,198	0,141	-	45,96 €
G1.25-45	45	56,25	58,75	30,00	10	0,205	0,147	✓	46,17 €
G1.25-46	46	57,50	60,00	30,00	10	0,212	0,154	-	46,31 €
G1.25-47	47	58,75	61,25	30,00	10	0,219	0,161	-	46,61 €
G1.25-48	48	60,00	62,50	30,00	10	0,226	0,168	-	46,77 €
G1.25-49	49	61,25	63,75	30,00	10	0,233	0,176	-	47,78 €
G1.25-50	50	62,50	65,00	30,00	10	0,241	0,183	✓	48,17 €
G1.25-51	51	63,75	66,25	30,00	10	0,248	0,191	-	48,66 €
G1.25-52	52	65,00	67,50	30,00	10	0,256	0,198	-	49,13 €
G1.25-53	53	66,25	68,75	30,00	10	0,264	0,206	-	49,59 €
G1.25-54	54	67,50	70,00	30,00	10	0,272	0,214	-	49,90 €
G1.25-55	55	68,75	71,25	30,00	10	0,280	0,222	-	50,25 €
G1.25-56	56	70,00	72,50	30,00	10	0,288	0,231	-	52,46 €
G1.25-57	57	71,25	73,75	30,00	10	0,297	0,239	-	54,92 €
G1.25-58	58	72,50	75,00	30,00	10	0,306	0,248	-	55,64 €
G1.25-59	59	73,75	76,25	30,00	10	0,314	0,257	-	56,87 €
G1.25-60	60	75,00	77,50	30,00	10	0,323	0,266	-	58,13 €
G1.25-61	61	76,25	78,75	30,00	10	0,332	0,275	-	58,65 €
G1.25-62	62	77,50	80,00	30,00	10	0,342	0,284	-	59,51 €
G1.25-63	63	78,75	81,25	30,00	10	0,351	0,293	-	60,10 €
G1.25-64	64	80,00	82,50	30,00	10	0,361	0,303	-	60,77 €
G1.25-65	65	81,25	83,75	30,00	10	0,370	0,313	-	61,60 €
G1.25-66	66	82,50	85,00	30,00	10	0,380	0,322	-	62,47 €
G1.25-68	68	85,00	87,50	30,00	10	0,400	0,343	-	63,92 €
G1.25-70	70	87,50	90,00	30,00	10	0,421	0,363	✓	65,08 €
G1.25-72	72	90,00	92,50	30,00	10	0,442	0,385	-	65,42 €
G1.25-73	73	91,25	93,75	30,00	10	0,453	0,396	-	65,72 €
G1.25-74	74	92,50	95,00	30,00	10	0,464	0,407	-	66,10 €
G1.25-76	76	95,00	97,50	30,00	10	0,487	0,429	-	67,27 €
G1.25-78	78	97,50	100,00	30,00	10	0,510	0,452	-	69,60 €
G1.25-80	80	100,00	102,50	30,00	10	0,534	0,476	-	74,21 €
G1.25-84	84	105,00	107,50	30,00	10	0,583	0,525	-	74,87 €
G1.25-88	88	110,00	112,50	30,00	10	0,635	0,577	-	82,30 €
G1.25-90	90	112,50	115,00	30,00	10	0,661	0,604	-	83,05 €
G1.25-96	96	120,00	122,50	30,00	12	0,745	0,688	-	95,57 €
G1.25-100	100	125,00	127,50	30,00	12	0,804	0,746	-	97,08 €
G1.25-112	112	140,00	142,50	30,00	12	0,995	0,938	-	107,42 €
G1.25-120	120	150,00	152,50	40,00	15	1,135	1,077	-	114,92 €
G1.25-130	130	162,50	165,00	40,00	15	1,323	1,265	-	128,08 €
G1.25-140	140	175,00	177,50	40,00	15	1,525	1,468	-	138,40 €

On request

↓ **Gears available up to this size** ↓

G1.25-142 142 177,50 180,00 **Dimensions: contact us** On request

*Depending on availability - Dimensions in mm

Our other products



PRF_BR
Clamp for aluminium profile, Clamp for profile



CHB
Reaction arm, CHB gear reducers reaction arm



PITAss
Locking bolt, with T handle



RDE-N
Sealing washer Hygienic Usit®, Stainless steel - Black EPDM



MCLred
Reducing sleeve female/female, Cylindrical - stainless steel



PTGP
Tensioner pulley, For flat belts



HSSss
Stainless steel shoulder screw ISO7379, Stainless steel ISO 7379



CHTRP
Single and dual output gearboxes, Up to 28,8 Nm



CLLCLLP
Clevis components, long version, Steel - long range



DOMI50
Domino 50 adjustable slide, Slide DOMILINE 50



PO
Pull handle - Multi-sector, Smooth hole



B3PAN
Panamech, Multi-Beam stainless steel, Stainless steel - with clampin...


Complementary products



YG1
HEAVY DUTY spur gear, Steel 35NCD6



ZG125
Plastic spur gear, Machined plastic (delrin)

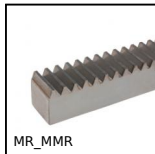

MR_MMR
Metric section rack, Steel