

Steel spur gear





Module 1.25



- Precision class 9
- Pressure angle 20°
- Linear speed 300m/min

Steel 20NCD2

Torque and power indication				
For 50 teeth at 1000 rpm				
	20NCD2 Z10CNF18.09	20NCD2 hardened	brass	fibre
Nm	3.80	18	1.90	1.52
kW	0.40	1.89	0.19	0.16

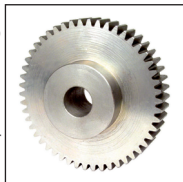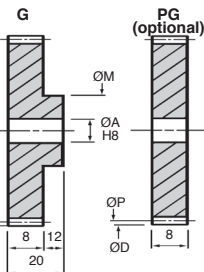

IN STOCK*
Otherwise contact us

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-12%	-25%	On request

Part number	Teeth Z	PCD OP	External OD	Boss OM	Bore OA	Weight (kg)		Stock*	Price each 1 to 5	
						G	PG		G	PG
G1.25-9	9	12,50	15,00	15,00	6	0,019	0,006	-	83,05	€
G1.25-10	10	13,75	16,25	16,25	6	0,024	0,007	✓	25,44	€
G1.25-11	11	15,00	17,50	17,50	6	0,029	0,009	-	25,44	€
G1.25-12	12	15,00	17,50	17,50	6	0,029	0,009	✓	25,44	€
G1.25-13	13	16,25	18,75	18,25	6	0,032	0,011	-	26,63	€
G1.25-14	14	17,50	20,00	20,00	6	0,039	0,013	✓	27,10	€
G1.25-15	15	18,75	21,25	12,00	6	0,023	0,015	-	27,56	€
G1.25-16	16	20,00	22,50	12,00	8	0,022	0,016	✓	28,52	€
G1.25-17	17	21,25	23,75	12,00	8	0,024	0,019	✓	29,25	€
G1.25-18	18	22,50	25,00	15,00	8	0,033	0,021	-	29,96	€
G1.25-19	19	23,75	26,25	15,00	8	0,036	0,024	-	31,17	€
G1.25-20	20	25,00	27,50	15,00	8	0,039	0,027	✓	31,59	€
G1.25-21	21	26,25	28,75	15,00	8	0,042	0,030	-	32,05	€
G1.25-22	22	27,50	30,00	15,00	8	0,045	0,033	✓	32,34	€
G1.25-23	23	28,75	31,25	15,00	8	0,048	0,037	-	32,73	€
G1.25-24	24	30,00	32,50	15,00	8	0,052	0,040	-	33,30	€
G1.25-25	25	31,25	33,75	15,00	8	0,055	0,044	-	34,02	€
G1.25-26	26	32,50	35,00	15,00	8	0,059	0,048	-	34,42	€
G1.25-27	27	33,75	36,25	15,00	8	0,063	0,052	-	35,19	€
G1.25-28	28	35,00	37,50	15,00	8	0,067	0,056	-	36,71	€
G1.25-29	29	36,25	38,75	15,00	8	0,072	0,060	-	37,68	€
G1.25-30	30	37,50	40,00	20,00	8	0,089	0,065	-	38,93	€
G1.25-31	31	38,75	41,25	20,00	8	0,093	0,069	-	39,73	€
G1.25-32	32	40,00	42,50	20,00	8	0,098	0,074	✓	40,53	€
G1.25-33	33	41,25	43,75	20,00	8	0,103	0,079	-	41,30	€

On request

*Depending on availability - Dimensions in mm

Part number	Teeth Z	PCD ØP	External ØD	Boss ØM	Bore ØA	Weight G	PG	Stock*	Price each 1 to 5 G
G1.25-34	34	42,50	45,00	20,00	8	0,108	0,084	✓	41,84 €
G1.25-35	35	43,75	46,25	20,00	8	0,113	0,089	-	42,77 €
G1.25-36	36	45,00	47,50	20,00	8	0,119	0,094	✓	43,31 €
G1.25-37	37	46,25	48,75	20,00	8	0,124	0,100	-	43,73 €
G1.25-38	38	47,50	50,00	20,00	8	0,130	0,105	-	44,21 €
G1.25-39	39	48,75	51,25	20,00	8	0,135	0,111	-	44,80 €
G1.25-40	40	50,00	52,50	30,00	10	0,173	0,115	✓	45,09 €
G1.25-41	41	51,25	53,75	30,00	10	0,179	0,121	✓	45,29 €
G1.25-42	42	52,50	55,00	30,00	10	0,185	0,128	-	45,49 €
G1.25-43	43	53,75	56,25	30,00	10	0,192	0,134	-	45,79 €
G1.25-44	44	55,00	57,50	30,00	10	0,198	0,141	-	45,96 €
G1.25-45	45	56,25	58,75	30,00	10	0,205	0,147	✓	46,17 €
G1.25-46	46	57,50	60,00	30,00	10	0,212	0,154	-	46,31 €
G1.25-47	47	58,75	61,25	30,00	10	0,219	0,161	-	46,61 €
G1.25-48	48	60,00	62,50	30,00	10	0,226	0,168	-	46,77 €
G1.25-49	49	61,25	63,75	30,00	10	0,233	0,176	-	47,78 €
G1.25-50	50	62,50	65,00	30,00	10	0,241	0,183	✓	48,17 €
G1.25-51	51	63,75	66,25	30,00	10	0,248	0,191	-	48,66 €
G1.25-52	52	65,00	67,50	30,00	10	0,256	0,198	-	49,13 €
G1.25-53	53	66,25	68,75	30,00	10	0,264	0,206	-	49,59 €
G1.25-54	54	67,50	70,00	30,00	10	0,272	0,214	-	49,90 €
G1.25-55	55	68,75	71,25	30,00	10	0,280	0,222	-	50,25 €
G1.25-56	56	70,00	72,50	30,00	10	0,288	0,231	-	52,46 €
G1.25-57	57	71,25	73,75	30,00	10	0,297	0,239	-	54,92 €
G1.25-58	58	72,50	75,00	30,00	10	0,306	0,248	-	55,64 €
G1.25-59	59	73,75	76,25	30,00	10	0,314	0,257	-	56,87 €
G1.25-60	60	75,00	77,50	30,00	10	0,323	0,266	-	58,13 €
G1.25-61	61	76,25	78,75	30,00	10	0,332	0,275	-	58,65 €
G1.25-62	62	77,50	80,00	30,00	10	0,342	0,284	-	59,51 €
G1.25-63	63	78,75	81,25	30,00	10	0,351	0,293	-	60,10 €
G1.25-64	64	80,00	82,50	30,00	10	0,361	0,303	-	60,77 €
G1.25-65	65	81,25	83,75	30,00	10	0,370	0,313	-	61,60 €
G1.25-66	66	82,50	85,00	30,00	10	0,380	0,322	-	62,47 €
G1.25-68	68	85,00	87,50	30,00	10	0,400	0,343	-	63,92 €
G1.25-70	70	87,50	90,00	30,00	10	0,421	0,363	✓	65,08 €
G1.25-72	72	90,00	92,50	30,00	10	0,442	0,385	-	65,42 €
G1.25-73	73	91,25	93,75	30,00	10	0,453	0,396	-	65,72 €
G1.25-74	74	92,50	95,00	30,00	10	0,464	0,407	-	66,10 €
G1.25-76	76	95,00	97,50	30,00	10	0,487	0,429	-	67,27 €
G1.25-78	78	97,50	100,00	30,00	10	0,510	0,452	-	69,60 €
G1.25-80	80	100,00	102,50	30,00	10	0,534	0,476	-	74,21 €
G1.25-84	84	105,00	107,50	30,00	10	0,583	0,525	-	74,87 €
G1.25-88	88	110,00	112,50	30,00	10	0,635	0,577	-	82,30 €
G1.25-90	90	112,50	115,00	30,00	10	0,661	0,604	-	83,05 €
G1.25-96	96	120,00	122,50	30,00	12	0,745	0,688	-	95,57 €
G1.25-100	100	125,00	127,50	30,00	12	0,804	0,746	-	97,08 €
G1.25-112	112	140,00	142,50	30,00	12	0,995	0,938	-	107,42 €
G1.25-120	120	150,00	152,50	40,00	15	1,135	1,077	-	114,92 €
G1.25-130	130	162,50	165,00	40,00	15	1,323	1,265	-	128,08 €
G1.25-140	140	175,00	177,50	40,00	15	1,525	1,468	-	138,40 €

On request

↓ **Gears available up to this size** ↓

G1.25-142 142 177,50 180,00 **Dimensions: contact us** **On request**

*Depending on availability - Dimensions in mm

Our other products



CHAEpac

Square decorative screwed hinges, carbon fibre reinforced



PRF_ECL

Nut for aluminium profile, Stainless steel square nut with tab



PENC

Recessed handle, clip-in



HW_HT

Half-rail guide, Rail



WJUM10

Drylin® W bearing block, Slide



 
CHAC4040NP

Square hinge with riveted pin, not drilled, Square with riveted pin,...




BTES

Universal stainless steel arm for tensioner, For use in hostile envi...



EZY

 Cylindrical stop, Steel



PRZ

Wear strip for slat top chain, Z profile to be



BZY_SS

Stainless steel cylindrical elasto



GSI_A

Stainless steel adjustable gas spring,



CFS

Miniature cam follower, Miniature

Complementary products




YG1

HEAVY DUTY spur gear, Steel 35NCD6



ZG125

 Plastic spur gear, Machined plastic (delrin)



MR_MMR

Metric section rack, Steel