


Module 1.5

Steel 20NCD2



- Precision class 9
- Pressure angle 20°
- Linear speed 300m/min

Torque and power indication				
For 50 teeth at 1000 rpm				
	20NCD2	20NCD2	brass	fibre
	Z10CNF18.09	hardened		
Nm	8.88	41.50	4.44	3.55
kW	0.93	4.23	0.46	0.37

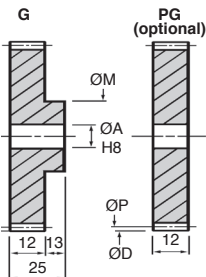

✓ IN STOCK*
Otherwise contact us

DISCOUNTS

Qty	1+	6+	20+	50+
Disc. List	-12%	-25%		On request

Part number	Teeth Z	PCD ØP	External ØD	Boss ØM	Bore ØA	Weight (kg)		Stock*	Price each 1 to 5	
						G	PG		G	PG
G1.5-9	9	15,00	18,00	18	8	0,032	0,012	✓	25,46 €	
G1.5-10	10	16,50	19,50	18	8	0,035	0,015	✓	25,46 €	
G1.5-11	11	18,00	21,00	18	8	0,039	0,019	-	25,46 €	
G1.5-12	12	18,00	21,00	14	8	0,029	0,019	✓	12,95 €	
G1.5-13	13	19,50	22,50	15	8	0,035	0,023	✓	25,02 €	
G1.5-14	14	21,00	24,00	15	8	0,040	0,027	✓	25,62 €	
G1.5-15	15	22,50	25,50	18	8	0,052	0,032	✓	14,05 €	
G1.5-16	16	24,00	27,00	20	10	0,058	0,034	✓	14,43 €	
G1.5-17	17	25,50	28,50	20	10	0,063	0,040	✓	27,80 €	
G1.5-18	18	27,00	30,00	20	10	0,069	0,045	✓	22,80 €	
G1.5-19	19	28,50	31,50	20	10	0,075	0,051	✓	29,73 €	
G1.5-20	20	30,00	33,00	20	10	0,081	0,058	✓	16,73 €	
G1.5-21	21	31,50	34,50	20	10	0,088	0,064	✓	16,73 €	
G1.5-22	22	33,00	36,00	20	10	0,095	0,071	✓	16,45 €	
G1.5-23	23	34,50	37,50	20	10	0,102	0,079	✓	32,41 €	
G1.5-24	24	36,00	39,00	25	10	0,127	0,086	✓	17,56 €	
G1.5-25	25	37,50	40,50	25	10	0,135	0,094	✓	34,47 €	
G1.5-26	26	39,00	42,00	25	10	0,144	0,102	-	36,10 €	
G1.5-27	27	40,50	43,50	25	10	0,152	0,111	-	37,21 €	
G1.5-28	28	42,00	45,00	25	10	0,161	0,120	✓	38,33 €	
G1.5-29	29	43,50	46,50	25	10	0,170	0,129	-	38,96 €	
G1.5-30	30	45,00	48,00	25	10	0,180	0,139	✓	21,51 €	
G1.5-31	31	46,50	49,50	25	10	0,190	0,149	✓	40,71 €	
G1.5-32	32	48,00	51,00	25	10	0,200	0,159	✓	22,24 €	
G1.5-33	33	49,50	52,50	25	10	0,211	0,170	✓	41,84 €	
G1.5-34	34	51,00	54,00	25	10	0,221	0,180	✓	42,23 €	

On request

*Depending on availability - Dimensions in mm

Part number	Teeth Z	PCD ØP	External ØD	Boss ØM	Bore ØA	Weight (kg)		Stock*	Price each 1 to 5	
						G	PG		G	PG
G1.5-35	35	52,50	55,50	30	15	0,235	0,183	-	42,72	€
G1.5-36	36	54,00	57,00	30	15	0,247	0,194	✓	24,10	€
G1.5-37	37	55,50	58,50	30	15	0,259	0,206	-	45,90	€
G1.5-38	38	57,00	60,00	30	15	0,271	0,218	-	46,89	€
G1.5-39	39	58,50	61,50	30	15	0,283	0,231	-	47,88	€
G1.5-40	40	60,00	63,00	40	15	0,351	0,243	✓	48,91	€
G1.5-41	41	61,50	64,50	40	15	0,364	0,257	-	48,91	€
G1.5-42	42	63,00	66,00	40	15	0,377	0,270	✓	48,95	€
G1.5-43	43	64,50	67,50	40	15	0,391	0,284	-	49,02	€
G1.5-44	44	66,00	69,00	40	15	0,405	0,298	-	49,02	€
G1.5-45	45	67,50	70,50	40	15	0,420	0,312	-	50,03	€
G1.5-46	46	69,00	72,00	40	15	0,435	0,327	✓	51,13	€
G1.5-47	47	70,50	73,50	40	15	0,450	0,342	-	52,33	€
G1.5-48	48	72,00	75,00	40	15	0,465	0,358	✓	53,46	€
G1.5-49	49	73,50	76,50	40	15	0,481	0,373	✓	53,46	€
G1.5-50	50	75,00	78,00	40	15	0,497	0,389	✓	59,74	€
G1.5-51	51	76,50	79,50	40	15	0,513	0,406	-	61,57	€
G1.5-52	52	78,00	81,00	40	15	0,530	0,423	-	62,82	€
G1.5-53	53	79,50	82,50	40	15	0,547	0,440	-	63,82	€
G1.5-54	54	81,00	84,00	40	15	0,564	0,457	-	64,03	€
G1.5-55	55	82,50	85,50	40	15	0,582	0,475	-	64,31	€
G1.5-56	56	84,00	87,00	40	15	0,600	0,493	-	64,84	€
G1.5-57	57	85,50	88,50	40	15	0,618	0,511	-	65,45	€
G1.5-58	58	87,00	90,00	40	15	0,637	0,530	-	65,45	€
G1.5-59	59	88,50	91,50	40	15	0,656	0,549	-	66,10	€
G1.5-60	60	90,00	93,00	40	15	0,675	0,568	✓	66,48	€
G1.5-62	62	93,00	96,00	40	15	0,715	0,608	-	67,77	€
G1.5-64	64	96,00	99,00	40	15	0,756	0,648	-	68,61	€
G1.5-65	65	97,50	100,50	40	15	0,777	0,669	-	70,28	€
G1.5-66	66	99,00	102,00	40	15	0,798	0,691	-	72,85	€
G1.5-68	68	102,00	105,00	40	15	0,842	0,734	-	74,50	€
G1.5-70	70	105,00	108,00	40	15	0,886	0,779	-	77,17	€
G1.5-71	71	106,50	109,50	50	15	0,980	0,802	-	79,31	€
G1.5-72	72	108,00	111,00	50	15	1,003	0,825	-	81,62	€
G1.5-73	73	109,50	112,50	50	15	1,026	0,849	-	83,59	€
G1.5-74	74	111,00	114,00	50	15	1,050	0,872	-	86,47	€
G1.5-75	75	112,50	115,50	50	15	1,074	0,897	-	86,99	€
G1.5-76	76	114,00	117,00	50	15	1,099	0,921	-	87,34	€
G1.5-78	78	117,00	120,00	50	15	1,149	0,971	-	91,74	€
G1.5-80	80	120,00	123,00	50	15	1,200	1,022	✓	95,08	€
G1.5-86	86	129,00	132,00	50	15	1,362	1,184	-	102,17	€
G1.5-90	90	135,00	138,00	50	15	1,476	1,298	✓	109,46	€
G1.5-96	96	144,00	147,00	50	15	1,657	1,479	-	116,69	€
G1.5-98	98	147,00	150,00	50	15	1,720	1,542	-	123,96	€
G1.5-100	100	150,00	153,00	50	15	1,784	1,606	-	132,05	€
G1.5-105	105	157,50	160,50	50	15	1,951	1,773	-	140,69	€
G1.5-110	110	165,00	168,00	50	15	2,125	1,947	-	151,80	€
G1.5-115	115	172,50	175,50	50	15	2,308	2,130	-	169,06	€
G1.5-120	120	180,00	183,00	50	15	2,498	2,320	-	188,99	€

On request

↓ **Gears available up to this size** ↓

G1.5-298	298	447,00	450,00	Dimensions : contact us	on request
-----------------	------------	---------------	---------------	--------------------------------	-------------------

*Depending on availability

Our other products



PR580

Stainless steel articulated foot Ø80, Ø 80



PARF110

Pressed steel base rigid foot, Swivelling Ø110



SH3

Parallel axis helical gear, Machined plastic (delrin)



PRES2HR

Manual workbench press, Force up to 200kg



NPTR10

Adjustable cross clamp, Adjustable



NDS20

Double cross clamp, Crossed



SLBWSS

Indexing plunger, weldable, Weldable - Stainless steel



PF55

Worm and wheel gear reducer, up to 57 Nm



DB

Steel bevel gear, 2:1



BABpss

301 Stainless steel ball pin, Stainless steel



GCL

Linear ball slide - Stainless steel balls, Chariot - from 516 N



VRSSss

Male swivelling lifting rings stainless steel, Male swivelling - s...

Complementary products



YG1

HEAVY DUTY spur gear, Steel 35NCD6




ZG1

Plastic spur gear, Machined plastic (delrin)



GG1

Ground spur gear, Heat treated steel

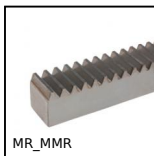

MR_MMR

Metric section rack, Steel