

Steel spur gear





Module 2.0

Steel 20NCD2



- Precision class 9
- Pressure angle 20°
- Linear speed 300m/min

Torque and power indication				
For 50 teeth at 1000 rpm				
	20NCD2	20NCD2		
	Z10CNF18.09	hardened	brass	fibre
Nm	25	119	12.50	10
kW	2.61	12.51	1.32	1.04

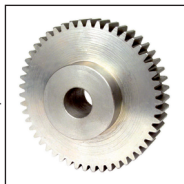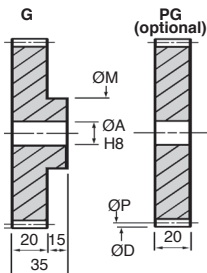

✓ IN STOCK*
Otherwise contact us



DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-12%	-25%	On request

Part number	Teeth Z	PCD ØP	External ØD	Boss ØM	Bore ØA	Weight (kg)		Stock*	Price each 1 to 5	
						G	PG		G	PG
G2-9	9	20,00	24,00	24	12	0,070	0,031	✓	33,16 €	
G2-10	10	22,00	26,00	26	12	0,089	0,041	✓	33,16 €	
G2-11	11	24,00	28,00	28	12	0,110	0,052	-	33,16 €	
G2-12	12	24,00	28,00	28	12	0,110	0,052	✓	17,76 €	
G2-13	13	26,00	30,00	20	12	0,087	0,064	✓	35,08 €	
G2-14	14	28,00	32,00	20	12	0,100	0,077	✓	37,07 €	
G2-15	15	30,00	34,00	25	15	0,117	0,081	✓	20,93 €	
G2-16	16	32,00	36,00	25	15	0,132	0,096	-	22,01 €	
G2-17	17	34,00	38,00	25	15	0,148	0,112	-	41,84 €	
G2-18	18	36,00	40,00	30	15	0,190	0,129	✓	23,07 €	
G2-19	19	38,00	42,00	30	15	0,207	0,147	-	44,08 €	
G2-20	20	40,00	44,00	30	15	0,226	0,165	✓	24,13 €	
G2-21	21	42,00	46,00	30	15	0,246	0,185	-	46,17 €	
G2-22	22	44,00	48,00	35	15	0,296	0,206	✓	47,88 €	
G2-23	23	46,00	50,00	35	15	0,317	0,227	✓	47,88 €	
G2-24	24	48,00	52,00	35	15	0,340	0,250	✓	26,26 €	
G2-25	25	50,00	54,00	35	15	0,364	0,273	✓	51,68 €	
G2-26	26	52,00	56,00	35	15	0,388	0,298	✓	53,31 €	
G2-27	27	54,00	58,00	40	20	0,411	0,302	✓	55,22 €	
G2-28	28	56,00	60,00	40	20	0,437	0,329	✓	56,40 €	
G2-29	29	58,00	62,00	40	20	0,464	0,356	-	57,79 €	
G2-30	30	60,00	64,00	40	20	0,493	0,385	✓	31,71 €	
G2-31	31	62,00	66,00	40	20	0,522	0,414	-	61,40 €	
G2-32	32	64,00	68,00	40	20	0,552	0,444	✓	34,49 €	
G2-33	33	66,00	70,00	40	20	0,584	0,476	-	65,42 €	

On request

*Depending on availability - Dimensions in mm

Part number	Teeth Z	PCD ØP	External ØD	Boss ØM	Bore ØA	Weight (kg)		Stock	Price each 1 to 5	
						G	PG		G	PG
G2-34	34	68,00	72,00	40	20	0,616	0,508	✓	68,61 €	
G2-35	35	70,00	74,00	50	20	0,730	0,541	✓	70,80 €	
G2-36	36	72,00	76,00	50	20	0,764	0,575	✓	40,22 €	
G2-37	37	74,00	78,00	50	20	0,799	0,610	-	75,76 €	
G2-38	38	76,00	80,00	50	20	0,836	0,646	-	77,76 €	
G2-39	39	78,00	82,00	50	20	0,873	0,683	✓	79,62 €	
G2-40	40	80,00	84,00	50	20	0,911	0,721	✓	81,07 €	
G2-41	41	82,00	86,00	50	20	0,949	0,760	-	82,59 €	
G2-42	42	84,00	88,00	50	20	0,989	0,800	-	83,53 €	
G2-43	43	86,00	90,00	50	20	1,030	0,841	-	84,55 €	
G2-44	44	88,00	92,00	50	20	1,072	0,883	✓	85,87 €	
G2-45	45	90,00	94,00	50	20	1,115	0,926	✓	87,18 €	
G2-46	46	92,00	96,00	50	20	1,159	0,969	-	89,19 €	
G2-47	47	94,00	98,00	50	20	1,203	1,014	-	91,18 €	
G2-48	48	96,00	100,00	50	20	1,249	1,060	✓	93,87 €	
G2-49	49	98,00	102,00	50	20	1,296	1,106	-	96,83 €	
G2-50	50	100,00	104,00	50	20	1,343	1,154	✓	100,50 €	
G2-51	51	102,00	106,00	50	20	1,392	1,202	-	102,45 €	
G2-52	52	104,00	108,00	50	20	1,441	1,252	-	104,23 €	
G2-53	53	106,00	110,00	50	20	1,492	1,302	-	105,43 €	
G2-54	54	108,00	112,00	50	20	1,543	1,354	✓	107,21 €	
G2-55	55	110,00	114,00	50	20	1,596	1,406	-	117,72 €	
G2-56	56	112,00	116,00	50	20	1,649	1,460	-	120,21 €	
G2-57	57	114,00	118,00	50	20	1,703	1,514	-	122,62 €	
G2-58	58	116,00	120,00	50	20	1,759	1,569	-	124,77 €	
G2-59	59	118,00	122,00	50	20	1,815	1,626	-	126,22 €	
G2-60	60	120,00	124,00	50	20	1,872	1,683	✓	127,97 €	
G2-62	62	124,00	128,00	50	20	1,989	1,800	-	131,12 €	
G2-64	64	128,00	132,00	50	20	2,211	1,921	-	134,29 €	
G2-65	65	130,00	134,00	50	20	2,173	1,983	-	140,69 €	
G2-66	66	132,00	136,00	50	20	2,236	2,046	-	143,07 €	
G2-68	68	136,00	140,00	50	20	2,364	2,175	-	145,20 €	
G2-70	70	140,00	144,00	50	20	2,497	2,308	✓	148,86 €	
G2-71	71	142,00	146,00	70	20	2,781	2,376	-	157,12 €	
G2-72	72	144,00	148,00	70	20	2,850	2,444	-	166,66 €	
G2-73	73	146,00	150,00	70	20	2,920	2,514	-	173,41 €	
G2-74	74	148,00	152,00	70	20	2,990	2,585	-	178,28 €	
G2-75	75	150,00	154,00	70	20	3,062	2,656	-	184,26 €	
G2-76	76	152,00	156,00	70	20	3,135	2,729	-	193,24 €	
G2-78	78	156,00	160,00	70	20	3,283	2,877	-	203,27 €	
G2-80	80	160,00	164,00	70	20	3,435	3,029	✓	223,02 €	
G2-86	86	172,00	176,00	70	20	3,914	3,508	-	239,93 €	
G2-90	90	180,00	184,00	70	20	4,252	3,846	-	266,28 €	
G2-96	96	192,00	196,00	70	20	4,789	4,383	-	285,08 €	
G2-98	98	196,00	200,00	70	20	4,975	4,570	-	310,29 €	
G2-100	100	200,00	204,00	70	20	5,166	4,760	-	331,11 €	
G2-105	105	210,00	214,00	70	20	5,658	5,253	-	343,42 €	
G2-110	110	220,00	224,00	70	20	6,175	5,770	-	366,92 €	
G2-115	115	230,00	234,00	70	20	6,716	6,311	-	392,45 €	
G2-120	120	240,00	244,00	70	20	7,281	6,875	-	426,40 €	

On request

↓ Gears available up to this size ↓

G2-290 290 580,00 584,00 Dimensions : contact us on request

*Depending on availability - Dimensions in mm

Our other products



NCT
Square tube
connector, Fixed
angle



MRAeco
Low cost quick link,
Steel



ADL_F
Female eye bolt
conforms to DIN582,
Steel



VELM6
Screw-on base for
hook-and-loop strip,
Polyamide



BLH70
Right angled gearbox,
from 26 to 128 Nm



RTE
Rotex®, jaw coupling,
Aluminium



EHD08-3
Internal epicyclic
servo reducers, from
20 to 50 Nm



COA-COG
Surface mounting
plate, Surface
mounting plate for
clevis



D-PAR_SS
Stainless steel
progressive stop,



H02
Single needle roller
universal joint, Heavy



PF30
Worm and wheel gear
reducer, up to 8.80



G1
Steel spur gear, Steel
20NCD2

Complementary products




YG2
HEAVY DUTY spur
gear, Steel 35NCD6



ZG2
Plastic spur gear,
Machined plastic
(delrin)



 GG2
Ground spur gear,
Heat treated steel



MR_MMR
Metric section rack,
Steel