

# Steel spur gear



## Module 3,0

## C45 steel

### - Economy range of gears

- Pressure angle 20°


- Material:

C45 steel UNI7845

### Info


- Pilot bore information is given as a guide only and may vary between batches

- Gear should be finished to suit the application, **we are unable to offer this service**

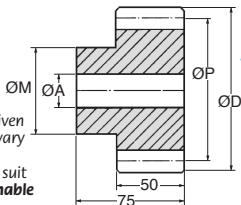

**Economy range**

Supplied pre-bored

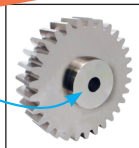


### DISCOUNTS

Qty	1+	4+	10+
Disc.	List	-5%	On request

Part number	Z Teeth	ØP PCD	ØD External	ØM Boss	ØA Pilot bore		Price each 1 to 3
G3-12/ECO	12	36	42	25	12	✓	6,52 €
G3-13/ECO	13	39	45	25	12	-	7,79 €
G3-14/ECO	14	42	48	30	12	✓	8,07 €
G3-15/ECO	15	45	51	35	12	✓	9,09 €
G3-16/ECO	16	48	54	38	15	✓	10,56 €
G3-17/ECO	17	51	57	42	15	✓	11,24 €
G3-18/ECO	18	54	60	45	15	✓	12,02 €
G3-19/ECO	19	57	63	45	15	-	12,38 €
G3-20/ECO	20	60	66	45	15	✓	13,84 €
G3-21/ECO	21	63	69	45	15	✓	16,15 €
G3-22/ECO	22	66	72	50	15	✓	16,65 €
G3-23/ECO	23	69	75	50	15	✓	18,27 €
G3-24/ECO	24	72	78	50	16	✓	18,65 €
G3-25/ECO	25	75	81	60	16	✓	20,76 €
G3-26/ECO	26	78	84	60	16	✓	22,21 €
G3-27/ECO	27	81	87	60	16	✓	23,76 €
G3-28/ECO	28	84	90	60	16	✓	26,40 €
G3-29/ECO	29	87	93	60	16	✓	27,31 €
G3-30/ECO	30	90	96	60	16	✓	28,36 €
G3-31/ECO	31	93	99	70	20	✓	29,39 €
G3-32/ECO	32	96	102	70	20	✓	30,92 €
G3-33/ECO	33	99	105	70	20	✓	31,04 €
G3-34/ECO	34	102	108	70	20	✓	32,27 €
G3-35/ECO	35	105	111	70	20	✓	34,18 €
G3-36/ECO	36	108	114	70	20	✓	36,74 €
G3-37/ECO	37	111	117	80	20	✓	38,16 €
G3-38/ECO	38	114	120	80	20	✓	38,77 €
G3-39/ECO	39	117	123	80	20	✓	39,87 €
G3-40/ECO	40	120	126	80	20	✓	40,08 €
G3-41/ECO	41	123	129	90	20	✓	46,78 €
G3-42/ECO	42	126	132	90	20	✓	52,51 €
G3-43/ECO	43	129	135	90	20	✓	55,62 €
G3-44/ECO	44	132	138	90	20	✓	57,10 €
G3-45/ECO	45	135	141	90	20	✓	60,33 €
G3-46/ECO	46	138	144	90	20	✓	64,19 €
G3-47/ECO	47	141	147	90	20	✓	67,07 €
G3-48/ECO	48	144	150	100	20	✓	68,39 €

Dimensions in mm
 
## Our other products



Worm and wheel set,  
Machined plastic  
(delrin)



Eco range Spur gear,  
Steel C45



Silicone conical elasto  
buffer, Female  
mounting



Eco range Spur gear,  
Steel C45



Fixed castor with  
plate, Steel - grey  
rubber



Straight clevis,  
Straight clevis for use  
with a male clevis



Precision locknut,  
Precision locknut



Joints for aluminium  
profile, Variable angle  
hinge



Spring loaded plunger  
with ball tip, Stainless



Wheel, Rubber tyre -  
Polypropylene rim



Ball transfer unit bolt  
fitting, Heavy



Plain washer, Steel

## Complementary products



Steel spur gear, Steel  
20NCD2



Moulded plastic spur  
gear, Moulded plastic  
(nylon)



Plastic spur gear,  
Machined plastic  
(delrin)



HEAVY DUTY spur  
gear, Steel 35NCD6